



Fall Protection
for Tools

Everything
you need to

fight gravity.

Product
Catalogue



#3MScienceOfSafety

Fall Protection for Tools Awareness Resources.

Fall Protection for Tools Pocket Reference Guide

Learn how to make virtually any tool ready for tethering with this included reference guide.



Common Tool Attachment Points Poster

Discover the most common places to equip your gear with 3M™ DBI-SALA® Fall Protection for Tools. Visualise the available attachment points and their associated weight ratings.




Hard Hat Stickers

Make safety awareness efforts stick with these Stop the Drop hard hat stickers.



Looping Awareness Videos

Get immediate access to high definition videos that can be used in training and awareness materials at your work location.

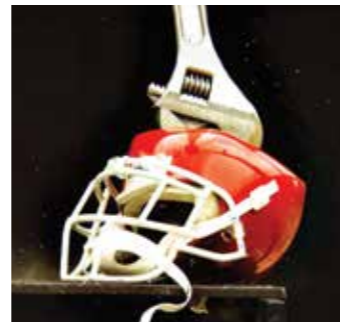

<http://bit.ly/2C9vsqY>

Table of contents.

Attachment Points	4	Tool Pouches	20
Tool Lanyards	10	Spill Control Buckets	22
Tool Holsters.....	14	Wristbands	26
Tool Belts.....	19		

The science of fighting gravity.

Protecting workers takes more than just keeping them from falling. Their equipment also needs to be kept safe at height.

That's why for over 10 years, we've been pioneering an innovative line of products and solutions to prevent dropped tools and equipment. From construction sites to oil rigs, we help make work environments safer and more productive by protecting workers from hazards that can result in personal injury, equipment damage and tool loss.

Certified and tested.

Our onsite ISO 17025 accredited lab allows us to simulate heat, cold, moisture, corrosion and abrasion-the challenges you face every day. We conduct dynamic and static strength tests, both in the field and in our ISO 90001 certified manufacturing facilities, ensuring you get the highest quality, most reliable fall protection for tools.



Three pillars of Science of Safety.

This industry-leading approach embodies best practice on a global level and is comprised of three complementary elements:



Selection.



Training.



Fit Validation.

Visit www.3M.com/SafetyOfSafety for more information.

For product inquiries:

3M.com/FallProtection
00 800 999 55500

3M™ DBI-SALA® D-rings

<http://bit.ly/2C9vsqY>

- D-rings can be attached to virtually any tool under 2.3 kg (5 lbs) or 0.9 kg (2 lbs) using our Quick-Wrap Tape (see page 5).
- Creates an attachment point in less than a minute.
- Dual D-rings allow for 100% tool tie-off during tool transfers.



Part #	Description	Load rating	Quantity	Non-conductive
1500003	D-ring 0.5" x 2.25"	0.9 kg (2 lbs)	10	No
1500005	D-ring 0.5" x 2.25" non-conductive	0.9 kg (2 lbs)	10	Yes
1500007	D-ring 1" x 3.5"	2.3 kg (5 lbs)	10	No
1500001	Dual D-ring small	0.9 kg (2 lbs)	10	No



3M™ DBI-SALA® Quick-Wrap Tape II

<http://bit.ly/2C9vsqY>

- Longer 3 year shelf life.
- Heavy duty 2.54 cm (1") wide tape with high-elongation properties resulting in more wraps with the same length of tape.
- Used with our D-rings (see page 4) and Tool Cinch Attachments (see page 6) to create instant tethering points on virtually any tool.
- Conforms to shape of tool handles, adheres on contact to most clean tools and can be repositioned during installation.
- Proprietary 3M material and adhesive provide good tear resistance.

Part #	Description	Quantity	Length
1500168	Quick Wrap Tape II, Blue	1	274 cm (108")
1500169	Quick Wrap Tape II, Blue	10	274 cm (108")
1500171	Quick Wrap Tape II, Blue, 2x length	1	548.6 cm (216")
1500172	Quick Wrap Tape II, Blue, 2x length	10	548.6 cm (216")
1500174	Quick Wrap Tape II, Yellow	1	274 cm (108")
1500175	Quick Wrap Tape II, Yellow	10	274 cm (108")



1500168



1500171



1500174



3M™ DBI-SALA® Tool Cinch Attachments

🔗 <http://bit.ly/2C9vsqY>

- Tool Cinch Attachments feature a cinch design that allows users to quickly secure equipment up to 15.9 kg (35 lbs) or 36.3 kg (80 lbs).
- Stabilisation wings can be used to keep Tool Cinch Attachments in place using our Quick-Wrap Tape (see page 5).
- Visit our website to see real-world examples of our Tool Cinch Attachments in use.



Part #	Description	Load rating	Quantity
1500015	V-Ring attachment point, 2 stabilisation wings	15.9 kg (35 lbs)	1
1500016	V-Ring attachment point, 2 stabilisation wings	15.9 kg (35 lbs)	10
1500014	V-Ring attachment point, stabilisation wing	15.9 kg (35 lbs)	10
1500012	V-Ring attachment point	15.9 kg (35 lbs)	10
1500018	V-Ring attachment point, 2 stabilisation wings	36.3 kg (80 lbs)	10



3M™ DBI-SALA® Heat Shrink

🔗 <http://bit.ly/2C9vsqY>

- Protect your investment and connection point! Heat Shrink protects our Quick-Wrap Tape (see page 5) from abrasives and harsh work environments.
- Heat Shrink links reduce in size by 200% when heat is applied.

Part #	Description	Quantity
1500019	Heat Shrink 1.9 cm x 4.5 cm (0.75" x 1.75")	25
1500020	Heat Shrink 2.5 cm x 4.5 cm (1" x 1.75")	25
1500021	Heat Shrink 3.8 cm x 5.1 cm (1.5" x 2")	25
1500022	Heat Shrink 5.1 cm x 10.2 cm (2" x 4")	10
1500023	Heat Shrink 7.6 cm x 10.2 cm (3" x 4")	10



3M™ DBI-SALA® D-ring Cord

🔗 <http://bit.ly/2C9vsqY>

- Easily cinches to tools weighing up to 2.3 kg (5 lbs).
- Simply pass the loop end of a D-ring Cord through a pre-drilled hole or closed handle to create an attachment point.
- Extremely durable and reusable.

Part #	Description	Load rating	Quantity
1500009	D-ring Cord	2.3 kg (5 lbs)	10



3M™ DBI-SALA® Quick Spins

<http://bit.ly/2C9vsqY>

- Simply slides onto the handle of a tool in seconds.
- Swivel spin top makes them tangle resistant.
- Reusable and suitable for non-conductive use.



Part #	Description	Load rating	Quantity
1500027	Small 1.5 cm (0.6")	0.5 kg (1 lbs)	10
1500028	Medium 2 cm (0.8")	0.5 kg (1 lbs)	10
1500029	Large 2.5 cm (1")	0.5 kg (1 lbs)	10
1500030	X-Large 3.1 cm (1.2")	0.5 kg (1 lbs)	10
1500031	Pen Holder 0.8 cm (0.3")	-	10
1500032	Pen Holder with Coil 0.8 cm (0.3")	-	10
1500033	Permanent Marker 1.3 cm (0.5")	-	10
1500034	Permanent Marker with Coil 1.3 cm (0.5")	-	10



1500028



1500030

3M™ DBI-SALA® Micro D-ring Cord

<http://bit.ly/2C9vsqY>

- Designed to allow for easy tethering of small devices such as cell phones, cameras and radios.
- Adheres to most surfaces creating an attachment point in seconds.
- Load rated for 0.9 kg (2 lbs) when used with 1500060.
- Uses 3M very high bond adhesive.

Part #	Description	Load rating	Quantity
1500010	Micro D-ring Cord	0.9 kg (2 lbs)	10



3M™ DBI-SALA® Quick Rings

<http://bit.ly/2C9vsqY>

- Quick Rings are an economical solution for tethering tools quickly.
- Allow many tools up to 0.9 kg (2 lbs) to be made tether-ready.
- Ring pliers can be used to simplify quick ring installation.



Part #	Description	Load rating	Quantity
1500024	Quick Ring, Small 1.9 cm (0.75")	0.9 kg (2 lbs)	25
1500025	Quick Ring, Medium 2.5 cm (1")	0.9 kg (2 lbs)	25
1500026	Quick Ring, Large 3.8 cm (1.5")	0.9 kg (2 lbs)	25

3M™ DBI-SALA® Harness Adapter

- Provides an attachment point for tools on harness webbing.
- Fast and easy installation—anywhere on your harness webbing.
- Abrasion-resistant and durable.
- Can be used on products with black & gold carabiner.



1500161

Part #	Description	Load rating	Quantity
1500161	Harness Adapter	2.3 kg (5 lb)	1



3M™ DBI-SALA® Bungee Tethers



Part #	Description	Load rating	Length (relaxed)	Length (stretched)
1500047	Hook2Loop Bungee Tether	4.5 kg (15 lbs)	81.3 cm (32")	119.4 cm (47")
1500048	Hook2Loop Bungee Tether (10 pack)	4.5 kg (15 lbs)	81.3 cm (32")	119.4 cm (47")
1500049	Medium-Duty Hook2Loop Bungee Tether	15.9 kg (35 lbs)	78.7 cm (31")	132.1 cm (52")

Engineered to last

Built to be more durable and longer-lasting than the competition, our bungee tethers are third-party load rated and thoughtfully designed to prevent dropped objects.




Self-Locking carabiner

The Hook2Loop Bungee Tether features a self-locking carabiner that prevents accidental opens and automatically closes.



Competitor non-locking carabiners

Non-locking carabiners can be disconnected with a simple twist, potentially resulting in an accidental drop.

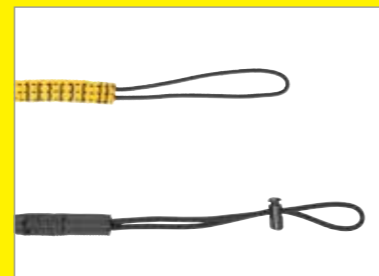

Competitor barrel locks

Many competitive bungee-tether bottoms often utilise a barrel lock. These barrel locks can pose risks as they allow for improper tethering of tools.

3M™ DBI-SALA® Coil Tethers

An industry-first innovation.


Easy to clean and out of the way—exactly what a tether should be. The lightweight vinyl construction and ultra-compact design of our Coil Tethers makes them an ideal alternative to classic bungee tethers. Since we first introduced them to the marketplace, we've continued to refine and improve our line of coil lanyards with feedback from actual workers in the field.

1500160 Hook2Hook Coil Tether with Swivel



1500066 Hook2QuickRing Coil Tether with Tail

- Use with hammers and other long-handled tools.
- Available as a combo with our Hammer Holster.

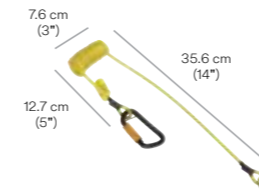

1500068 Trigger2Trigger Coil Tether

- Ideal for use from Wristband.



1500060 Clip2Loop Coil Tether

- Secure cameras, cell phones, radios and other small objects.
- Works well with our Micro D-ring.



1500059 Clip2Clip Coil Tether

- Non-conductive.
- Ideal for use from Wristband.



1500178 Hard Hat Tether



Part #	Description	Quantity	Load rating	Length (relaxed)	Length (stretched)
1500160	Hook2Hook Coil Tether with Swivel	10	2.3 kg (5 lbs)	10.2 cm (4")	157.5 cm (62")
1500068	Trigger2Trigger Coil Tether	10	2.3 kg (5 lbs)	4.4 cm (1.75")	70 cm (24")
1500059	Clip2Clip Coil Tether	10	0.9 kg (2 lbs)	4.4 cm (1.75")	70 cm (24")
1500066	Hook2Quick Ring Coil Tether with Tail	10	0.9 kg (2 lbs)	7.6 cm (3")	157.5 cm (62")
1500060	Clip2Loop Coil Tether	10	0.9 kg (2 lbs)	17.8 cm (7")	86.4 cm (34")
1500178	Hard Hat tether	10	1.8 kg (4 lbs)	14 cm (5.5")	91 cm (36")

3M™ DBI-SALA® Retractor

- High-strength Dyneema® retractor line Secure tools up to 2,5 kg (5 lbs).
- Line stays taut while reaching, retracts when not in use.
- Housing connection point swivels with workers motions.
- Prevent accidental disconnections or carabiner rollout with dual-action self-locking carabiners on each end.

Part #	Quantity	Load rating
1500156	1	2.3 kg (5 lbs)



3M™ DBI-SALA® Retractor

- Compatible with a number of our Tool Holsters (see page 14), Wristbands (see page 26), and Tool Pouches (see page 20).
- Inner 132 cm (52") steel coil allows automatic retraction when not in use.

Part #	Quantity	Load rating
1500069	1	0.7 kg (1.5 lbs)



3M™ DBI-SALA® Trigger2Trigger Lanyards

- Thumb-controlled trigger snaps on both sides of these lanyards are easy to operate, even while wearing gloves.
- Trigger snaps swivel, making them tangle-resistant.


Part #	Quantity	Load rating	Length
1500054	10	4.5 kg (10 lbs)	30.48 cm (12")
1500056	10	4.5 kg (10 lbs)	60.96 cm (24")
1500058	10	4.5 kg (10 lbs)	91.44 cm (36")



3M™ DBI-SALA® Medium-Duty Hook2Loop Lanyard

- Features an aluminium double-action twist-lock carabiner to prevent accidental opens.
- Works well with medium-duty tool cinch.

Part #	Load rating	Length
1500050	15.9 kg (35 lbs)	182.9 cm (72")

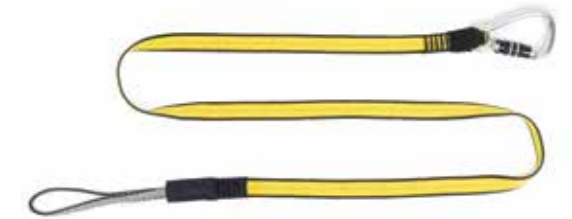

3M™ DBI-SALA® Heavy-Duty Hook2Loop Lanyard

- Features an aluminium double-action twist-lock carabiner to prevent accidental opens.
- Works well with heavy-duty tool cinch (see page 6).

Part #	Load rating	Length
1500051	36.6 kg (80 lbs)	182.9 cm (72")



3M™ DBI-SALA® Heavy-Duty Hook2Rail Lanyard

- Features an aluminium double-action twist-lock carabiner to prevent accidental opens.
- Large double-action twist-lock rail carabiner.
- Works well with heavy-duty tool cinch (see page 6).

Part #	Load rating	Length
1500052	36.3 kg (80 lbs)	182.9 cm (72")



3M™ DBI-SALA® Smart Holsters

Your tools, at the ready.

Safer. Easier. It's not often that your job can be both, but 3M DBI-SALA Smart Holsters are engineered for exactly that. These next generation tool pouches feature intelligent productivity features that are designed to keep your tool right where you want it at all times.

Beacon high-visibility Reflectors

Products equipped with our high-visibility reflectors are always easy to identify and locate, even when left in dark spaces. The highly reflective material stitched into the front and back of the holster makes it easily detectable with a flashlight even in low-light conditions.



The faster, smarter way to holster

Our Quick-Mag Technology speeds up your workflow and reduces how often your tools need to be holstered. This powerful magnetic tool staging system allows tools to simply stick to the holster, ensuring the tool you need is always at the ready.



Bottom drain vent

You're at your best when your tools are too. The integrated drain vent in our Smart Holsters protects your tools from rusting and your holster from dry rot. Even in rainy weather conditions, the drain vent helps keep the holster dry by allowing water to pass through at all times.



3M™ DBI-SALA® Single and Dual Tool Holsters



[1] Hook2Loop Bungee Tether sold separately.

- Single and Dual Tool Holsters are equipped with D-rings that are load rated for 2.3 kg (5 lbs).
- Several variants of these holsters come with Retractors (indicated below) (see page 12). Retractors are load rated for 0.7 kg (1.5 lbs).
- Single and dual tool holsters feature Beacon High-Visibility Reflectors and the Quick-Mag Magnetic Tool Staging System.
- A bottom drain vent allows the holster to perform even in wet conditions.

Part #	Description	Retractors included	Attachment
1500103	Single Tool Holster	None	Harness
1500104	Single Tool Holster with Retractor	1x	Harness
1500101	Single Tool Holster	None	Belt
1500102	Single Tool Holster with Retractor	1x	Belt
1500105	Extra-Deep Single Tool Holster	None	Belt
1500108	Dual Tool Holster	None	Harness
1500109	Dual Tool Holster with Retractors	2x	Harness
1500106	Dual Tool Holster	None	Belt
1500107	Dual Tool Holster with Retractors	2x	Belt

3M™ DBI-SALA® Tape Measure Holsters

- Designed to be used with virtually any tape measure, or the optional tape measure sleeve, allowing tape measures to be safely tethered and holstered.
- Includes a Retractor (see page 12).
- The tape measure sleeve conforms to the size of nearly every tape measure.
- Features Beacon™ High-Visibility Reflectors.



Part #	Description
1500098	Tape Measure Holster with Retractor
1500099	Tape Measure Sleeve
1500165	Large Tape Measure Sleeve
1500100	Tape Measure Holster with Retractor and Sleeve Combo

3M™ DBI-SALA® Pouch Holster with Retractor

- Holster for tape measures and other small tools.
- Includes a retractor (see page 12).



Part #	Description
1500095	Pouch Holster with Retractor

3M™ DBI-SALA® Scaffold Wrench Holster with Retractor

- Quickly holster scaffold wrenches while working at height.
- Features Beacon High-Visibility Reflectors.



Back of holster features pouch for Safety Retractor (see page 12). Rear feed system allows retractor to tie off a scaffold wrench while staying out of the way.

Part #	Description
1500096	Scaffold Wrench Holster with Retractor
1500097	Scaffold Wrench Holster with Retractor and Hook2Loop Bungee Tether

3M™ DBI-SALA® Hammer Holster

- The Hammer Holster allows for the safe holstering of virtually any hammer under 2.3 kg (5 lbs).
- D-ring on the side of the holster is load rated for 2.3 kg (5 lbs).
- The 1500094 combo comes with a 1500066 Hook2Quick Ring Coil Tether (see page 11) that is specially designed for use with the Hammer Holster. The Hook2Quick Ring Coil Tether is load rated for 0.9 kg (2 lbs).
- During transport, the Hammer Holster can be locked shut with a hook and loop strap. While being used, the strap can be locked up allowing for easy hammer access and holstering.



Top: Hammer Holster is locked, preventing hammer from slipping out.
Bottom: Hammer Holster is unlocked, making it suitable for active use.

Part #	Description
1500093	Hammer Holster
1500094	Hammer Holster & Hook2Quick Ring Coil Tether

3M™ DBI-SALA® Adjustable Radio Holster

- Holster adjusts to fit virtually any hand-held radio, mobile phone, and many other devices.
- Can be worn from belt or harness.
- A Micro D-ring (see page 8) can be placed on the back of a device, and can then be tethered to a D-ring on the front of the Adjustable Radio Holster using a 1500066 Clip2Loop Coil Tether (see page 11).



Can be worn from a belt or harness.

Part #	Description
1500088	Adjustable Radio Holster
1500089	Adjustable Radio Holster, Clip2Loop Coil Tether and Micro D-ring

3M™ DBI-SALA® Spray Can/Bottle Holster

- Flexible neoprene holster allows for quick tethering of bottles and spray cans.
- 1500092 comes with 1500059 Clip2Clip Coil Tether (see page 11).



Part #	Description
1500091	Spray Can/Bottle Holster
1500092	Spray Can/Bottle Holster and Clip2Clip Coil Tether

3M™ DBI-SALA® Battery Holster/Sleeve

- Unique sleeve design conforms to the size of virtually any drill battery.
- Sleeve is cinched to the drill, allowing the drill to be tethered off while being used at height.

Part #	Quantity	Load rating
1500090	1	4.5 kg (10 lbs)



3M™ DBI-SALA® Comfort Tool Belt

- Extra padding provides superior comfort compared to many other tool belts.
- Modular approach allows user to customise their own holster and pouch system.

Part #	Waist size	Size
1500110	71 cm-91 cm (28"-36")	S-M
1500111	91 cm-112 cm (36"-44")	L-XL
1500112	112 cm-132 cm (44"-52")	2XL-3XL



3M™ DBI-SALA® Utility Tool Belt

- Padded Cordura provides for durability and comfort.

Part #	Waist size	Size
1500113	71 cm-117 cm (28"-46")	S-L
1500114	102 cm-137 cm (40"-54")	XL-3XL



3M™ DBI-SALA® Belt Loops

- 1500116 is used for tying off tools from a belt, while the 1500118 is used for staging tools.

Part #	Description	Load rating	Quantity
1500116	Belt loop D-ring	3.2 kg (5 lbs)	10
1500118	Belt loop trigger	3.2 kg (5 lbs)	10



3M™ DBI-SALA® Small Parts Pouches



1500123 1500121 1500120 1500122 1500119

- Innovative self-closure system traps objects inside, making it nearly impossible for objects to fall out once placed in the bag.
- Easy to retrieve objects since no opening or closing is necessary.
- Compatible with most tool belts.

Part #	Description
1500122	Small Parts Pouch, vinyl yellow
1500119	Small Parts Pouch, canvas black
1500120	Small Parts Pouch, canvas camo
1500121	Small Parts Pouch, canvas orange
1500123	Small Parts Pouch, extra deep canvas black



Belt loops located on back of pouch.



The Small Parts Pouch is designed for small parts such as nuts, bolts, screws and nails.



Items are placed inside the pouch, at which point they are immediately secured by the self-closure system.



Even when the pouch is flipped vertically, the pouch traps objects inside, making it nearly impossible for them to fall out.

3M™ DBI-SALA® Utility Pouch

- Features two outside pockets for storing spud wrenches and two inner pockets for storing additional tools.
- Tools can be tethered to D-rings on the inside and outside of the pouch.
- Adjustable side-release closure system helps prevent objects from falling out when the pouch isn't being used.

Part #	Description
1500132	Utility Pouch



3M™ DBI-SALA® Inspection Pouch

- Designed for the safe transport and use of most multi-meters, air monitors, and other portable testing devices.
- A unique adjustable opening can be used to create a hands-free workstation off the hip or chest.
- Can be worn off a belt, or over the shoulder using the included shoulder strap.

Part #	Description
1500131	Inspection Pouch



Hands-free workstation from belt or shoulder.

3M™ DBI-SALA® Tool Pouches

- Constructed from a heavy-duty canvas with an inner lining to help prevent punctures.
- Multiple inner pockets accommodate a number of tools while an integrated D-ring makes tethering tools incredibly easy.
- Available in standard and extra-deep variations.
- The standard pouch uses a hook and loop closure system that can be locked open during use.
- The extra-deep Tool Pouch features a magnetic closure system as well as a side-release buckle.

Part #	Width	Height	Retractors/triggers
1500124	19.1 cm (7.5")	27.9 cm (11")	-
1500125	19.1 cm (7.5")	27.9 cm (11")	2 retractors
1500126	19.1 cm (7.5")	27.9 cm (11")	2 triggers
1500127	22.2 cm (8.75")	33 cm (13")	-
1500128	22.2 cm (8.75")	33 cm (13")	2 retractors
1500129	22.2 cm (8.75")	33 cm (13")	2 triggers



3M™ DBI-SALA® Safe Buckets

With an integrated closure system that helps prevent dropped objects, our Safe Buckets are designed to be the perfect companion for workers at height carrying heavy loads.

Closure systems

Every Safe Bucket features either a unique drawstring or a locking hook and loop closure system that acts as an extra layer of spill-protection during transport and lifting. Colourful indicator tabs provide quick visual cues to indicate whether the bucket is in lockdown mode or easy-access mode.



Built-in connection points

The Safe Bucket was engineered for use with tools at height, and includes multiple connection points for tethering.

High-quality canvas and vinyl

Safe Buckets are available in both heavy-duty canvas and vinyl variants that are load rated for 45.4 kg (100 lbs) and 113.4 kg (250 lbs) respectively.



1500134



1500140

Standard Safe Bucket models

<http://bit.ly/2C9vsqY>

Integrated carabiner and hoisting strap

Instead of rope, which is susceptible to fraying, a heavy-duty hoisting/shoulder strap is built into every Safe Bucket. Each bucket is also equipped with a high-quality and lightweight aluminium twist-lock carabiner load rated for 30 kN (6,700 lbs). There is no need to worry about a knot failing, or a non-locking carabiner which may slip off at a connection point.



Puncture resistance

Where you work, durability is non-negotiable. That's why every Safe Bucket features hard composite plating at the bottom to protect it from accidental punctures. A leather sleeve also covers the inserts, protecting them from the elements and harsh work environments.

Part #	Load rating	Closure system	Body material	Height/diameter	Capacity
1500134	45.4 kg (100 lbs)	Hook and loop	Canvas	38 cm / 31.75 cm (15" / 12.5")	30 L
1500133	45.4 kg (100 lbs)	Drawstring	Canvas	38 cm / 31.75 cm (15" / 12.5")	30 L
1500140	113.4 kg (250 lbs)	Hook and loop	Vinyl	38 cm / 31.75 cm (15" / 12.5")	30 L
1500139	113.4 kg (250 lbs)	Drawstring	Vinyl	38 cm / 31.75 cm (15" / 12.5")	30 L

3M™ DBI-SALA® Hard-Body Safe Bucket Insert

- Converts a standard soft-body Safe Bucket into a hard-body Safe Bucket.
- Our reusable hard-body Safe Bucket insert keeps your Safe Bucket standing upright, making it easier to stage tools and stay productive.
- Integrated inner pockets allow tools to be holstered and organised quickly.

Part #	Description
1500141	Hard-Body Safe Bucket Insert



3M™ DBI-SALA® 5 Gallon Safe Bucket

- Used to transport standard 5 gallon buckets.
- 5 gallon plastic buckets clip into the Safe Bucket with a unique hook system.
- When not being used, the Safe Bucket can be flattened for easy storage.
- Unique locking hook and loop closure system helps ensure that there are no accidental spills during lifting and transportation.



Plastic bucket not included.

Part #	Load rating
1500135	45.4 kg (100 lbs)

3M™ DBI-SALA® Long Safe Buckets

- Transport scaffolding and longer tools safely and easily with our Long Safe Buckets.
- More effective than hand-to-hand transportation or using rope with hitch knots.
- Hook and loop top closure system keeps poles secure during lift.
- Equipped with a double twist-action locking carabiner for maximum safety.

Part #	Length	Closure system	Load rating
1500136	122 cm (48")	Hook and loop	45.4 kg (100 lbs)
1500137	183 cm (72")	Hook and loop	45.4 kg (100 lbs)
1500138	305 cm (120")	Hook and loop	45.4 kg (100 lbs)



1500136

3M™ DBI-SALA® Pullaway Wristbands

Pullaway wristbands are designed for those who work around rotating or moving equipment. They feature an elastic strap to conform to the wearer's wrist size automatically and come in standard and slim variants.

Part #	Description	Quantity	Load rating
1500071	Pullaway Wristband, small	10	2.3 kg (5 lbs)
1500073	Pullaway Wristband, medium	10	2.3 kg (5 lbs)
1500075	Pullaway Wristband, large	10	2.3 kg (5 lbs)
1500077	Pullaway Wristband, small (slim)	10	2.3 kg (5 lbs)
1500079	Pullaway Wristband, medium (slim)	10	2.3 kg (5 lbs)
1500081	Pullaway Wristband, large (slim)	10	2.3 kg (5 lbs)



Pullaway Wristband Slim Pullaway Wristband

3M™ DBI-SALA® Adjustable Wristbands



Adjustable Wristband

Our adjustable wristband uses a hook and loop system to adjust to any wrist size. An elastic band helps ensure a comfortable fit.



Adjustable Wristband with Cord

Adjusts to any wrist size using a hook and loop system. A built-in cord is used to quickly attach and stage tools directly to the wristband.



Adjustable Wristband with Retractor

Adjusts to any wrist size. A built-in retractor with an attached trigger can be used to quickly work with many hand tools.

Part #	Description	Quantity	Load rating
1500083	Adjustable Wristband	10	2.3 kg (5 lbs)
1500085	Adjustable Wristband with Cord	10	2.3 kg (5 lbs)
1500087	Adjustable Wristband with Retractor	10	2.3 kg (5 lbs)





Fall Protection
for Tools

3M Fall Protection

Capital Safety (Northern Europe) Limited

3M Centre, Cain Road
Bracknell, Berkshire, RG12 8HT, UK

Capital Safety Group (EMEA)

Le Broc Center, Bâtiment A, Z.1. 1re Avenue – BP15
06511 Carros Le Broc, Cedex, FRANCE

Phone +33 (0)4 83 58 08 08 Email informationfallprotection@mmm.com Web 3M.com/

#3MScienceOfSafety

3M is a trademark of 3M Company. DBI-SALA® is a trademark of D B Industries, LLC.

Registered address: 3M Centre, Cain Road, Bracknell, Berkshire, RG12 8HT. Registered in England and Wales No. 1918922.

Please recycle.

©3M 2019. All rights reserved.