



N-117
N-119

LCD Drawer & KVM Benefits

- ▶ Multi-user Matrix KVM with either 16 or 32 ports in 1U
- ▶ Cost efficient Combo KVM integration
- ▶ "One Man" installation slides for easy, quick installation
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Secure remote user access across the world wide web

Drawer Features & Options

- 1U rackmount drawer with either 17" or 19" LCD
- Combo interface either PS/2 or USB input to the LCD drawer
- Multiple keyboard language selections with either touchpad or trackball
- Slide rails with fixed positions to prevent drawer movement when typing
- Enhanced aesthetics with new molded front panel and two point lock

Options

DVI-D



 
Audio



BNC + S-Video



DC Power



Monitor



Grade A 17", 19" industrial TFT LCD panel

1280 x 1024 max. resolution


250 cd/m² brightness

1000 : 1 contrast ratio


170° x 160° viewing angle (H / V)

Diagram


Unit : mm

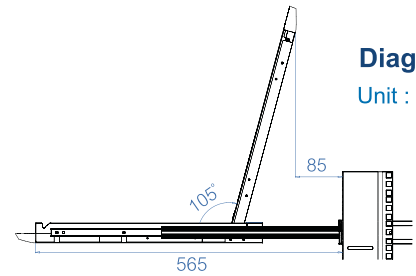


Ne N keyboard integrated with touchpad

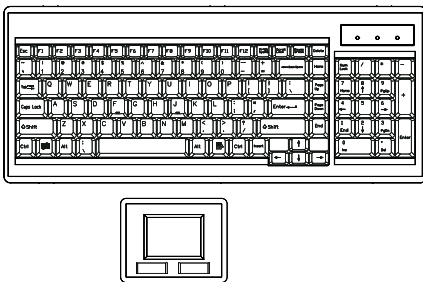

Nb N keyboard integrated with trackball

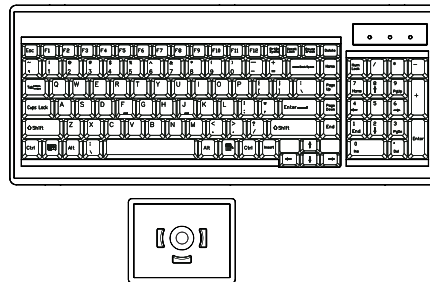

Supporting layouts

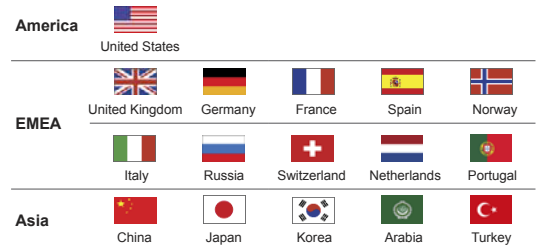

Dimensions

Model	Product Dimension (W x D x H)	Packing Dimension (W x D x H)	Net Weight	Gross Weight
N-117	441.6 x 650 x 44.3 mm 17.4 x 25.6 x 1.74 inch	595 x 860 x 140 mm 23.4 x 33.9 x 5.5 inch	13 kg 29 lb	19 kg 42 lb
N-119	441.6 x 650 x 44.3 mm 17.4 x 25.6 x 1.74 inch	595 x 860 x 140 mm 23.4 x 33.9 x 5.5 inch	13 kg 29 lb	19 kg 42 lb

! The weight is only for the single console models. It varies with accessories & options such as KVM, DVI-D, AV, audio & DC power.

Base Model

17" LCD

19" LCD

<ul style="list-style-type: none"> • Combo interface • without KVM 	N-117	N-119
--	-------	-------

KVM Integration

back



X stands for the 2nd digit of 17" and 19" LCD size.

7 = 17"

9 = 19"

Matrix Cat6 KVM



www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MUKVM-KIT.pdf

Console	Local	Remote	IP	8-port	16-port	32-port
IP	1	1	1	-	N11X - MUIP1613	N11X - MUIP3213
IP IP	1	1	2	-	N11X - MUIP1624	N11X - MUIP3224
	1	1	0	-	N11X - MUIP1602	N11X - MUIP3202
	1	2	0	-	N11X - MUIP1603	N11X - MUIP3203
	1	3	0	-	N11X - MUIP1604	N11X - MUIP3204


Combo Cat6 KVM



www.austin-hughes.com/support/usermanual/cyberview/UM-CV-UKVM-KIT.pdf

Console	Local	Remote	IP	8-port	16-port	32-port
IP	1	0	1	N11X - UIP802	N11X - UIP1602	N11X - UIP3202
	1	1	0	N11X - U802	N11X - U1602	N11X - U3202
	1	0	0	N11X - U801	N11X - U1601	N11X - U3201

 
Matrix DB-15 KVM



www.austin-hughes.com/support/usermanual/cyberview/UM-CV-MKVM-KIT.pdf

Console	Local	Remote	IP	8-port	16-port	32-port
IP	1	1	1	N11X - MIP813	N11X - MIP1613	-
IP IP	1	1	2	N11X - MIP824	N11X - MIP1624	-
	1	1	0	N11X - MIP802	N11X - MIP1602	-
	1	2	0	N11X - MIP803	N11X - MIP1603	-
	1	3	0	N11X - MIP804	N11X - MIP1604	-

 Combo DB-15 KVM



www.austin-hughes.com/support/usermanual/cyberview/UM-CV-SKVM-KIT.pdf

Console	Local	Remote	IP	8-port	16-port	32-port
IP	1	0	1	N11X - IP802	N11X - IP1602	-
	1	1	0	N11X - 802	N11X - 1602	-
	1	0	0	N11X - S801	N11X - S1601	-

PS/2 DB-15 KVM



www.austin-hughes.com/support/usermanual/cyberview/UM-CV-PS2KVM-KIT.pdf

Console	Local	Remote	IP	4-port	8-port	16-port
	1	0	0	-	N11X - 801	-