

Modular Patch Cords

	Blue	Gray	White	Black	Green	Yellow
10GX Patch Cord, Bonded-Pair, 4-pair, 24 AWG Solid, T568A/B-T568A/B, CMR						
4 ft (1.2 m)	CA21106004	CA21108004	CA21109004	CA21100004	CA21105004	CA21104004
7 ft (2.1 m)	CA21106007	CA21108007	CA21109007	CA21100007	CA21105007	CA21104007
10 ft (3.0 m)	CA21106010	CA21108010	CA21109010	CA21100010	CA21105007	CA21104007
xxx	CA21106xxx	CA21108xxx	CA21109xxx	CA21100xxx	CA21105xxx	CA21104xxx
CAT6+ Patch Cord, Bonded-Pair, 4-pair, 24 AWG Solid, T568A/B-T568A/B, CMR						
4 ft (1.2 m)	C601106004	C601108004	C601109004	C601100004	C601105004	C601104004
7 ft (2.1 m)	C601106007	C601108007	C601109007	C601100007	C601105007	C601104007
10 ft (3.0 m)	C601106010	C601108010	C601109010	C601100010	C601105007	C601104007
xxx	C601106xxx	C601108xxx	C601109xxx	C601100xxx	C601105xxx	C601104xxx
CAT5E Patch Cord, Bonded-Pair, 4-pair, 24 AWG Solid, T568A/B-T568A/B, CMR						
4 ft (1.2 m)	C501106004	C501108004	C501109004	C501100004	C501105004	C501104004
7 ft (2.1 m)	C501106007	C501108007	C501109007	C501100007	C501105007	C501104007
10 ft (3.0 m)	C501106010	C501108010	C501109010	C501100010	C501105007	C501104007
xxx	C501106xxx	C501108xxx	C501109xxx	C501100xxx	C501105xxx	C501104xxx

10GX, CAT6+ and CAT5E patch cords available in 1 ft to 100 ft in increment of 1ft, 105 ft to 250 ft in increments of 5 ft. Other standard colors available.

Small OD patch cords are available in 10GX and Cat6. Refer to catalog for available colors and part numbers.

Traceable Patch Cords

	Blue	Gray	White	Black	Green	Yellow
10GX Traceable Patch Cord, Bonded-Pair, 4-Pair, 24 AWG Solid, T568A/B-T568A/B, CMR						
4 ft (1.2 m)	CAT1106004	CAT1108004	CAT1109004	CAT1100004	CAT1105004	CAT1104004
7 ft (2.1 m)	CAT1106007	CAT1108007	CAT1109007	CAT1100007	CAT1105007	CAT1104007
10 ft (3.0 m)	CAT1106010	CAT1108010	CAT1109010	CAT1100010	CAT1105007	CAT1104007
xxx	CAT1106xxx	CAT1108xxx	CAT1109xxx	CAT1100xxx	CAT1105xxx	CAT1104xxx
CAT6+ Traceable Patch Cord, Bonded-Pair, 4-Pair, 24 AWG Solid, T568A/B-T568A/B, CMR						
4 ft (1.2 m)	C6T1106004	C6T1108004	C6T1109004	C6T1100004	C6T1105004	C6T1104004
7 ft (2.1 m)	C6T1106007	C6T1108007	C6T1109007	C6T1100007	C6T1105007	C6T1104007
10 ft (3.0 m)	C6T1106010	C6T1108010	C6T1109010	C6T1100010	C6T1105007	C6T1104007
xxx	C6T1106xxx	C6T1108xxx	C6T1109xxx	C6T1100xxx	C6T1105xxx	C6T1104xxx

Traceable patch cords available in 1 ft to 100 ft in increment of 1ft, 105 ft to 250 ft in increments of 5 ft. Other standard colors available.

REVConnect Modular Connectors

	10GX	CAT6+	CAT5E
Gray	RVAMJKUGY-S1	RV6MJKUGY-S1	RV5MJKUGY-S1
Almond	RVAMJKUAL-S1	RV6MJKUAL-S1	RV5MJKUAL-S1
Electrical White	RVAMJKUEW-S1	RV6MJKUEW-S1	RV5MJKUEW-S1
Black	RVAMJKUBK-S1	RV6MJKUBK-S1	RV5MJKUBK-S1
Ivory	RVAMJKUIV-S1	RV6MJKUIV-S1	RV5MJKUIV-S1
Orange	RVAMJKUOR-S1	RV6MJKUOR-S1	RV5MJKUOR-S1
Red	RVAMJKURD-S1	RV6MJKURD-S1	RV5MJKURD-S1
Yellow	RVAMJKUYL-S1	RV6MJKUYL-S1	RV5MJKUYL-S1
Green	RVAMJKUGN-S1	RV6MJKUGN-S1	RV5MJKUGN-S1
Blue	RVAMJKUBL-S1	RV6MJKUBL-S1	RV5MJKUBL-S1
Purple	RVAMJKUPR-S1	RV6MJKUPR-S1	RV5MJKUPR-S1
Brown	RVAMJKUBN-S1	RV6MJKUBN-S1	RV5MJKUBN-S1
Orange, TIA 606	RVAMJKUTO-S1	RV6MJKUTO-S1	RV5MJKUTO-S1
Red, TIA 606	RVAMJKUTR-S1	RV6MJKUTR-S1	RV5MJKUTR-S1
Yellow, TIA 606	RVAMJKUTY-S1	RV6MJKUTY-S1	RV5MJKUTY-S1
Green, TIA 606	RVAMJKUTG-S1	RV6MJKUTG-S1	RV5MJKUTG-S1
Blue, TIA 606	RVAMJKUTB-S1	RV6MJKUTB-S1	RV5MJKUTB-S1
Purple, TIA 606	RVAMJKUTP-S1	RV6MJKUTP-S1	RV5MJKUTP-S1
Brown, TIA 606	RVAMJKUTN-S1	RV6MJKUTN-S1	RV5MJKUTN-S1
Shielded Jack	RVAMJKSME-S1	RV6MJKSME-S1	RV5MJKSME-S1
UTP Plug	RVAFPUBK-S1	-	-
STP Plug	RVAFPSME-S1	-	-

Single packs shown. All parts available in bulk packaging of 24 jacks (replace S1 with B24).

Category Cable

Category 6A	
625 MHz CMR, Small OD	10GXS12
625 MHz CMP, Small OD	10GXS13
625 MHz CMR, Shielded	10GX52F
625 MHz CMP, Shielded	10GX53F
Category 6	
600 MHz CMR	4812
600 MHz CMP	4813
400 MHz CMR	3612
400 MHz CMP	3613
350 MHz CMR	2412
350 MHz CMP	2413
350 MHz CMR, Shielded	2412F
350 MHz CMP, Shielded	2413F
Category 5e	
350 MHz CMR	1212
350 MHz CMP	1213
200 MHz CMR	1583A
200 MHz CMP	1585A
350 MHz CMR, Shielded	1212F
350 MHz CMP, Shielded	1213F

Refer to catalog for colour and put-up codes.

Mohawk Cable*

Category 6 cable	White	Blue
250 MHz 6LAN CMR	M58291	M58292
250 MHz 6LAN CMP	M58280	M58281
Category 5e cable	White	Blue
100 MHz 5eLAN CMR	M57554	M57553
100 MHz 5eLAN CMP	M57547	M57546

* Minimum Swept Frequencies

REVConnect Preloaded Patch Panels

Category 6A	Black Panels	White Panels
10GX REVConnect Patch Panel 24-port, 1U (Preloaded)	RVAPPF1U24BK	RVAPPF1U24WH
10GX REVConnect Patch Panel 48-port, 2U (Preloaded)	RVAPPF2U48BK	RVAPPF2U48WH
10GX REVConnect Angled Patch Panel 24-port, 1U (Preloaded)	RVAPPA1U24BK	RVAPPA1U24WH
10GX REVConnect Angled Patch Panel 48-port, 2U (Preloaded)	RVAPPA2U48BK	RVAPPA2U48WH
Category 6		
CAT6+ REVConnect Patch Panel 24-port, 1U (Preloaded)	RV6PPF1U24BK	RV6PPF1U24WH
CAT6+ REVConnect Patch Panel 48-port, 2U (Preloaded)	RV6PPF2U48BK	RV6PPF2U48WH
CAT6+ REVConnect Angled Patch Panel 24-port, 1U (Preloaded)	RV6PPA1U24BK	RV6PPA1U24WH
CAT6+ REVConnect Angled Patch Panel 48-port, 2U (Preloaded)	RV6PPA2U48BK	RV6PPA2U48WH
Category 5e		
CAT5E REVConnect Patch Panel 24-port, 1U (Preloaded)	RV5PPF1U24BK	RV5PPF1U24WH
CAT5E REVConnect Patch Panel 48-port, 2U (Preloaded)	RV5PPF2U48BK	RV5PPF2U48WH
CAT5E REVConnect Angled Patch Panel 24-port, 1U (Preloaded)	RV5PPA1U24BK	RV5PPA1U24WH
CAT5E REVConnect Angled Patch Panel 48-port, 2U (Preloaded)	RV5PPA2U48BK	RV5PPA2U48WH

Questions?

Contact your local Belden representative, call us at 1.800.BELDEN.1 (1.800.235.3361) or visit www.belden.com

KeyConnect Modular Jacks



	10GX	CAT6+	CAT5E
Gray	AX102280	AX101318*	AX101307*
Almond	AX102281	AX101319*	AX101308*
Electrical White	AX102282	AX101320*	AX101309*
Black	AX102283	AX101321*	AX101310*
Ivory	AX103073	AX103076*	AX103079*
Orange	AX104152	AX104189*	AX104182*
Red	AX104153	AX104190*	AX104183*
Yellow	AX104154	AX104191*	AX104184*
Green	AX104155	AX104192*	AX104185*
Blue	AX104156	AX104193*	AX104186*
Purple	AX104157	AX104194*	AX104187*
Brown	AX104158	AX104195*	AX104188*
Orange, TIA 606	AX102284	AX101322	AX101311
Red, TIA 606	AX102285	AX101323	AX101312
Yellow, TIA 606	AX102286	AX101324	AX101313
Green, TIA 606	AX102287	AX101325	AX101314
Blue, TIA 606	AX102288	AX101326	AX101315
Purple, TIA 606	AX102289	AX101327	AX101316
Brown, TIA 606	AX102290	AX101328	AX101317
Shielded Jack	AX104562	AX104596	AX104595
CAT6+ Shielded KeyConnect Modular Jack, Metallic		AX104596	

*Also available in bulk packaging (add -B24 after the part number)

MDVO Modular Jacks



	10 GX	CAT6+	CAT5E
Gray	AX102269	AX101063	AX101044
Almond	AX102270	AX101064	AX101045
White	AX102271	AX101065	AX101046
Black	AX102272	AX101066	AX101047
Ivory	AX102562	AX102563	AX102564
Orange, TIA 606	AX102273	AX101067	AX101048
Red, TIA 606	AX102274	AX101068	AX101049
Yellow, TIA 606	AX102275	AX101069	AX101050
Green, TIA 606	AX102276	AX101070	AX101051
Blue, TIA 606	AX102277	AX101071	AX101052
Purple, TIA 606	AX102278	AX101072	AX101053
Brown, TIA 606	AX102279	AX101073	AX101054

Tools

BIX Connecting Tool	A0270165
110 Connecting Tool	AX100749
KeyConnect Rapid Termination Tool	AX105566
REVConnect Universal Termination Tool	RVUTT01



Work Station Outlets

(REVConnect Compatible with KeyConnect)

	KeyConnect	MDVO
1-port Faceplate	AX102660	A0405257
2-port Faceplate	AX102655	AX101433
4-port Faceplate	AX102249	AX101437
6-port Faceplate	AX102251	AX101441
4-port decora Adapter	AX106575-EW	A0409653 (3-port)
4-port 106 Adapter	AX104124	AX100310
4-port mod. furn. Adapter	AX102900	AX100927
2-port Side-Entry Box	AX105353-EW	A0645273
4-port Side-Entry Box	AX105354-EW	—

Part numbers are either Electric White or White.
For other colors, please refer to catalog.

KeyConnect Modular Patch Panels (Empty)

KeyConnect Modular Patch Panels (RevConnect Compatible)	
24-port, 1U, Black (Empty)	AX103114
48-port, 2U, Black (Empty)	AX103115
48-port, 1U, Black (Empty)	AX103121
KeyConnect AngleFlex Modular Patch Panels	
24-Port, 1U, Angled, Black (Empty)	AX103248
48-Port, 2U, Angled, Black (Empty)	AX103249
KeyConnect Angled Modular Patch Panels	
24-port, 1U, Black (Empty)	AX104599
48-port, 2U, Black (Empty)	AX104601
48-port, 1U, Black (Empty)	AX104600




Preloaded Patch Panels (KeyConnect, HD-110, HD-BIX)

10GX KeyConnect Patch Panels	
24-Port, 1U, Titanium (Preloaded)	AX103254
48-port, 2U, Titanium (Preloaded)	AX103256
48-Port, 1U, Titanium (Preloaded)	AX103264
CAT6+ KeyConnect Patch Panels	
24-Port, 1U, Black (Preloaded)	AX103253
48-Port, 2U, Black (Preloaded)	AX103255
CAT6+ HD Patch Panels	
24-port, 1U, Black (Preloaded) HD-110	AX105520
48-port, 2U, Black (Preloaded) HD-110	AX105521
CAT5E KeyConnect Patch Panels	
24-port, 1U, Black (Preloaded)	AX104013
48-port, 2U, Black (Preloaded)	AX104014
CAT5E HD Patch Panels	
24-Port, 1U, Black (Preloaded) HD-BIX	AX103260
48-Port, 2U, Black (Preloaded) HD-BIX	AX103261



MDVO Patch Panels (Empty)

Flex Patch Panel, 24-port, 1U, Black (Empty)	AX101456
Flex Patch Panel, 48-port, 2U, Black (Empty)	AX101458

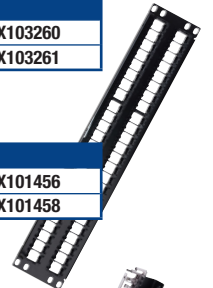

GigaBIX IDC System

GigaBIX Termination Kits	
GigaBIX Termination Kit, 72-port	AX101470
GigaBIX Termination Kit, 300-pair	AX101471
GigaBIX Rack Mount Termination Kit, 48-port	AX101985
GigaBIX Connecting Components	
GigaBIX Connector, 6-port	AX101447
GigaBIX Connector, 25-pair	AX101448
GigaBIX Mount, 12-connector	AX101472
GigaBIX Rack Mount Panel, 48-port, 3U, Empty	AX101986
GigaBIX Wire Guard	AX101486
GigaBIX Designation Strip	AX101483
GigaBIX Termination Bar	AX101719
GigaBIX Cable Management Accessories	
GigaBIX Cable Management Module	AX101469
GigaBIX Patch Cord Organizer	AX101468
GigaBIX Patch Cord Organizer, Cover	AX101521
GigaBIX Horizontal Channel Plate	AX101520
GigaBIX Management Ring	AX101478



BIX IDC System

BIX Mounts and Accessories	
BIX Mount, QMBIX10A, 250-pair	A0270164
BIX Distribution Ring	A0270168
BIX Designation Strip	A0270169
Distribution Connector	
BIX Distribution Connector, 5-pair Marking	A0266828
BIX Distribution Connector, 4-pair Marking	A0393146

