


LEVITON SDX PLATFORM | FIBER OPTIC ENCLOSURES, ADAPTER PLATES, AND ACCESSORIES

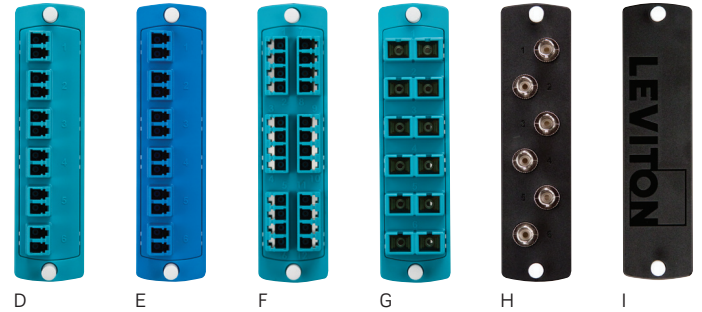

2000i SDX RACK-MOUNT ENCLOSURES	PART NO.
[A] 1RU, empty, sliding tray, accepts 3 adapter plates	5R1UH-S03
2RU, empty, sliding tray, accepts 6 adapter plates	5R2UH-S06
4RU, empty, sliding tray, accepts 12 adapter plates	5R4UH-S12


1000I SDX RACK-MOUNT ENCLOSURES	PART NO.
[B] 1RU, empty, accepts 3 adapter plates	5R1UM-F03
1RU, empty, with sliding tray, accepts 3 adapter plates	5R1UM-S03
2RU, empty, accepts 6 adapter plates	5R2UM-F06
2RU, empty, with sliding tray, accepts 6 adapter plates	5R2UM-S06
3RU, empty, accepts 9 adapter plates	5R3UM-F09
4RU, empty, accepts 12 adapter plates	5R4UM-F12

500I SDX RACK-MOUNT ENCLOSURES	PART NO.
[C] 1RU, empty, accepts 3 adapter plates	5R1UL-F03
2RU, empty, accepts 6 adapter plates	5R2UL-F06
3RU, empty, accepts 12 adapter plates	5R3UL-F12

SDX MOLDED ADAPTER PLATES WITH ZIRCONIA CERAMIC SLEEVE	PART NO.
[D] Plate (aqua), 50 μm LOMM (OM3 and OM4) Duplex LC, 12-fiber	5F100-2QL
[E] Plate (blue), SM (OS2), Duplex LC, 12-fiber	5F100-2LL
[F] Plate (aqua), 50 μm LOMM (OM3 and OM4) Quad LC, 24-fiber	5F100-4QL
Plate (blue), SM (OS2), Quad LC, 24-fiber	5F100-4LL
Plate (aqua), 50 μm LOMM (OM3 and OM4), Duplex SC, 6-fiber	5F100-6QC
Plate (blue), SM (OS2), Duplex SC, 6-fiber	5F100-6LC
[G] Plate (aqua), 50 μm LOMM (OM3 and OM4), Duplex SC, 12-fiber	5F100-2QC
Plate (blue), SM (OS2), Duplex SC, 12-fiber	5F100-2LC
[H] Plate (black), ST MM/SM, 6-fiber	5F100-6MT
Plate (black), ST MM/SM, 8-fiber	5F100-8MT
[I] Plate (black), Blank	5F100-PLT


ACCESSORIES	PART NO.
Universal Clamp Kit (for enclosure mounting), single cable grommet	5RCMP-KIT
Universal Clamp Kit (for enclosure mounting), multiple cable grommet	5RCMP-KT2
Universal Clamp Kit, Single and Multiple Cable Grommet (for rack mounting)	5RCMR-KIT
Patch Cord Management Tray, 1RU	5R1UX-CMT
Patch Cord Management Tray, 2RU	5R2UX-CMT
Patch Cord Management, 0RU (bag of 2)	5RCMT-VFG

LEVITON FIBER OPTIC CONNECTORS

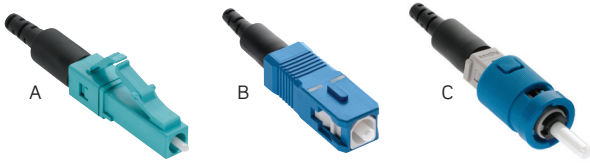

FASTCAM® PRE-POLISHED STYLE	OM3/4 50µm LOMM	OS2 SM
[A] LC	49991-LLC	49991-SLC
[B] SC	49991-LSC	49991-SSC
[C] ST	N/A	49991-SST

All FastCAM connectors require a precision cleaver and a tool kit.

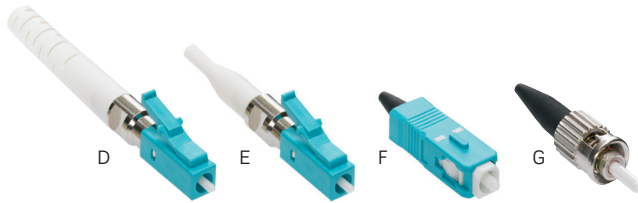


FAST-CURE® ADHESIVE STYLE	OM3/4 50µm LOMM	OS2 SM
[D] LC (with 3mm boot)	49990-LL2	49990-SL2
[E] LC (with .9mm boot)	49990-LDL	49990-SDL
[F] SC	49990-LSC	49990-SSC
[G] ST	N/A	49990-SST

LEVITON FIBER OPTIC FAN KITS AND SPLICE TRAYS




	PART NO.
[A] Fan-Out Kit 24" Length, 12-Fiber	49887-12S
Fan-Out Kit 36" Length, 12-Fiber	49887-12L
[B] 12-Fiber Mini, 3.74" x 5.59" x .39" (Heat Shrink Splice Sleeves Included)	T5PLS-12F
[C] 24-Fiber High Density, 4.5" x 7.63" x .43" (Heat Shrink Splice Sleeves Included)	T5PLS-24F
Splice Tray Mounting Hardware Kit	SPLMT-HKT

LEVITON ECONOMY SERIES FIBER OPTIC PIGTAILS (3 METERS)

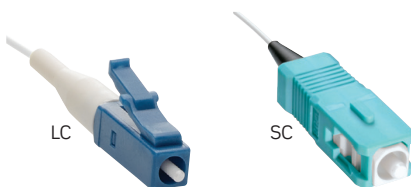

	OM3	OM4	OS2
LC, Individual Pigtailed	5LPLC-M03	54PLC-M03	UPPLC-S03
LC, 12-Fiber Color-Coded Pigtail Kit	5LPLC-KIT	54PLC-KIT	UPPLC-KIT
SC, Individual Pigtailed	5LPSC-M03	54PSC-M03	UPPSC-S03
SC, 12-Fiber Color-Coded Pigtail Kit	5LPSC-KIT	54PSC-KIT	UPPSC-KIT
ST, Individual Pigtailed	5LPST-M03	N/A	UPPST-S03
ST, 12-Fiber Color-Coded Pigtail Kit	N/A	N/A	UPPST-KIT

LEVITON ECONOMY SERIES FIBER OPTIC DUPLEX PATCH CORDS

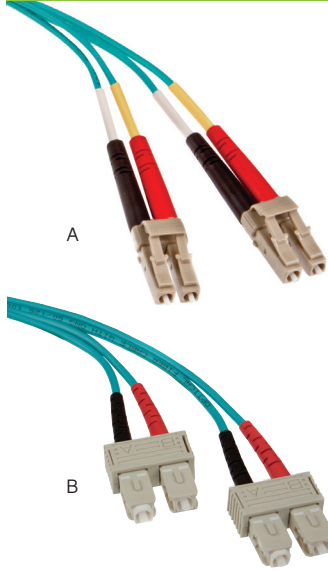

	OM3*	OM4*	OS2*
[A] LC-LC, 1 meter	5LDLC-M01	54DLC-M01	UPDLC-S01
LC-LC, 2 meter	5LDLC-M02	54DLC-M02	UPDLC-S02
LC-LC, 3 meter	5LDLC-M03	54DLC-M03	UPDLC-S03
LC-LC, 5 meter	5LDLC-M05	54DLC-M05	UPDLC-S05
LC-LC, 10 meter	5LDLC-M10	54DLC-M10	UPDLC-S10
[B] SC-SC, 1 meter	5LDSC-M01	54DSC-M01	UPDSC-S01
SC-SC, 2 meter	5LDSC-M02	54DSC-M02	UPDSC-S02
SC-SC, 3 meter	5LDSC-M03	54DSC-M03	UPDSC-S03
SC-SC, 5 meter	5LDSC-M05	54DSC-M05	UPDSC-S05
SC-SC, 10 meter	5LDSC-M10	54DSC-M10	UPDSC-S10

*OM3 = 50/125 μm Laser-Optimized Multimode, OM4 = 50/125 μm Laser-Optimized Multimode, OS2 = Single-Mode
 Note: For ordering Premium Series Patch Cords, go to Leviton.com/Configurator

BERK-TEK PREMISE DISTRIBUTION CABLE, TIGHT BUFFER, PLENUM



	6 FIBER	12 FIBER	24 FIBER
OM3	PDP006EB3010/25	PDP012EB3010/25	PDP024EB3010/25
OM4	PDP006FB3010/F5	PDP012FB3010/F5	PDP024FB3010/F5
OS2	PDP006AB0707	PDP012AB0707	PDP024AB0707

BERK-TEK ARMORED, PREMISE DISTRIBUTION, TIGHT BUFFER, PLENUM



	6 FIBER	12 FIBER	24 FIBER
OM3	PDPK006EB3010/25	PDPK012EB3010/25	PDPK024EB3010/25
OM4	PDPK006FB3010/F5*	PDPK012FB3010/F5	PDPK024FB3010/F5
OS2	PDPK006AB0707	PDPK012AB0707	PDPK024AB0707

* = Make-to-Order Item, 1640 foot minimum quantity order

BERK-TEK INDOOR/OUTDOOR, PREMISE DISTRIBUTION, TIGHT BUFFER, PLENUM



	6 FIBER	12 FIBER	24 FIBER
OM3	PDP006EB3010/25-I/O-C4(AQU)	PDP012EB3010/25-I/O-C4(AQU)	PDP024EB3010/25-I/O-C4(AQU)
OM4	PDP006FB3010/F5-I/O-C4(AQU)	PDP012FB3010/F5-I/O(AQU)	PDP024FB3010/F5-I/O-C4(AQU)*
OS2	PDP006AB0707-I/O-C4(YEL)	PDP012AB0707-I/O-C4(YEL)	PDP024AB0707-I/O-C4(YEL)

* = Make-to-Order Item, 1640 foot minimum quantity order

BERK-TEK ARMORED INDOOR/OUTDOOR, PREMISE DISTRIBUTION, TIGHT BUFFER, PLENUM



	6 FIBER	12 FIBER	24 FIBER
OM3	PDPK006EB3010/25-I/O-C4C5(AQU)	PDPK012EB3010/25-I/O-C4C5(AQU)	PDPK024EB3010/25-I/O-C4C5(AQU)
OM4	PDPK006FB3010/F5-I/O-C4C5(AQU)*	PDPK012FB3010/F5-I/O-C4C5(AQU)*	PDPK024FB3010/F5-I/O-C4C5(AQU)*
OS2	PDPK006AB0707-I/O-C4C5(YEL)	PDPK012AB0707-I/O-C4C5(YEL)	PDPK024AB0707-I/O-C4C5(YEL)

* = Make-to-Order Item, 1640 foot minimum quantity order



Build your high-performance networks with Berk-Tek and Leviton, two of the most innovative, reliable, and service-oriented names in the industry. With the combined strength of Berk-Tek cable and Leviton connectivity you get the best end-to-end copper and fiber solutions available.

For a complete collection of all Berk-Tek and Leviton Network Solutions products, visit BerkTek.com, Leviton.com, or BerkTekLevitonTechnologies.com.