

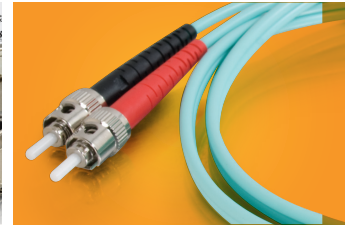
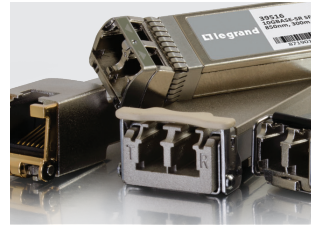


NETWORKING/ DATACOMM

QUICK PRODUCT FINDER

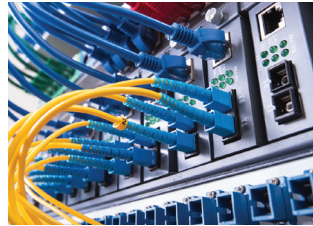

SIMPLIFIED CONNECTIVITY

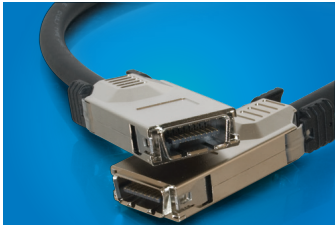

It's Our Expertise & Solutions, It's Your Experience... It's Who We Are

Simplified Connectivity is more than just designing and manufacturing easy-to-use and easy-to-install connectivity products. It's the expertise of the people that provide technical and sales support. It's the confidence in knowing that the products and solutions you buy from C2G are tried and tested by people like yourself every day. It's the planning and thoughtfulness that goes into creating the kind of user expertise that our customers want and expect. Simplified Connectivity is about people, products, and performance — C2G is leading the competition in all three.

TECHNICAL EXPERTISE



C2G supports our customers with FREE technical and sales support on all of our products. All of our technical experts have been thoroughly trained on C2G products, typical applications, and many have earned industry-recognized certifications in specific fields of technology. In addition to our people, C2G's website is an endless portal of technical information for everyone — from a first-time user to a veteran installer.

STRAIGHT FORWARD SOLUTIONS



C2G products are designed to be easy-to-use and easy-to-install. We create products based on customer feedback, and we stay akin to where the IT and A/V industries are going in the next five years. We strive to create solutions that meet or exceed customer expectations.

EFFORTLESS EXPERIENCE



The effortless experience is defined by you, our customers, and C2G is constantly changing and adapting in order to meet your product and service demands. When you email, text, call, or live chat, you are speaking to a C2G employee that is literally surrounded by product managers, technical support experts, a finance team, and peer sales representatives. Our goal is to make doing business with C2G easy, regardless of the way you choose to interact with us.

Products and Solutions of Simplified Connectivity

C2G product solutions fit effortlessly into the spaces where you work, share, and connect. Our products go into the data centers that power the networks you rely on, connect the personal devices you use throughout the day, and make your work spaces highly productive and efficient.




CISCO® TRANSCEIVERS

SKU	Item Description	OEM Equivalent
89116	Cisco DS-SFP-FC8G-SW Compatible 2/4/8GBS Fibre Channel SW MMF SFP+ Transceiver Module	DS-SFP-FC8G-SW
89069	Cisco GLC-BX-D Compatible 1000BASE-BX SMF SFP (Mini-GBIC) Transceiver Module	GLC-BX-D
89068	Cisco GLC-BX-U Compatible 1000BASE-BX SMF SFP (Mini-GBIC) Transceiver Module	GLC-BX-U
88604	Cisco GLC-EX-SMD Compatible 1000BASE-EX SMF SFP (Mini-GBIC) Transceiver Module	GLC-EX-SMD
89076	Cisco GLC-FE-100FX Compatible 100BASE-FX MMF SFP (Mini-GBIC) Transceiver Module	GLC-FE-100FX
88605	Cisco GLC-FE-100FX-RGD Compatible 100BASE-FX MMF SFP (Mini-GBIC) Transceiver Module	GLC-FE-100FX-RGD
89123	Cisco GLC-FE-100LX Compatible 100BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	GLC-FE-100LX
89054	Cisco GLC-GE-100FX Compatible 100BASE-FX MMF SFP (Mini-GBIC) Transceiver Module	GLC-GE-100FX
88608	Cisco GLC-LH-SMD Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	GLC-LH-SMD
88601	Cisco GLC-LX-SM-RGD Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	GLC-LX-SM-RGD
89058	Cisco GLC-SX-MM Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	GLC-SX-MM
88607	Cisco GLC-SX-MMD Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	GLC-SX-MMD
88609	Cisco GLC-SX-MM-RGD Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	GLC-SX-MM-RGD
89055	Cisco GLC-T Compatible 1000BASE-T Copper SFP (Mini-GBIC) Transceiver Module	GLC-T
89064	Cisco GLC-ZX-SM Compatible 1000BASE-ZX SMF SFP (Mini-GBIC) Transceiver Module	GLC-ZX-SM
89143	Cisco ONS-SI-GE-SX Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	ONS-SI-GE-SX
89129	Cisco QSFP-40G-SR4 Compatible 40GBASE-SR MMF QSFP+ Transceiver Module	QSFP-40G-SR4
89128	Cisco SFP-10G-ER Compatible 10GBASE-ER SMF SFP+ Transceiver Module	SFP-10G-ER



88610

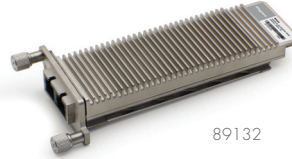

89132



89072

CISCO® TRANSCEIVERS (CONTINUED)

SKU	Item Description	OEM Equivalent
89071	Cisco SFP-10G-LR Compatible 10GBASE-LR SMF SFP+ Transceiver Module	SFP-10G-LR
89072	Cisco SFP-10G-LRM Compatible 10GBASE-LRM MMF SFP+ Transceiver Module	SFP-10G-LRM
89070	Cisco SFP-10G-SR Compatible 10GBASE-SR MMF SFP+ Transceiver Module	SFP-10G-SR
89119	Cisco SFP-1GB-SX Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	SFP-1GB-SX
88602	Cisco SFP-GE-L Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	SFP-GE-L
89108	Cisco SFP-GE-S Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	SFP-GE-S
88610	Cisco SFP-GE-T Compatible 1000BASE-T Copper SFP (Mini-GBIC) Transceiver Module	SFP-GE-T
89115	Cisco WS-G5483 Compatible 1000BASE-TX COPPER GBIC Transceiver Module	WS-G5483
89074	Cisco WS-G5484 Compatible 1000BASE-SX MMF SC GBIC Transceiver Module	WS-G5484
89138	Cisco WS-G5486 Compatible 1000BASE-LX SMF GBIC Transceiver Module	WS-G5486
89104	Cisco X2-10GB-LR Compatible 10GBASE-LR SMF X2 Transceiver Module	X2-10GB-LR
89073	Cisco X2-10GB-SR Compatible 10GBASE-SR MMF X2 Transceiver Module	X2-10GB-SR
89132	Cisco XENPAK-10GB-SR Compatible 10GBASE-SR MMF XENPAK Transceiver Module	XENPAK-10GB-SR
89100	Cisco XFP10GLR-192SR-L Compatible 10GBASE-LR SMF XFP Transceiver Module	XFP10GLR-192SR-L
89133	Cisco XFP-10G-MM-SR Compatible 10GBASE-SR MMF XFP Transceiver Module	XFP-10G-MM-SR



89083



89101

JUNIPER NETWORKS® TRANSCEIVERS

SKU	Item Description	OEM Equivalent
89083	Juniper Networks EX-SFP-10GE-LR Compatible 10GBASE-LR SMF SFP+ Transceiver Module	EX-SFP-10GE-LR
89082	Juniper Networks EX-SFP-10GE-SR Compatible 10GBASE-SR MMF SFP+ Transceiver Module	EX-SFP-10GE-SR
89081	Juniper Networks EX-SFP-1GE-LX Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	EX-SFP-1GE-LX
89080	Juniper Networks EX-SFP-1GE-SX Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	SFP-1GE-SX
89103	Juniper Networks EX-SFP-1GE-T Compatible 1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	EX-SFP-1GE-T
89101	Juniper Networks EX-XFP-10GE-LR Compatible 10GBASE-LR SMF XFP Transceiver Module	EX-XFP-10GE-LR
89107	Juniper Networks SFP-1GE-FE-E-T Compatible 10/100/1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	SFP-1GE-FE-E-T
89079	Juniper Networks SFP-1GE-LX Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	SFP-1GE-LX
89078	Juniper Networks SFP-1GE-T Compatible 1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	SFP-1GE-T
89120	Juniper Networks XFP-10G-S Compatible 10GBASE-SR MMF XFP Transceiver Module	XFP-10G-S

HP® TRANSCEIVERS

SKU	Item Description	OEM Equivalent
89145	HP 3CSFP91 Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	3CSFP91
89142	HP 453154-B21 Compatible 1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	453154-B21
89109	HP 455883-B21 Compatible 10GBASE-SR MMF SFP+ Transceiver Module	455883-B21
89137	HP AJ716A Compatible 2/4/8GBS Fibre Channel SW MMF SFP+ Transceiver Module	AJ716A
89085	HP J4858C Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	J4858C
89089	HP J4859C Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	J4859C
89134	HP J4860C Compatible 1000BASE-ZX SMF SFP (Mini-GBIC) Transceiver Module	J4860C
89087	HP J8177C Compatible 1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	J8177C
89061	HP J9054C Compatible 100BASE-FX MMF SFP (Mini-GBIC) Transceiver Module	GLC-LH-SM
89135	HP J9054C Compatible 100BASE-FX MMF SFP (Mini-GBIC) Transceiver Module	J9054C
89091	HP J9150A Compatible 10GBASE-SR MMF SFP+ Transceiver Module	J9150A
89093	HP J9151A Compatible 10GBASE-LR SMF SFP+ Transceiver Module	J9151A
89088	HP JD089B Compatible 1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	JD089B
89092	HP JD092B Compatible 10GBASE-SR MMF SFP+ Transceiver Module	JD092B
89094	HP JD094B Compatible 10GBASE-LR SMF SFP+ Transceiver Module	JD094B
89084	HP JD118B Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	JD118B
89090	HP JD119B Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	JD119B
89086	HP JD493A Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	JD493A

BROCADE® TRANSCEIVERS

SKU	Item Description	OEM Equivalent
89112	Brocade 10G-SFP+ SR Compatible 10GBASE-SR MMF SFP+ Transceiver Module	10G-SFP+ SR
89144	Brocade E1MG-LX-OM Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	E1MG-LX-OM
88603	Brocade E1MG-SX-OM Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	E1MG-SX-OM
89125	Brocade E1MG-TX Compatible 1000BASE-TX COPPER SFP (Mini-GBIC) Transceiver Module	E1MG-TX



89141

FINISAR® TRANSCEIVERS

SKU	Item Description	OEM Equivalent
89141	Finisar FCLF-8521-3 Compatible 1000BASE-TX COPPER SFP (Mini-GBIC) Transceiver Module	FCLF-8521-3
89126	Finisar FTLF8519P2BNL Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	FTLF8519P2BNL
89124	Finisar FTLF8524P2BNL Compatible 1/2/4GBS Fibre Channel SW MMF SFP (Mini-GBIC) Transceiver Module	FTLF8524P2BNL
89114	Finisar FTLF8524P2BNV Compatible 1/2/4GBS Fibre Channel SW MMF SFP (Mini-GBIC) Transceiver Module	FTLF8524P2BNV
89113	Finisar FTLF8528P2BCV Compatible 2/4/8GBS Fibre Channel SW MMF SFP+ Transceiver Module	FTLF8528P2BCV
89110	Finisar FTLX1471D3BCL Compatible 10GBASE-LR SMF SFP+ Transceiver Module	FTLX1471D3BCL
89102	Finisar FTLX8571D3BCL Compatible 10GBASE-SR MMF SFP+ Transceiver Module	FTLX8571D3BCL
89122	Finisar FTLX8571D3BCV Compatible 10GBASE-SR MMF SFP+ Transceiver Module	FTLX8571D3BCV



89117



88606

OTHER TRANSCEIVERS

SKU	Item Description	OEM Equivalent
89127	MSA Compliant 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	N/A
89130	MSA Compliant 40GBASE-SR MMF QSFP+ Transceiver Module	N/A
89099	MSA Standard Compliant 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	N/A
89095	Netgear® AGM731F Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	AGM731F
89105	Intel® E10GSFSPSR Compatible 10GBASE-SR MMF SFP+ Transceiver Module	E10GSFSPSR
89097	Force10® GP-XFP-1S Compatible 10GBASE-SR MMF XFP Transceiver Module	GP-XFP-1S
89140	Enterasys® MGBIC-LC03 Compatible 1000BASE-MX MMF SFP (Mini-GBIC) Transceiver Module	MGBIC-LC03
89121	Extreme Networks® 10301 Compatible 10GBASE-SR MMF SFP+ Transceiver Module	10301
89098	3COM® 3CSFP92 Compatible 1000BASE-LX SMF SFP (Mini-GBIC) Transceiver Module	3CSFP92
89131	Arista Networks® AR-SFP-10G-LR Compatible 10GBASE-LR SMF SFP+ Transceiver Module	AR-SFP-10G-LR
89096	Arista Networks® AR-SFP-10G-SR Compatible 10GBASE-SR MMF SFP+ Transceiver Module	AR-SFP-10G-SR
89117	Arista Networks® AR-SFP-1G-T Compatible 1000BASE-TX Copper SFP (Mini-GBIC) Transceiver Module	AR-SFP-1G-T
89146	Avaya®/Nortel® AA1419013-E5 Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	AA1419013-E5
88606	Avaya®/Nortel® AA1419048-E6 Compatible 1000BASE-SX MMF SFP (Mini-GBIC) Transceiver Module	AA1419048-E6

NETWORKING/DATACOMM

Cat5e Booted Unshielded (UTP) Network Patch Cables



83220

LENGTH	GREY	BLUE	BLACK	WHITE	RED	YELLOW	GREEN	ORANGE	PINK	PURPLE	BROWN
0.3m	83139	83159	83179	83259	—	—	—	—	—	—	—
0.5m	83140	83160	83180	83260	83220	83240	83200	83602	83616	83658	83672
1m	83141	83161	83181	83261	83221	83241	83201	83603	83617	83659	83673
1.5m	83142	83162	83182	83262	83222	83242	83202	83604	83618	83660	83674
2m	83143	83163	83183	83263	83223	83243	83203	83605	83619	83661	83675
3m	83144	83164	83184	83264	83224	83244	83204	83606	83620	83662	83676
5m	83145	83165	83185	83265	83225	83245	83205	83607	83621	83663	83677
7m	83146	83166	83186	83266	83226	83246	83206	83608	83622	83664	83678
10m	83147	83167	83187	83267	83227	83247	83207	83609	83623	83665	83679
15m	83148	83168	83188	83268	—	—	—	—	—	—	—
20m	83149	83169	83189	83269	—	—	—	—	—	—	—
30m	83150	83170	83190	83270	—	—	—	—	—	—	—
50m	83151	83171	—	—	—	—	—	—	—	—	—
100m	83152	83172	—	—	—	—	—	—	—	—	—

Cat5e Non-Booted Unshielded (UTP) Network Patch Cable

LENGTH	GREY	BLUE	BLACK	WHITE	RED	YELLOW	GREEN
0.5m	83000	83020	83040	83120	83080	83100	83060
1m	83001	83021	83041	83121	83081	83101	83061
1.5m	83002	83022	83042	83122	83082	83102	83062
2m	83003	83023	83043	83123	83083	83103	83063
3m	83004	83024	83044	83124	83084	83104	83064
5m	83005	83025	83045	83125	83085	83105	83065
7m	83006	83026	83046	83126	83086	83106	83066
10m	83007	83027	83047	83127	83087	83107	83067
15m	83008	83028	83048	—	—	—	—
20m	83009	83029	83049	—	—	—	—
30m	83010	83030	83050	—	—	—	—



83100



Cat5e Non-Booted Crossover Unshielded (UTP) Network Patch Cable

LENGTH	GREY	BLUE	BLACK	RED	YELLOW
0.5m	83280	83297	83314	83331	83348
1m	83281	83298	83315	83332	83349
1.5m	83282	83299	83316	83333	83350
2m	83283	83300	83317	83334	83351
3m	83284	83301	83318	83335	83352
5m	83285	83302	83319	83336	83353
7m	83286	83303	83320	83337	83354



83314





83770

LENGTH	GREY	BLUE	BLACK	WHITE	RED	YELLOW	GREEN
1m	83750	83770	83850	83880	83790	83810	83830
2m	83751	83771	83851	83881	83791	83811	83831
3m	83752	83772	83852	83882	83792	83812	83832
4m	83753	83773	83853	83883	83793	83813	83833
5m	83754	83774	83854	83884	83794	83814	83834
7m	83755	83775	83855	83885	83795	83815	83835
10m	83761	83781	83860	83886	83800	83821	83840
15m	83756	83776	83856	83887	83796	83816	83836
20m	83757	83777	83857	83888	—	—	—
30m	83758	83778	83858	83889	—	—	—
50m	83759	83779	83859	83890	—	—	—
100m	83760	83780	—	—	—	—	—

NETWORKING/DATACOMM

Cat6 Non-Booted Patch Cables



83396

LENGTH	GREY	BLUE	BLACK	WHITE	RED	YELLOW	GREEN	ORANGE	PINK	PURPLE	BROWN
0.3m	83364	83384	83404	83484	—	—	—	—	—	—	—
0.5m	83365	83385	83405	83485	83445	83465	83425	83573	83587	83630	83644
1m	83366	83386	83406	83486	83446	83466	83426	83574	83588	83631	83645
1.5m	83367	83387	83407	83487	83447	83467	83427	83575	83589	83632	83646
2m	83368	83388	83408	83488	83448	83468	83428	83576	83590	83633	83647
3m	83369	83389	83409	83489	83449	83469	83429	83577	83591	83634	83648
5m	83370	83390	83410	83490	83450	83470	83430	83578	83592	83635	83649
7m	83371	83391	83411	83491	83451	83471	83431	83579	83593	83636	83650
10m	83372	83392	83412	83492	83452	83472	83432	83580	83594	83637	83651
15m	83373	83393	83413	83493	—	—	—	—	—	—	—
20m	83374	83394	83414	83494	—	—	—	—	—	—	—
30m	83375	83395	83415	83495	—	—	—	—	—	—	—
50m	83376	83396	—	—	—	—	—	—	—	—	—
100m	83377	83397	—	—	—	—	—	—	—	—	—

Cat6a Booted Shielded (STP) Network Patch Cable

LENGTH	GREY	BLUE	BLACK	WHITE
0.3m	89921	89926	89931	89933
0.5m	89900	89907	89914	89934
1m	89901	89908	89915	89935
1.5m	89902	89909	89916	89936
2m	89903	89910	89917	89937
3m	89904	89911	89918	89938
5m	89905	89912	89919	89939
7m	89906	89913	89920	89940
10m	89922	89927	89932	89941
15m	89923	89928	—	—
20m	89924	89929	—	—
30m	89925	89930	—	—



89921

Cat6 Booted Crossover Unshielded (UTP) Network Patch Cable


LENGTH	GREY	BLUE	BLACK	RED
0.5m	83505	83522	83539	83556
1m	83506	83523	83540	83557
1.5m	83507	83524	83541	83558
2m	83508	83525	83542	83559
3m	83509	83526	83543	83560
5m	83510	83527	83544	83561
7m	83511	83528	83545	83562



83404

62.5/125 OM1 Duplex Multimode PVC Fibre Optic Cable (LSZH) – Orange

LENGTH	ST ST	SC SC	SC ST	LC SC	LC ST	LC LC
1m	85207	85239	85223	85255	85271	85287
2m	85208	85240	85224	85256	85272	85288
3m	85209	85241	85225	85257	85273	85289
5m	85210	85242	85226	85258	85274	85290
7m	85211	85243	85227	85259	85275	85291
10m	85212	85244	85228	85260	85276	85292
15m	85450	85453	85456	85459	85462	85465
20m	85451	85454	85457	85460	85463	85466
30m	85452	85455	85458	85461	85464	85467

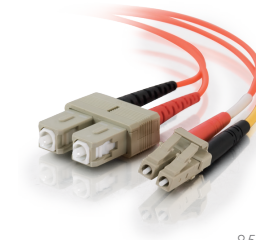

85255

50/125 OM2 Duplex Multimode PVC Fibre Optic Cable (LSZH) – Orange


LENGTH	ST ST	SC SC	SC ST	LC SC	LC ST	LC LC
1m	85468	85303	85480	85319	85492	85335
2m	85469	85304	85481	85320	85493	85336
3m	85470	85305	85482	85321	85494	85337
5m	85471	85306	85483	85322	85495	85338
7m	85472	85307	85484	85323	85496	85339
10m	85473	85308	85485	85324	85497	85340
15m	85474	85477	85486	85489	85498	85501
20m	85475	85478	85487	85490	85499	85502
30m	85476	85479	85488	85491	85500	85503



85492

10Gb 50/125 OM3 Duplex Multimode PVC Fibre Optic Cable (LSZH) – Aqua


LENGTH	ST ST	SC SC	SC ST	LC SC	LC ST	LC LC
1m	85504	85513	85522	85531	85540	85549
2m	85505	85514	85523	85532	85541	85550
3m	85506	85515	85524	85533	85542	85551
5m	85507	85516	85525	85534	85543	85552
7m	85508	85517	85526	85535	85544	85553
10m	85509	85518	85527	85536	85545	85554
15m	85510	85519	85528	85537	85546	85555
20m	85511	85520	85529	85538	85547	85556
30M	85512	85521	85530	85539	85548	85557
50M	–	–	–	–	–	85558

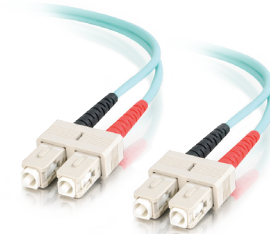

85255

9/125 OS1 Duplex Singlemode PVC Fibre Optic Cable (LSZH) – Yellow


LENGTH	ST ST	SC SC	SC ST	LC SC	LC ST	LC LC
1m	85559	85568	85577	85586	85595	85604
2m	85560	85569	85578	85587	85596	85605
3m	85561	85570	85579	85588	85597	85606
5m	85562	85571	85580	85589	85598	85607
7m	85563	85572	85581	85590	85599	85608
10m	85564	85573	85582	85591	85600	85609
15m	85565	85574	85583	85592	85601	85610
20m	85566	85575	85584	85593	85602	85611
30m	85567	85576	85585	85594	85603	85612

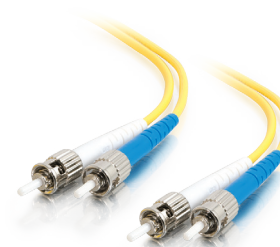

85492

NETWORKING/DATACOMM

COMING SOON! – Direct Attach Cables (DAC)

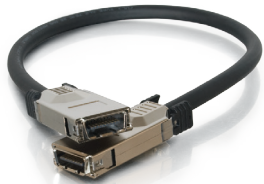

A brand of  legrand®



Great King Street North
Birmingham, West Midlands B19 2LF
www.c2g.com
UK Phone (0)800 328 2916
EMEA Phone +44 (0)1952 677300

Follow Us

