



STRUCTURED MEDIA™ CENTERS

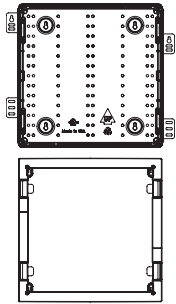

14" Series

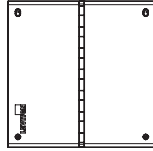


NEW 14" Plastic Series Wireless Structured Media Center (14" x 14.26" x 3.42")


Enclosure with Vented Cover	49605-140
Enclosure with Vented Hinged Door	49605-14P
Enclosure Only	49605-14E
Vented Hinged Door	49605-14S
Enclosure, Bulk Pack of 12	49605-14G
Vented Hinged Door, Bulk Pack of 12	49605-14B
Vented Cover, Bulk Pack of 12	49605-14F
Trim Ring Accessory	49605-14T
Add-on Lock and Key	5L000-L0K

The 14" enclosure creates a single distribution point for all low voltage cables in an apartment, condo, or small home, accommodating basic residential networking systems and accessories.

Plastic construction allows for RF transparency, extending and improving Wi-Fi® coverage.

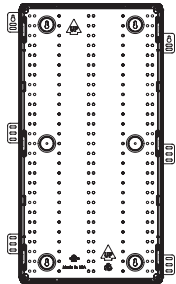

28" Series

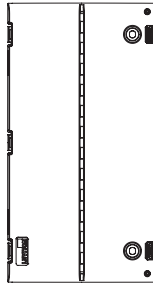


NEW 28" Plastic Series Wireless Structured Media Center (28" x 14.26" x 3.42")


Enclosure with Vented Cover	49605-28W
Enclosure with Vented Hinged Door	49605-28P
Enclosure Only	49605-28E
Vented Hinged Door	49605-28S
Enclosure, Bulk Pack of 6	49605-28G
Vented Hinged Door, Bulk Pack of 6	49605-28B
Vented Cover, Bulk Pack of 6	49605-28F
Trim Ring Accessory	49605-28T
Add-on Lock and Key	5L000-L0K

The 28" enclosure serves as command central for virtually all technology including home networking, Internet, satellite video, camera, VoIP, telephone, intercom, and audio. It is ideal for homes with more advanced multimedia needs and provides for future growth.

Plastic construction allows for RF transparency, extending and improving Wi-Fi coverage.

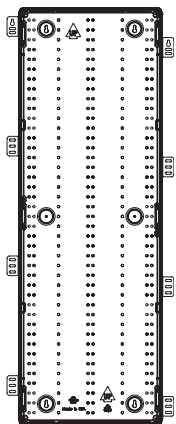

42" Series

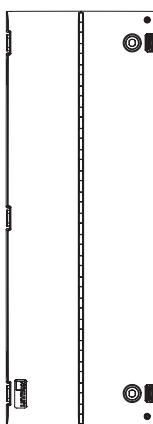


NEW 42" Plastic Series Wireless Structured Media Center (42" x 14.26" x 3.42")

Enclosure with Vented Hinged Door	49605-42P
Enclosure Only	49605-42E
Vented Hinged Door	49605-42S
Enclosure, Bulk Pack of 6	49605-42G
Vented Hinged Door, Bulk Pack of 6	49605-42B
Trim Ring Accessory	49605-42T
Add-on Lock and Key	5L000-L0K

The 42" enclosure is extra long to accommodate extensive voice, data, audio, and video equipment in larger homes or small businesses, and to provide maximum room for expansion. It accommodates a wide variety of modules for home networking, DSL, Internet, satellite video, camera, VoIP, multi-line telephones, intercom, audio distribution, and volume controls.

Plastic construction allows for RF transparency, extending and improving Wi-Fi coverage.

STRUCTURED MEDIA™ CENTERS

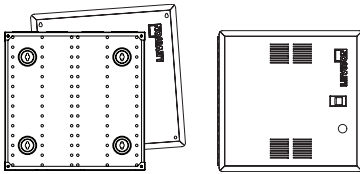


14" Series

14" Metal Series Structured Media Center (14" x 14.38" x 3.60")

Enclosure with Flush-Mount Cover	47605-140
Enclosure Only	47605-14E
Flush-Mount Cover	47605-14C
Enclosure, Bulk Pack of 6	47605-14G
Flush-Mount Cover, Bulk Pack of 6	47605-14B
Hinged Door	47605-14D
Premium Hinged Vented Door	47605-14S
Add-on Lock and Key	5L000-L0K

The 14" enclosure creates a single distribution point for all low voltage cables in an apartment, condo, or small home, accommodating basic residential networking systems and accessories.

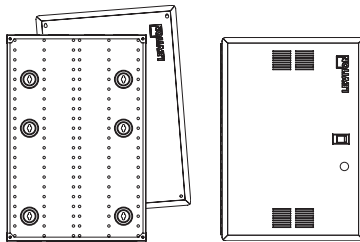


21" Series

21" Metal Series Structured Media Center (21.10" x 14.38" x 3.60")

Enclosure Only	47605-21E
Flush-Mount Cover	47605-21C
Premium Hinged Vented Door	47605-21S
Add-on Lock and Key	5L000-L0K

The 21" enclosure is ideal for voice, data, audio, and video distribution in condos and smaller homes, and provides additional room for larger modules and extra equipment.

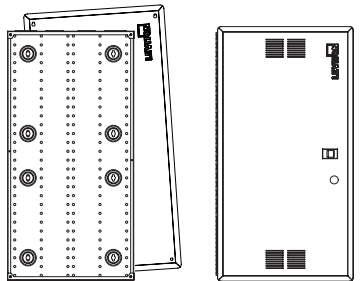


28" Series

28" Metal Series Structured Media Center (28" x 14.38" x 3.60")

Enclosure with Flush-Mount Cover	47605-28W
Enclosure Only	47605-28N
Flush-Mount Cover, Bulk Pack of 3	47605-28G
Enclosure, Bulk Pack of 3	47605-28B
Flush-Mount Cover	47605-F28
Hinged Door	47605-28D
Premium Hinged Vented Door	47605-28S
Add-on Lock and Key	5L000-L0K

The 28" enclosure serves as command central for virtually all technology including home networking, Internet, satellite video, camera, VoIP, telephone, intercom, and audio. It is ideal for homes with more advanced multimedia needs and provides for future growth.

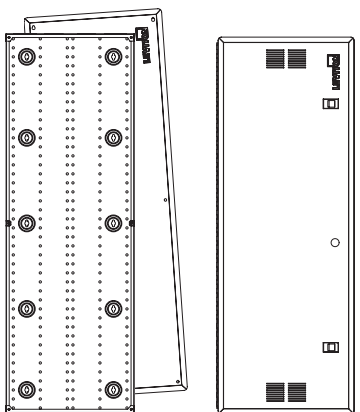


42" Series

42" Metal Series Structured Media Center (42" x 14.38" x 3.60")

Enclosure with Flush-Mount Cover	47605-42W
Enclosure Only	47605-42N
Flush-Mount Cover	47605-F42
Hinged Door	47605-42D
Premium Hinged Vented Door	47605-42S
Add-on Lock and Key	5L000-L0K

The 42" enclosure is extra long to accommodate extensive voice, data, audio, and video equipment in larger homes or small businesses, and to provide maximum room for expansion. It accommodates a wide variety of modules for home networking, DSL, Internet, satellite video, camera, VoIP, multi-line telephones, intercom, audio distribution, and volume controls.

STRUCTURED MEDIA™ CENTERS

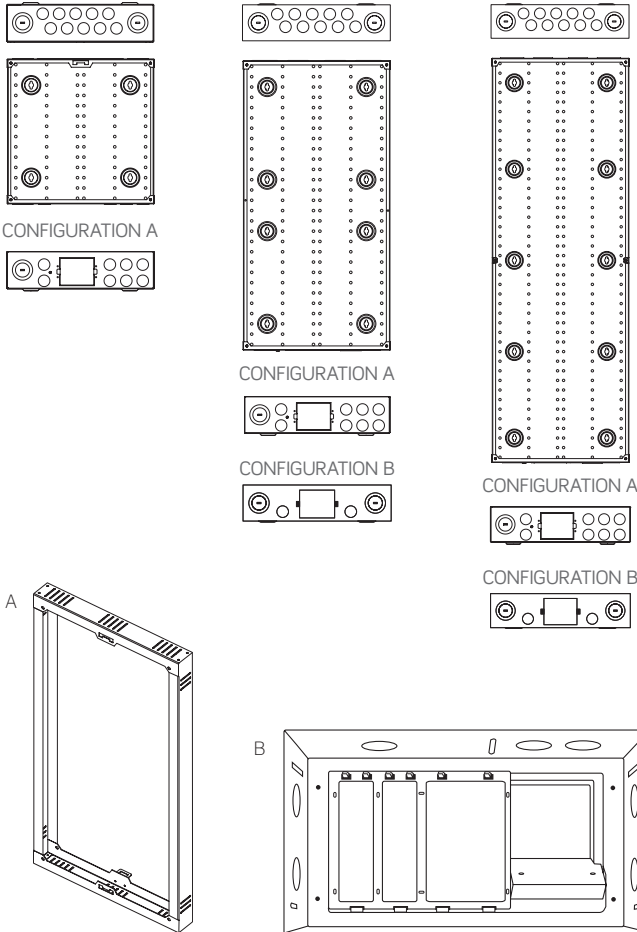

Multi-Dwelling Unit Structured Media Centers

14" Configuration A with flush-mount cover	47605-1MG
28" Configuration A with flush-mount cover	47605-2MG
42" Configuration A with flush-mount cover	47605-4MG
28" Configuration B enclosure only	47605-M28
42" Configuration B enclosure only	47605-M42

Multi-Bay Dual Enclosures

14" + 14" FTTH Multi-Bay Dual Enclosure	47FTH-440
28" + 14" FTTH Multi-Bay Dual Enclosure	47FTH-840

Extender Brackets


42" Structured Media Center Extender Bracket	47612-42B
[A] 28" Structured Media Center Extender Bracket	47612-28B

Compact Structured Media Centers for MDUs

[B] Compact Enclosure (Empty) and Cover (Shown)	47605-MDU
Compact Enclosure and Cover plus 1x6 Telephone Expansion Board	47604-0F6
Compact Enclosure and Cover plus 1x6 Telephone Expansion Board and 6-way Video Splitter	47604-F6S

SPOTLIGHT

Wireless Enclosure Connected Multi-Bay System

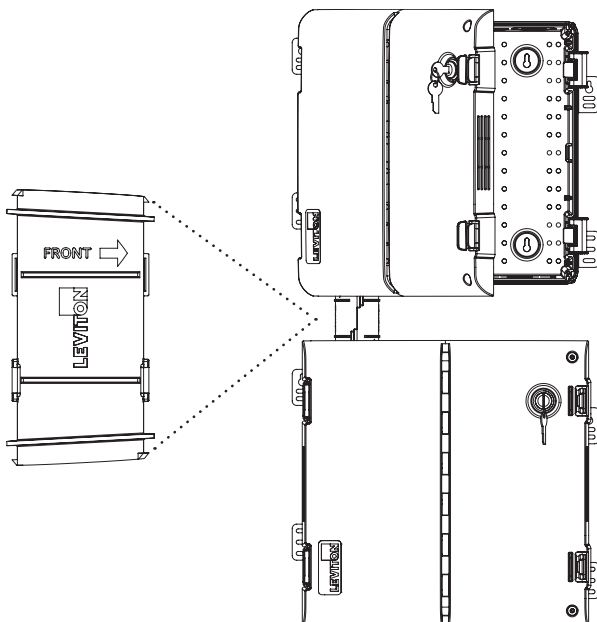


Use the easy-to-install Multi-Bay Attachment Tube between two or more Wireless Structured Media Center Enclosures to create a secure, fully isolated location for service provider equipment.

- Isolates service provider equipment from end-user connectivity and controls for better security.
- Heat separation and containment keeps equipment in both enclosures cooler and more efficient.
- Works with any size Wireless Structured Media Center. Include Lock and Key for added security on one or more of the connected enclosures.


Multi-Bay Attachment Tube	49605-TUB
14" Enclosure (order with Vented Cover, Vented Hinged Door, or Enclosure Only)	49605-14*
28" Enclosure (order with Vented Cover, Vented Hinged Door, or Enclosure Only)	49605-28*
42" Enclosure (order with Vented Cover, Vented Hinged Door, or Enclosure Only)	49605-42*
Add-on Lock and Key	5L000-LOK

* See page 1 for all wireless enclosure sizes, configurations and part numbers. Not compatible with other multi-bay enclosures.

PRE-CONFIGURED STRUCTURED CABLING PANELS

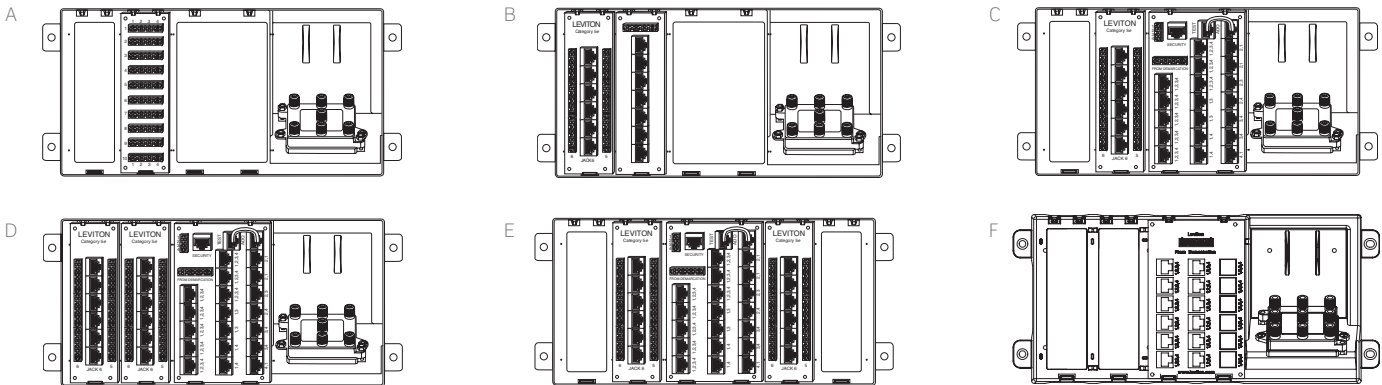


[A]	Basic Telephone and Video Panel	47606-BTV
[B]	Basic Home Networking Plus Panel	47606-BNP
[C]	Advanced Home Telephone and Video Panel	47606-AHT
[D]	Advanced Small Office Telephone and Video Panel	47606-ASO
[E]	12-Port Structured Media™ Panel	47603-12P
	18-Port Structured Media Panel	47603-18P
	24-Port Structured Media Panel	47603-24P
	4x18 Telephone Distribution Panel with Cat 5e Voice and Board	47603-8C1
[F]	4x12 Telephone Distribution Panel with 8-Way Splitter	47603-412
	4x18 Telephone Distribution Board on Shelf Bracket	47603-18M
	4x12 Telephone Distribution Board on Shelf Bracket	47603-12M

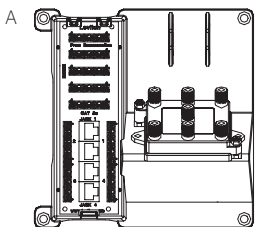

COMPACT SERIES PRE-CONFIGURED STRUCTURED CABLING PANEL


[A]	4 Telephone, 4 Data and 6-Way Video	47603-DP6
-----	-------------------------------------	-----------

LOW-PROFILE/HIGH-DENSITY INTERCONNECT PANELS

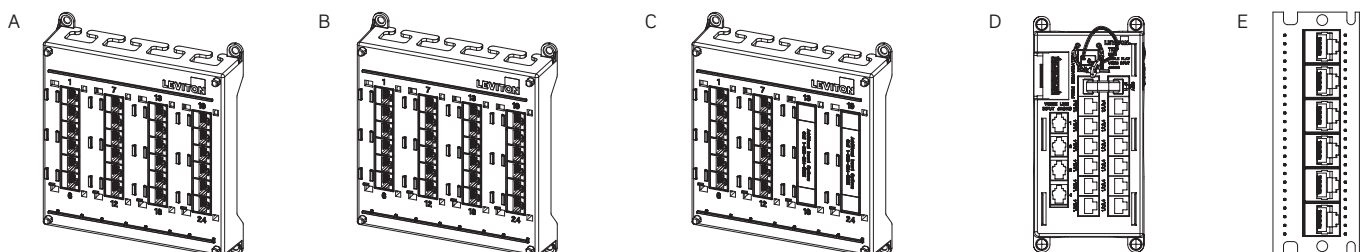

[A]	Cat 6/Cat 5e Twist and Mount Patch Panel, 12 Cat 6 and 12 Cat 5e connectors, cULus	476TM-654	[C]	Cat 6 Twist and Mount Patch Panel, 12 Cat 6 connectors, cULus	476TM-612
[B]	Cat 6 Twist and Mount Patch Panel, 24 Cat 6 connectors, cULus	476TM-624		Cat 5e Twist and Mount Patch Panel, 12 Cat 5e connectors, cULus	476TM-512
	Cat 5e Twist and Mount Patch Panel, 24 Cat 5e connectors, cULus	476TM-524	[D]	Telephone Input Distribution Panel (TIDP), cULus	476TL-T12
	Cat 6/Cat 5e Twist and Mount Patch Panel, 6 Cat 6 and 6 Cat 5e connectors, cULus	476TM-652	[E]	Cat 5e Twist and Mount Expansion Board	476TM-EX5
				Cat 6 Twist and Mount Expansion Board	476TM-EX6


MOUNTING BRACKETS FOR LEVITON STRUCTURED MEDIA™ CENTERS

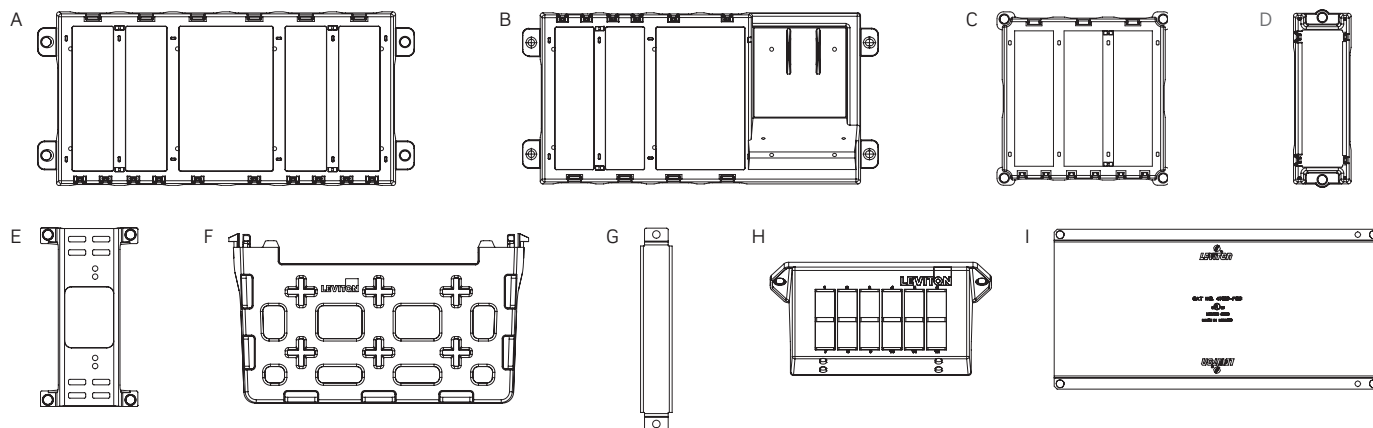

[A] Expansion Plastic Bracket	47612-EBK	Metal Universal Shelf Bracket	47612-UBK
[B] Shelf Plastic Bracket	47612-VSB	[G] 6" Universal Bracket (set of 2)	47612-6SB
[C] Plastic Half-Bracket	47612-HBK	12" Universal Bracket (set of 2)	47612-1SB
[D] Single Plastic Bracket	47612-SBK	[H] 12-Port QuickPort® Bracket (accepts 12 QuickPort Jacks)	47600-QPB
[E] Data Plastic Bracket	47612-DBK	[I] Full Width Universal Security Plate	47612-FSB
[F] Plastic Universal Shelf Bracket (includes (2) saddle-ties and 2 ½" of VELCRO® Softcinch, black)	49605-AUB	Half Width Universal Security Plate	47612-HSB






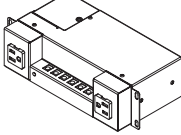
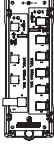
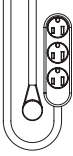
VELCRO® is a registered trademark of Velcro BVBA. Used with permission.

STAND-ALONE MODULES & EXPANSION BOARDS


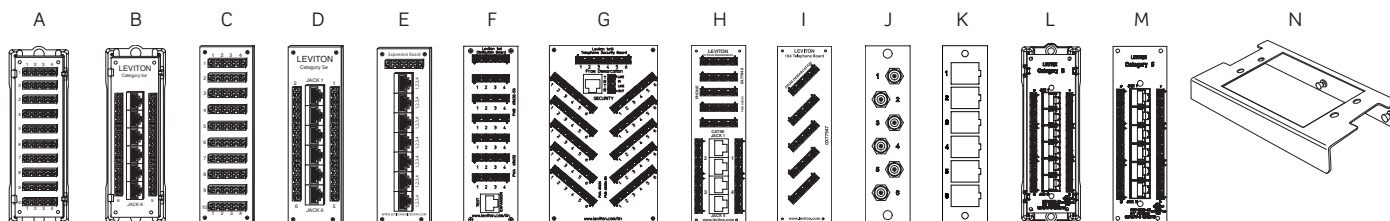


[A] 1x9 4-Line Bridged Telephone Module (stand alone)	47689-00B	[I] 1x4 Bridged Phone Board (expansion board)	47609-004
[B] Cat 5e Voice and Data Module (stand alone)	47605-C5B	[J] F-Connector Mounting Plate, 6-pack, loaded	5F100-6VF
[C] 1x9 4-Line Bridged Telephone Board (expansion board)	47603-110	[K] QuickPort® Mounting Plate, 6-pack, unloaded	5F100-6QP
[D] Cat 5e Voice and Data Board (expansion board)	47603-0C5	[L] Cat 6 Voice and Data Module (stand alone)	47611-C6B
[E] Telephone Patching Board (expansion board)	47609-EMP	[M] Cat 6 Voice and Data Board (expansion board)	47611-0C6
[F] 1x6 4-Line Bridged Telephone Board (expansion board)	47609-0F6	4x12 Telephone Distribution Board	47603-12B
[G] 1x10 6-Line Bridged Telephone Security Board (expansion board)	47609-S10	[N] Multimedia Bracket (accepts 5F100 series plates)	47612-MMA
[H] 1x4 Port 4-Line Bridged Phone and 4-Port Cat 5e Board (expansion board)	47609-4DP		




POWER MODULES

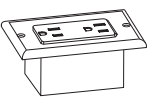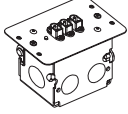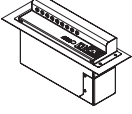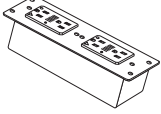							
[A] J-Box Kits							
Single Duplex J-Box Kit (surge)			47605-ACS				
Single Duplex J-Box Kit (non-surge)			47605-ACN	[E] AC Surge Module, Six Receptacles			48212-06S
[B] Universal Mini DC Power Supply Module			47605-PSB	[F] Versatile Power Supply 12VDC and NEMA AC			47605-PSC
[C] Universal Power Supply Module w/ IEC Receptacle			47605-PSA	IEC to NEMA Adapter Cord			48212-IEC
[D] AC Power Modules				[G] DC Bus 12 and 24 VDC Power Supply			48212-124
Double Duplex AC Power Module (surge)			47605-ODP	[H] 3-Outlet Power Strip with 1 1/2' cord			49605-APS
Double Duplex AC Power Module (non-surge)			47605-NDP				

VIDEO MODULES

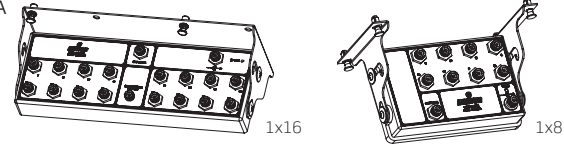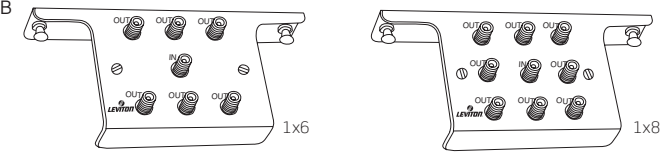
	
[A] Premium Amplified CATV Modules, SCITE/HDTV/DOCSIS Transmission Compliant	[B] Passive TV/CATV Splitter Modules
1x16 Premium Amplified CATV Module, 1 GHz, SCITE/HDTV/DOCSIS Transmission Compliant	1x6 Passive TV/CATV Splitter Module, 2 GHz
47693-08P	47690-6C2
1x8 Premium Amplified CATV Module, 1 GHz, SCITE/HDTV/DOCSIS Transmission Compliant	1x8 Passive TV/CATV Splitter Module, 2 GHz
47693-16P	47690-8C2
	Passive TV/CATV Splitter Modules Without Bracket
	1x6, Passive TV/CATV Splitter, No Bracket (2.05 GHz)
	47690-0G6
	1x8, Passive TV/CATV Splitter, No Bracket (2.05 GHz)
	47690-0G8

 RECESSED DEVICES

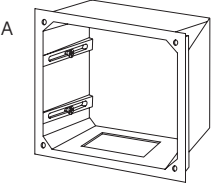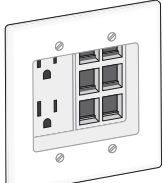			[A] Recessed Entertainment Box includes low-profile frame 9.46"x7.9" (240.3mm x 200.7mm)	47617-REB
			Recessed Entertainment Box includes high-profile cover	47617-RBH
			[B] One-Gang Recessed Duplex Receptacle (Also available in Ivory, Light Almond, and Black)	00689-00W
			[C] Two-Gang Recessed Duplex Receptacle (Also available in Ivory, Light Almond, and Black)	00690-00W

For a complete listing of our recessed device products, visit the residential entertainment products section of our website at Leviton.com.

DECORA® & ELECTRICAL-STYLE WALLPLATES

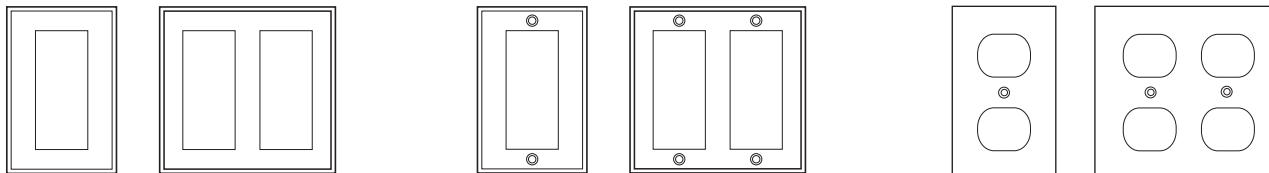

Decora Plus Snap-on Wallplates

Single-Gang	80301-S*
Dual-Gang	80309-S*

* = Color: Ivory (I), White (W), Grey (GY), Black (E), Light Almond (T), Brown (no letter used)

Decora Wallplates

Single-Gang	80401-*
Single-Gang (nylon)	80401-N*
Dual-Gang	80409-*
Dual-Gang (nylon)	80409-N*


* = Color: Ivory (I), White (W), Grey (GY), Black (E), Light Almond (T), Brown (no letter used)

Nylon Electrical Wallplates

Single-Gang	80703-*
Dual-Gang (nylon)	80716-*

* = Color: Ivory (I), White (W), Grey (GY), Black (E), Light Almond (T), Brown (no letter used)


QUICKPORT® WALLPLATES, SINGLE-GANG - ACCEPTS ALL QUICKPORT JACKS AND COUPLERS

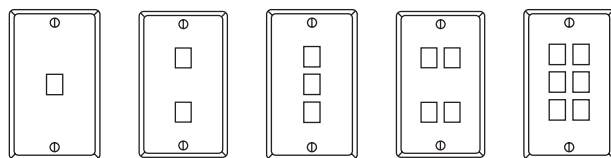

Single-Gang QuickPort Wallplates

1-Port	2-Port	3-Port	4-Port	6-Port
41080-1*P	41080-2*P	41080-3*P	41080-4*P	41080-6*P


* = Color: Ivory (I), White (W), Light Almond (T), Grey (G), Black (E), Brown (B)

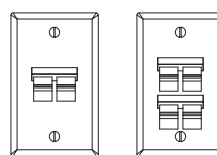

Angled Single-Gang QuickPort Wallplates

2-Port	4-Port
41081-2*P	41081-4*P

* = Color: Ivory (I), White (W), Light Almond (T)

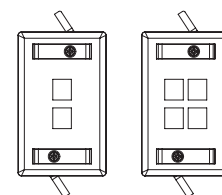


Single-Gang QuickPlate® Tempo Wallplates

2-Port	4-Port
42090-2^S	42090-4^S


^ = Color: Ivory (I), White (W), Light Almond (T), Grey (G), Black (B)

QUICKPORT STAINLESS STEEL WALLPLATES, SINGLE-GANG - ACCEPTS ALL QUICKPORT JACKS AND COUPLERS

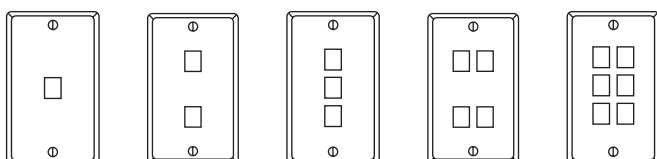

1-Port	2-Port	3-Port	4-Port	6-Port
43080-1S1	43080-1S2	43080-1S3	43080-1S4	43080-1S6

QUICKPORT DECORA® INSERTS - FIELD CONFIGURABLE WITH ALL QUICKPORT JACKS AND COUPLERS

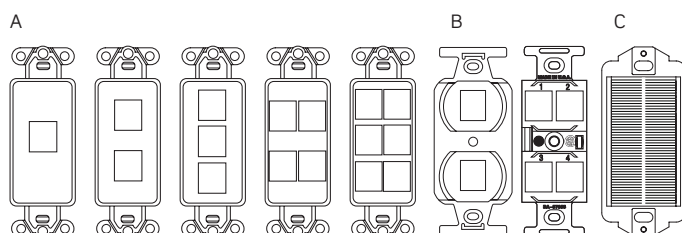

[A] Decora Multimedia Inserts	4164+*
-------------------------------	--------

† = Port configuration: (1), (2), (3), (4), (6)
* = Color: Ivory (I), White (W), Grey (GY), Black (E), Light Almond (T), Brown (B)

[B] Type 106 Duplex Inserts	
2-Port Insert	41087-2*P

4-Port Insert	41087-Q*P
---------------	-----------

* = Color: Ivory (I), White (W), Grey (G), Black (E)

[C] Decora Brush Passthrough Insert	41075-DB*
-------------------------------------	-----------

* = Color: White (W), Black (E), only brush is visible when installed.

SNAP-IN ADAPTERS & CONNECTORS



HOME 5e® QuickPort® Jacks
5EHOM-R*5



HOME 6® QuickPort Jacks
61HOM-R*6

* = Color: Ivory (I), Brown (B), White (W), Grey (G), Black (E), Blue (L), Light Almond (T)



BNC Couplers
Standard BNC 41084-B*F
Gold-Plated BNC 40832-0B°



S-Video
S-Video Coupler 40734-CV~
S-Video Jack, 110 termination 40734-SV*



3.5MM Stereo
3.5MM Stereo, screw terminal 40839-S~S



F-Connector Couplers
Nickel-Plated, 1GHz 41084-F*F
Gold-Plated, 2.5GHz 40831-F*G



Binding Post Couplers
Gold plated w/ black stripe 40833-B*E
Gold plated w/ red stripe 40833-B*R

* = Color: Ivory (I), White (W), Light Almond (T), Grey (G), Black (E), Brown (B)
† = Color: Ivory (I), White (W), Light Almond (T), Grey (G), Black (E)
~ = Color: Ivory (I), White (W)
° = Color: Ivory (I), White (W), Light Almond (T)



Cat 5 Jacks 41108-R†5



Voice Grade Jacks
6-conductor USOC jack 41106-R†6
8-conductor USOC jack 41108-R†8

† = Color: Ivory (I), White (W), Grey (G), Black (E), Orange (O), Blue (L), Crimson Red (C), Dark Red (R), Yellow (Y), Brown (B), Lt Almond (T), Green (V), and Purple (P)



RCA to 110 40735-Rx†

x = Inner Barrel Color: Orange (O), Red (R), White (W), Yellow (Y)
Ivory and White connectors available with Green (V) or Blue (L) Inner Barrel



RCA w/ black stripe 40830-B*E
RCA w/ red stripe 40830-B*R
RCA w/ yellow stripe 40830-B*Y
RCA w/ green stripe 40830-B~V
RCA w/ blue stripe 40830-B~L



Snap-in Blank Module 41084-B*B



Banana Jack Couplers
Gold Plated w/ black stripe 40837-B*E
Gold Plated w/ red stripe 40837-B*R

* = Color: Ivory (I), White (W), Light Almond (T)
~ = Color: Ivory (I), White (W)



HDMI Coupler 40834-*

 
* = Color: Ivory (I), White (W)



USB A/A Coupler 40835-*

* = Color: Ivory (I), White (W), Light Almond (T) Black (E)

COMPRESSION CONNECTORS



[A] F-Style	40985-CPF
[B] RCA-Style	40985-CRU


PERFORMANCE PATCH CORDS



eXtreme® High-Flex Cat 6 Patch Cords (5 per pack) 6H460-xx*


xx = Length: 6l = 6 inches, 01-20 feet
 * = Color: White (W), Blue (L), Yellow (Y), Red (R), Gray (S), Green (G), Black (E)

TOOLS

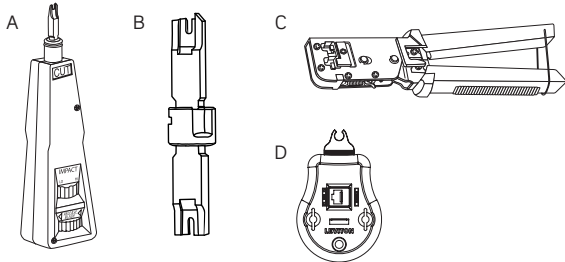

[A] Wire Punchdown/Termination Tool (Blades sold separately)	49553-814
[B] Wire Punchdown/Termination Tool Blades	
110 IDC Blade	49553-110
[C] EZ-RJ45 Crimp Tool	40989-ACT
[D] Palm Termination Tool	47615-PTT

ACCESSORIES

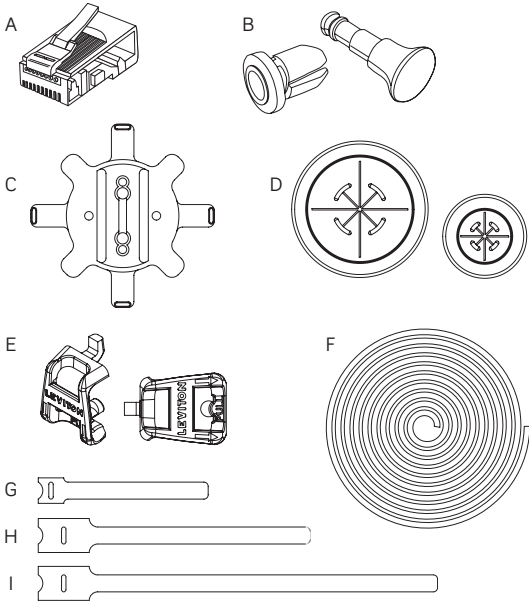

[A] EZ-RJ45 Cat 5e Plug (single unit)	47613-EZC
EZ-RJ45 Cat 5e Plug Bulk Pack (10 per pack)	47613-EZR
[B] Push-Lock Pins for Structured Media™ Centers (20 per pack)	47615-NYL
[C] Cable Routing Ring with (2) Push Pins	49605-AFR
[D] Grommet Accessory Pack for Structured Media Centers (Includes (3) 1" and (2) 2" rubber grommets. Works with all enclosure knockouts)	49605-GRM
[E] Saddle Tie kit w/ VELCRO® (includes (5) saddle ties, 5' of VELCRO® Softcinch, black)	49605-AST
[F] 15' bulk roll, ½" VELCRO® Softcinch, Black	49605-AHL
[G] VELCRO® Brand Tie-Wrap, 5" Length (25 per roll)	43105-005
[H] VELCRO® Brand Tie-Wrap, 8" Length (25 per roll)	43108-008
[I] VELCRO® Brand Tie-Wrap, 12" Length (25 per roll)	43112-012

VELCRO® is a registered trademark of Velcro BVBA. Used with permission.



LEVITON CONNECTED HOME DIVISION HEADQUARTERS

leviton.com/ns | 2222 - 222nd Street S.E., Bothell, WA 98021 USA

INSIDE SALES 800.722.2082 insidesales@leviton.com

INTERNATIONAL INSIDE SALES +1.425.486.2222 intl@leviton.com

TECHNICAL SUPPORT 800.824.3005 / +1.425.486.2222 appeng@leviton.com

LEVITON CORPORATE HEADQUARTERS

leviton.com | 201 N. Service Road, Melville, NY 11747 USA

CUSTOMER SERVICE 800.323.8920 / +1.631.812.6000 customerservice@leviton.com