

**Net-Verse**<sup>™</sup> Cabinets  
Versatility Made Simple

**BIG DATA**

Universal Design Converts Quickly to a Network or Server Cabinet



# Net-Verse™ Cabinets

Net-Verse™ Cabinets are the preferred choice for applications that require maximum flexibility in data center, enterprise or colocation deployment.

Data centers are under immense pressure to increase their operational efficiencies and overall operating OpeX ensuring that the data center is operating 24/7 without fail. With increased pressure for premium cabinet solutions within Data Center, Enterprise, and Colocations, there is a need to have a simple cost-effective cabinet solution.

Net-Verse™ Cabinets provides a 16 model offering matching current IT applications. This standard offering matches server, switch and network applications with flexible mounting options.

**Fill your data center with versatile cabinets – in the most efficient and cost-effective way – Look no further than Panduit® Net-Verse™ Cabinets.**

## Features and Benefits:

- Fully adjustable e-rail offers application flexibility
- Optional in-cabinet blanking panels are fully compatible with Panduit Universal Aisle Containment System maximizing airflow and thermal efficiency
- Multi-point locking doors and locking side panels provides enhanced security
- 2 full height multi purpose PDU/cable management brackets for mounting PDUs or lashing cables.
- Load ratings: static – 3000 lbs. (1360 kg); rolling – 1100 lbs. (500 kg)
- Cabinet sizes available: Width: 600mm, 800mm; Depth: 1000mm, 1200mm; Height: 42 RU, 45 RU



Integral vertical blanking panels in the 800mm wide cabinet offers 4 zero RU vertical openings that improve floor space utilization by up to 10%



Bonded doors and side panels provide a complete bonded cabinet for protection of equipment and personnel



Fully adjustable equipment rails with easy to read horizontal markings offer application flexibility, allowing you to make a network or server cabinet.



Large brush cable entry minimizes hot air recirculation and allows for large bundles of cables

Data Center

Enterprise

Colocation


# Net-Verse™ Cabinet Overview

<b>Class</b>	<b>Net-Verse™ Cabinets</b>
<b>Offering</b>	Fixed
<b>Height</b>	42 RU/45 RU
<b>Width</b>	600/800mm
<b>Depth</b>	1000/1200mm
<b>Standard Color</b>	Black
<b>Load Rating</b>	3,000 lbs. 1,360 kg static
	1,100 lbs. 500 kg rolling
<b>Doors</b>	69% air flow rate
	Single hinge front door
	Split hinge rear doors
	Two point lock – front door Three point lock – rear door
<b>Lockable Side Panels</b>	Horizontal split side panels for easy secured access
<b>E-rail Mounting</b>	Cage nuts
<b>Hardware</b>	Cage nuts and screws (40 pcs)
<b>Cable Management</b>	Fingers are offered as an accessory for the 800mm wide cabinet
<b>Grounding</b>	Bonding jumpers
<b>Thermal Management Options</b>	Universal aisle containment
<b>Casters</b>	Supplied
<b>PDU Brackets</b>	Supplied for both sides
<b>Roof</b>	Brush cable entry to minimize hot air recirculation

	<b>Net-Verse™ Cabinets</b>	<b>800mm Width</b>	<b>600mm Width</b>	
<b>With Side Panels</b>	42 RU	DN8212B	DN6212B	1000mm Depth
	45 RU	DN8512B	DN6512B	
	42 RU	DN8222B	DN6222B	1200mm Depth
	45 RU	DN8522B	DN6522B	
<b>Without Side Panels</b>	42 RU	DN8219B	DN6219B	1000mm Depth
	45 RU	DN8519B	DN6519B	
	42 RU	DN8229B	DN6229B	1200mm Depth
	45 RU	DN8529B	DN6529B	

# Accessorize

Our line of Net-Verse™ Accessories are designed to supply end users with the options necessary to allow for more cable management and thermal solutions.

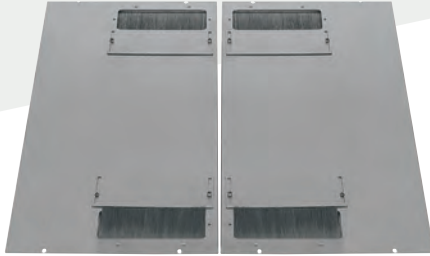


Bottom Cover Plates



Cable Management Fingers and Mounting Brackets for 800mm Cabinet



Side Panels

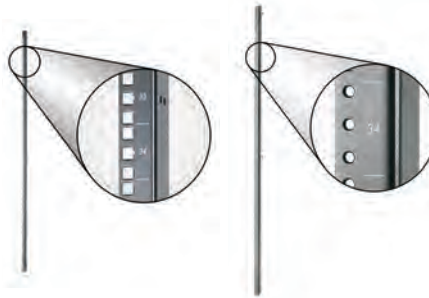

Cage Nut

Tapped

Fully Adjustable Equipment Rails



Front Door



Split Rear Door

Accessories	
Cable Management Fingers with Mounting Brackets for 800mm Wide Cabinet	
42 RU.	D12FBB
45 RU.	D15FBB
Bottom Cover Plates	
600mm wide x 1000mm depth.	D61BCPB
600mm wide x 1200mm depth.	D62BCPB
800mm wide x 1000mm depth.	D81BCPB
Equipment Rails	
42 RU – cage nut.	D2ERB
45 RU – cage nut.	D5ERB
42 RU – 12-24 tapped.	D2ERTB
45 RU – 12-24 tapped.	D5ERTB

Accessories	
Side Panels	
42 RU x 1000mm.	D21SPB
42 RU x 1200mm.	D22SPB
45 RU x 1000mm.	D51SPB
45 RU x 1200mm.	D52SPB
Cabinet Doors	
42 RU x 600mm width front door, Black.	D62FDB
42 RU x 600mm width front door, White.	D62FDW
42 RU x 600mm width split rear door, Black.	D62RDB
42 RU x 600mm width split rear door, White.	D62RDW
45 RU x 600mm width front door, Black.	D65FDB
45 RU x 600mm width front door, White.	D65FDW
45 RU x 600mm width split rear door, Black.	D65RDB
45R U x 600mm width split rear door, White.	D65RDW