

Industrial in a new light

PRODUCT SELECTION GUIDE

Turnkey lighting and controls solutions
for warehouses, distribution centers
and logistic facilities



Benefits of quality industrial lighting.

Lighting affects productivity and contributes to the success of an industrial facility.

Warehouses, distribution centers and logistics facilities are growing rapidly with the booming market of online commerce and on-demand inventory. Whether a new construction project or retrofitting an existing building, the quality of the lighting makes a difference. Lighting can affect productivity, energy efficiency, maintenance costs, employee performance and even the number of errors and accidents, making a significant contribution to the safety of workers.

In addition to a safe and productive working environment, today's building owners seek new levels of smart facilities management. With the latest advancements in LED lighting and its control capabilities, building owners and warehouse managers are realizing the benefits through increased productivity, employee safety and energy savings.

Solutions for an industrial environment



Warehouse/ distribution areas

Industry leading LED technology offers instant on and off capability, multiple accessories, light distributions and mounting options.



Offices/ general areas

Cooper's ambient lighting solutions offer installation flexibility for a variety of applications.

Recessed downlights and cylinders designed to meet commercial energy code requirements.



Lighting controls

Full line of relay panels and energy management systems for complete facility control of lighting systems.



Emergency and life safety

Complete selection of life safety emergency lighting, exit signage and Code compliant battery backup.



Security/site

Outdoor site and security fixtures for flood and general area lighting.


**DOWNLOAD
THE INDUSTRIAL
BROCHURE HERE**



Maximize Savings with Utility Rebates

Cooper Lighting Solutions Exclusive Utility Rebate Incentive Finder

cooperlighting.com/incentivefinder

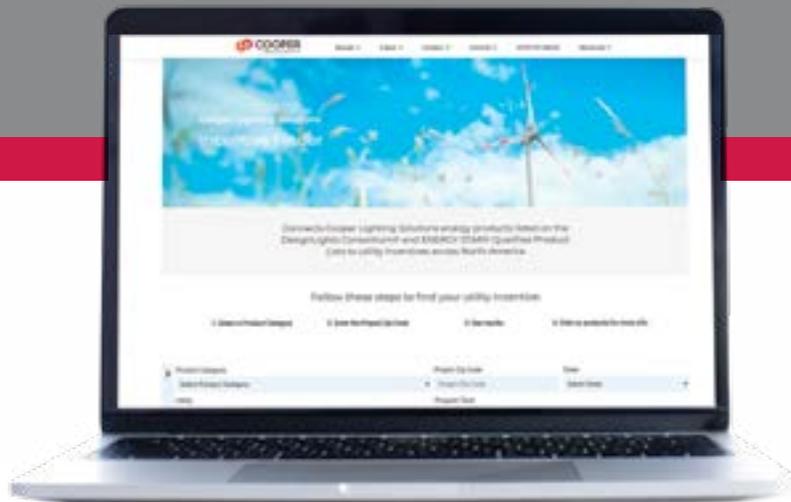

By using our online Incentive Finder, you can search by state and zip code to find local rebates to save money and add value for your customers. We've also identified the **ENERGY STAR**® and **DLC**® product ID numbers for your convenience.

Cooper Lighting Solutions has the largest portfolio of **ENERGY STAR**®-certified recessed downlights and **DesignLights**® Consortium (**DLC**) - qualified commercial luminaires, meeting high-quality, energy-efficient standards.

Code Compliance

The largest verified list of high performing LED lighting products.

<http://www.designlights.org/search/>
DLC Premium items are denoted in bold



UPC	DLC Product ID
080083811588	PG4TJNY3

<http://www.energystar.gov/productfinder/>



UPC	ENERGY STAR Unique ID
080083848164	2322242

www.energy.ca.gov



Look for the **DLC**, **ENERGY STAR** and **T20** icons that identifies qualified products.

Our Brands and Markets We Serve


At Cooper Lighting Solutions, we deliver industry leading indoor and outdoor lighting products, lighting controls, smart lighting systems, programs and services.



PAGE 5

METALUX INDUSTRIAL


Industrial recessed, linear, surface and high bay solutions.

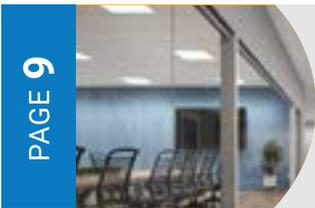

PAGE 9

METALUX


Commercial recessed, linear, surface and high bay solutions.

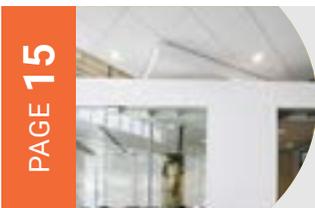

PAGE 15

HALO COMMERCIAL

Recessed downlight solutions.

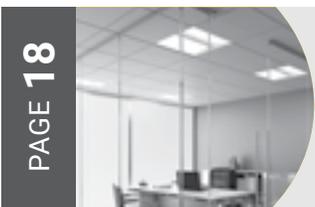

PAGE 18

GREENGATE


Lighting control sensors, panels and switches for multiple control configurations.



PAGE 23

SURE-LITES

Exit and Emergency fixtures and battery pack solutions.

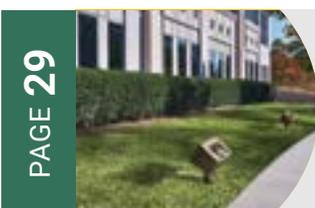

PAGE 29

LUMARK

Outdoor lighting solutions.

METALUX AMBIENT INDUSTRIAL



High Bay
p. 6-7



Vaportite
p. 7-8



OHB LED High Bay

Metalux

- Designed for a wide variety of applications and mounting heights
- Precision designed optical performance deliver even illumination
- Rugged design with rigid steel center channel
- Lensing provides LED protection and optical control
- Energy-efficient 1-for-1 replacement for linear fluorescent and HID high bay
- Ideal solution for industrial, manufacturing and gymnasium applications



Rapid Response

Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
OHB-18SE-MCL-UNV-L840-CD-U	Lensed, Wide Distr.	4-T5HO, 6-T8 320W MH	4000K	120-277V	18000	111	36	80083146925	P3F3AKYD
OHB-18SE-MCL-UNV-L850-CD-U	Clear Lens, Medium Distr.	4-T5HO, 6-T8 320W MH	5000K	120-277V	18000	111	36	80083902996	PX71TV2P
OHB-24SE-W-UNV-L840-CD-U	Lensed, Wide Distr.	6-T5HO, 8-T8, 400W MH	4000K	120-277V	24000	148	36	80083902972	PFO0QT12
OHB-24SE-W-UNV-L850-CD-U	Lensed, Wide Distr.	6-T5HO, 8-T8, 400W MH	5000K	120-277V	24000	148	36	080083902989	PBHX10S1

Note: DLC Premium items are noted in bold.

VHB LED High Bay

Metalux

- Designed for a wide variety of applications and mounting heights
- Precision designed optics; High impact polycarbonate optical lens
- Compact, lightweight design for ease of installation
- Energy-efficient LED solution for spaces that utilize traditional linear fluorescent and HID high bay
- Affordable solution for industrial, commercial, manufacturing and gymnasium applications



Rapid Response

Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
VHB-12-W-UNV-L840-CD-U	Wide Distr.	4-T8, 3-T5HO, 175W MH	4000K	120/277V	12,430	87	78	080083785971	P87DJGBP
VHB-12-W-UNV-L850-CD-U	Wide Distr.	4-T8, 3-T5HO, 175W MH	5000K	120/277V	12,773	87	78	080083785933	P6MXBQOS
VHB-18-W-UNV-L840-CD-U	Wide Distr.	4-T5HO, 6-T8 320W MH	5000K	120/277V	18,647	134	78	080083785919	P75UEXLK
VHB-18-W-UNV-L850-CD-U	Wide Distr.	4-T5HO, 6-T8 320W MH	4000K	120/277V	19,160	134	78	080083785902	PIJDELY
VHB-24-W-UNV-L840-CD-U	Wide Distr.	6-T5HO, 8-T8, 400W MH	5000K	120/277V	23,057	174	78	080083815708	PJ92YFP9
VHB-24-W-UNV-L850-CD-U	Wide Distr.	6-T5HO, 8-T8, 400W MH	4000K	120/277V	23,692	174	78	080083818365	PH575GE1

Lumen Selectable									
Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
VHB-1215-W-UNV-L840-CD-U	Wide Distr.	4-T8, 3-T5HO, 175W MH	4000K	120/277V	Selectable 12,000-15,000	110	78	080083192304	PJHJOBPH
VHB-1215-W-UNV-L850-CD-U	Wide Distr.	4-T8, 3-T5HO, 175W MH	5000K	120/277V	Selectable 12,000-15,000	110	78	080083192311	PQX68N7B
VHB-1824-W-UNV-L840-CD-U	Wide Distr.	4-T5HO, 6-T8 320W MH, 6-T5HO, 8-T8, 400W MH	4000K	120/277V	Selectable 18,000-24,000	158	78	080083192328	PKWWO6XP
VHB-1824-W-UNV-L850-CD-U	Wide Distr.	4-T5HO, 6-T8 320W MH, 6-T5HO, 8-T8, 400W MH	5000K	120/277V	Selectable 18,000-24,000	158	78	080083192335	PMKN6560
VHB-1824-N-UNV-L840-CD-U	Narrow Distr.	4-T5HO, 6-T8 320W MH, 6-T5HO, 8-T8, 400W MH	4000K	120/277V	Selectable 18,000-24,000	158	78	080083194834	P3BAS5NV, P9EQ8NS7
VHB-1824-N-UNV-L850-CD-U	Narrow Distr.	4-T5HO, 6-T8 320W MH, 6-T5HO, 8-T8, 400W MH	5000K	120/277V	Selectable 18,000-24,000	158	78	080083194841	PHU0FDKN, PHFFBWZM

Note: DLC Premium items are noted in bold.

High Bay

LHB LED High Bay

Metalux

- Economical high bay/low bay LED linear industrial luminaire
- Designed for a wide variety of applications and mounting heights
- Standard diffused lens provides added protection and glare control
- Energy-efficient, one-for-one replacement of linear fluorescent and HID fixtures
- Perfect for industrial, manufacturing, gymnasium and warehouse applications



Rapid Response

Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
LHB-12-UNV-L840-CD-U	Lensed, Medium Distr.	4-T8, 3-T5HO, 175W MH	4000K	120/277V	11,455	87	44	080083859160	PLCCRS3FP14Q
LHB-12-UNV-L850-CD-U	Lensed, Medium Distr.	4-T8, 3-T5HO, 175W MH	5000K	120/277V	11,493	87	44	080083859184	PLFXQYAHETOA
LHB-18-UNV-L840-CD-U	Lensed, Medium Distr.	4-T5HO, 6-T8 320W MH	4000K	120/277V	17,075	132	44	080083859207	PLYPCB02RW1Y
LHB-18-UNV-L850-CD-U	Lensed, Medium Distr.	4-T5HO, 6-T8 320W MH	5000K	120/277V	17,129	132	44	080083859221	PLEM5HU7PSWK
LHB-24-UNV-L840-CD-U	Lensed, Medium Distr.	6-T5HO, 8-T8, 400W MH	4000K	120/277V	22,012	172	44	080083859245	PLWL6C907DI4
LHB-24-UNV-L850-CD-U	Lensed, Medium Distr.	6-T5HO, 8-T8, 400W MH	5000K	120/277V	22,050	172	44	080083859269	PLQ5XUSDH4JX

Note: DLC Premium items are noted in bold.

UHB LED High Bay

Metalux

- Designed for a variety of mounting heights and applications
- Traditional round form factor and compact design allow for easy installation
- Specialty designed lens provides optimal distribution and reduced high angle glare
- Universal mounting allows for quick retrofit installations



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
UHB-12-UNV-L840-CD-U	Round, Die Cast, MD Distr.	4-T8, 3-T5HO, 175W MH	4000K	120/277V	13,436	99	45	080083885862	PLSZJNKFXWRM
UHB-12-UNV-L850-CD-U	Round, Die Cast, MD Distr.	4-T8, 3-T5HO, 175W MH	5000K	120/277V	13,672	100	45	080083885886	PL625202A764
UHB-18-UNV-L840-CD-U	Round, Die Cast, MD Distr.	6-T8, 4-T5HO, 320W MH	4000K	120/277V	19,607	147	45	080083885909	PLIB2FPH8U2B
UHB-18-UNV-L850-CD-U	Round, Die Cast, MD Distr.	6-T8, 4-T5HO, 320W MH	5000K	120/277V	19,654	150	45	080083885923	PLTP5R0QLF89
UHB-24-UNV-L840-CD-U	Round, Die Cast, MD Distr.	6-T5HO, 8-T8, 400W MH	4000K	120/277V	26,600	197	20	080083885947	PLDTKQEQCF8
UHB-24-UNV-L850-CD-U	Round, Die Cast, MD Distr.	6-T5HO, 8-T8, 400W MH	5000K	120/277V	26,664	197	20	080083885961	PLPWY41J5ISI
UHB-30-UNV-L840-CD-U	Round, Die Cast, MD Distr.	(6)T5HO 54W, 400W HID	4000K	120/277V	30000	137	20	080083885985	PLPDU641UFT8
UHB-30-UNV-L850-CD-U	Round, Die Cast, MD Distr.	6-T5HO, 8-T8, 400W MH	5000K	120/277V	32725	239	20	080083886005	PLX5IWPVBK00

Note: DLC Premium items are noted in bold.

VT LED Vaportite

Metalux

- Contemporary surface-mount fixture featuring rugged and durable construction
- Sealed and gasketed, reinforced fiberglass housing with a high impact lens
- Internal fasteners and tethers provide maximum protection and rigidity
- Optical performance for interior and exterior applications; IP65 certified; NSP Listed
- Ideal for parking garages, food processing, canopy, manufacturing and complex environments



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4VT3-LD5-4-G-UNV-L840-CD1-U	4' Fixed Output	2-T8, 1-T5HO	4000K	120/277V	4,428	32	40	080083851867	PA8HYRMS, P2K0S9SX, PMRYIYSZ, PJRKZ2U5, PVSGY9IF
4VT3-LD5-6-G-UNV-L840-CD1-U	4' Fixed Output	3-T8, 1-T5HO	4000K	120/277V	6,490	51	40	080083851447	P8U3H2QZ, PC8KZKBM, PDEVIYK6, P988IFAC

Note: DLC Premium items are noted in bold.

APVT LED Vaportite

Metalux

- Compact and durable vaportite fixture; Ideal for wet location environments
- Sealed and gasketed polycarbonate housing with a high impact polycarbonate lens
- Rated for -20°C to 30°C
- High-performance efficacy up to 132 lm/W
- Solution for interior and exterior applications including canopy, warehouse and light commercial environments



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4APVTLTD-40L840	4' Fixed Output	2-T8, 1-T5HO	4000K	120/277V	5,159	39	80	080083801305	PLR6T8MUGK5V, PLZRPONZA9RE
4APVTLTD-54L840	4' Fixed Output	2-T8, 1-T5HO	4000K	120/277V	6,209	39	80	080083802166	PLTWAYKH8VFL, PLOQOORWAVTW

Note: DLC Premium items are noted in bold.

Metalux Product Selection Guide



		High Bay	High Bay	High Bay	High Bay	Strip	Vaportite
		LHB	UHB	VHB	OHB	SLSTP	VT3 LED
APPLICABILITY	Warehouses	★★★	★★	★★★	★★★	★★	★★★
	Manufacturing	★★	★★	★★	★★★	★★	★★★
	Storage	★	★	★★★	★★★	★	★★
	Large Indoor				★★★		★★★
	Complex Environments		★★	★			★★★
FEATURES / PERFORMANCE	Lumen Range	12,000 - 36,000	12,000 - 30,000	Lumen Select	12,000 - 60,000	2400-5800	2,000 - 8,000
	Efficacy (Max)	140 lm/W	137 lm/W	147 lm/W	207 lm/W	125 lm/W	154 lm/W
	CRI	80	80	70, 80, 90	70, 80, 90	80	70, 80, 90
	Distribution	M	M	N, W	N, W	G	G, W, P
	Sizes	13" x 2' & 4'	12" Dia	< 2'	Scalable	2', 4', 8'	2', 4'
	Housing	CRS	Diecast	CRS / Extruded	CRS	CRS	Fiberglass/Polyester
	Lensing	Acrylic	Polycarbonate	Polycarbonate	Acrylic	Clear, Poly	DR Acrylic or Polycarb
	Life (@ 60K hrs)	L84	L91	L83	L96	L84	L91
	Ambient Range	-40C to 40C	-40C to 45C	-40C to 55C	-40C to 55C	-20C to 40C	-40C to 50C
	Emergency	Remote	None	Remote	Integrated	None	Yes
	Ratings	Damp	IP65	Damp	Damp	Damp	IP67
DLC	Premium	Premium	Standard, Premium	Premium	Standard	Premium	

Vaportite

★★★ = high applicability, ★★ = medium applicability, ★ = low applicability, blank = non-applicable

For certification information and to download this guide, visit Cooperlighting.com/MarketPro

METALUX AMBIENT COMMERCIAL



Troffer
p.10-13



Strip
p. 13



Wrap
p. 14



Flushmount
p. 14

Cruze ST Recessed LED Luminaire

Metalux

- Architectural center basket lens troffer with aesthetic appeal
- Latch-less design provides clean architectural look; Ribbed, frosted acrylic lens
- High-performance LED system with advanced light distribution
- Refined finish; Unmatched value
- Ideal choice for commercial, institutional and healthcare facilities



Rapid Response



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
22CZ2-32-UNV-L835-CD1-U	2'x2', Troffer	2-T5, 2-T8	3500K	120/277V	3,280	26	48	080083881185	PL057CFW (120V) , P15VC648 (277V)
22CZ2-32-UNV-L840-CD1-U	2'x2', Troffer	2-T5, 2-T8	4000K	120/277V	3,280	26	56	080083881208	P030DW27 (120V) , P8GWVUDUZ (277V)
22CZ2-34HE-UNV-L835-CD1-U	2'x2', Troffer	3-T8, 4-T8, 2-T5HO	3500K	120/277V	3386	26	28	080083881222	P6ZEZIGY
22CZ2-34HE-UNV-L840-CD1-U	2'x2', Troffer	3-T8, 4-T8, 2-T5HO	4000K	120/277V	3386	26	48	080083881260	PMRQB66T
22CZ2-39-UNV-L835-CD1-U	2'x2', Troffer	3-T8, 4-T8, 2-T5HO	3500K	120/277V	3,943	34	48	080083881284	P0AXJUK1
22CZ2-39-UNV-L840-CD1-U	2'x2', Troffer	3-T8, 4-T8, 2-T5HO	4000K	120/277V	3,943	34	48	080083881307	PU7UA6BJ
24CZ2-40-UNV-L835-CD1-U	2'x4', Troffer	2-T8, 3-T8	3500K	120/277V	4,196	36	26	080083881505	PUDYNNME
24CZ2-40-UNV-L840-CD1-U	2'x4', Troffer	2-T8, 3-T8	4000K	120/277V	4,196	36	28	080083881529	PWWGAYMY
24CZ2-50-UNV-L835-CD1-U	2'x4', Troffer	2-T8, 2-T5	3500K	120/277V	5,015	48	26	080083881628	POK3FN8Z
24CZ2-50-UNV-L840-CD1-U	2'x4', Troffer	2-T8, 2-T5	4000K	120/277V	5,015	48	26	080083881642	PI0YCHQ9

Note: DLC Premium items are noted in bold.

Features	Benefits
Latchless-design with no visible hinges	Improved aesthetic to delight specifiers
Standard matte white paint from corner to corner	Improved aesthetic to delight specifiers
Large J Box with standard access plate and trade size knockouts	Easier wiring access to delight contractors
Hemmed side flanges	Easier handling during installation to delight contractors
Linear disconnect included	Easier installation to delight contractors
Multiple sizes available (2'x2', 2'x4' in standard 3.25" depth & 1'x4' shallow 2.25" depth)	Enables fixture matching in spaces
Grid lock feature included in the endplate with available "earthquake clip" accessory	Helps meet building codes

Cruze LED Recessed Retrofit Kit

Metalux

- Upgrade 2' x 4' fluorescent luminaires to a high-performing LED system
- Engineered for simple and quick installation (less than 5 minutes); Labor savings
- Tool-less installation
- Uses the fluorescent luminaire's housing resulting in lower disposal costs
- Architectural style aesthetics for multiple applications



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
24CZRK-LD4-40-UNV-L840-CD1-U	2'x4' Center Basket Retrofit Kit	2-T8, 3-T8	4000K	120/277V	4,423	37	36	080083804610	P6J3B352

Note: Fixture housing not included; DLC Premium items are noted in bold.

Troffer

Encounter LED Series

Metalux

- Leverages patented WaveStream™ Technology with AccuAim™ optics
- Contemporary styling; Advanced optical control
- Optimal light uniformity, resulting in soft, natural light for superior visual comfort
- Over 60% energy savings when compared to fluorescent troffers
- Ideal choice for commercial interiors



Rapid Response



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
22EN-LD2-34-UNV-L835-CD1-U	2'x4', Recessed Troffer	3-T8, 4-T8, 2-T5HO	3500K	120/277V	3,471	29	40	080083752324	PUJBJAKE
22EN-LD2-34-UNV-L840-CD1-U	2'x4', Recessed Troffer	3-T8, 4-T8, 2-T5HO	4000K	120/277V	3,540	29	36	080083752317	PSRD33BV , PXJ7Q3QF
24EN-LD2-45-UNV-L835-CD1-U	2'x2', Recessed Troffer	2-T8, 3-T8	3500K	120/277V	4,656	38	18	080083752225	PYDG9S8N , PNGQ7GTA
24EN-LD2-45-UNV-L840-CD1-U	2'x2', Recessed Troffer	2-T8, 3-T8	4000K	120/277V	4,748	38	20	080083752218	PF2T7Y87 , PUGD2UQG

Note: DLC Premium items are noted in bold.

Troffer

SkyRidge LED Series

Metalux

- Leverages patented WaveStream™ Technology with AccuAim™ optics
- Affordable, aesthetically pleasing alternative to fluorescent fixtures
- Advanced optical control with optimal illumination
- Over 60% energy savings when compared to fluorescent troffers
- Ideal choice for commercial interiors



Rapid Response



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
22SR-LD2-29-C-UNV-L835-CD1-U	2'x2', Recessed Troffer	2-T5, 2-T8	3500K	120/277V	3,095	23	28	080083752584	PL2K2CYL(120V) , PURGNZ9E(277V)
22SR-LD2-29-C-UNV-L840-CD1-U	2'x2', Recessed Troffer	2-T5, 2-T8	4000K	120/277V	3,157	23	28	080083752577	PSRAE17C
24SR-LD2-48-C-UNV-L835-CD1-U	2'x4', Recessed Troffer	2-T8, 2-T5	3500K	120/277V	4,805	38	16	080083752492	P6V4CWNY
24SR-LD2-48-C-UNV-L840-CD1-U	2'x4', Recessed Troffer	2-T8, 2-T5	4000K	120/277V	4,901	38	16	080083752485	PDLK7ZMQ

Note: DLC Premium items are noted in bold.

RBG LED Series

Metalux

- Architectural elegant 6-inch grid, 4-inch aperture fixture
- Recessed, surface or suspension mounting
- Field-selectable CCT: 3000K, 3500K, 4000K via a switch
- 3 field-selectable lumens and watts via a switch; Flexibility to changing needs of a space
- Use for open and traditional offices, classrooms, coves, corridors, retail or anywhere stylish lines of light are desired



Catalog Number	Product Description	Replaces Up To	Selectable CCT	Voltage	Selectable Lumens	Watts (HI)	Pallet Quantity	UPC	DLC Product ID
4RBG6-SL1-L8SCT3	4' Length	2-F32T8, 1-F54T5HO, 2-F28T5	3000K/3500K/4000K	120-227V	500/750/1,000*	36	75	080083866465	PUREBLSF, PSMWARPL, PW27GGE8

*Lumens per ft.

CGT LED Panel Series

Metalux

- Affordable panel that fits in shallow plenums with room to spare; Thin 2 1/8 inch height
- Robust die-formed steel housing is post-painted for maximum durability
- Acrylic micro optics provide uniform illumination from corner to corner
- Extruded aluminum bezel with mitered corners tightly sealed to housing for durability
- Ideal for office spaces, schools, healthcare and retail merchandising areas



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
22CGT3535C	2'x2' Recessed Panel	3-T8	3500K	120/277V	3,449	32	72	080083880003	P6WE1HNZ
22CGT3540C	2'x2' Recessed Panel	3-T8	4000K	120/277V	3,582	32	72	080083880027	P0YGNM7S
24CGT4535C	2'x4' Recessed Panel	2-T8, 3-T8	3500K	120/277V	4,268	38	36	080083880089	P28JP113
24CGT4540C	2'x4' Recessed Panel	2-T8, 3-T8	4000K	120/277V	4,432	38	18	080083880102	PLTEVMIJ
24CGT4550C	2'x4' Recessed Panel	2-T8, 3-T8	5000K	120/277V	4,432	38	36	080083880126	P8BJLKN
24CGT5535C	2'x4' Recessed Panel	3-T8, 4-T8	3500K	120/277V	5,139	47	36	080083880164	PGQBAT0L
24CGT5540C	2'x4' Recessed Panel	3-T8, 4-T8	4000K	120/277V	5,337	47	36	080083880188	P5F04P82

FPS LED Panel Series

Metalux

- Ultra-thin, high-performance flat panel; Less than 2-inches height for shallow plenums
- Up to 120 lm/W; Field-selectable CCT: 3000K, 3500K, 4000K via a switch
- 3 field-selectable lumens and watts via a switch; Flexibility to changing needs of a space
- Integrated grid retention clips provide installation speed and flexibility
- Solution for office spaces, schools, healthcare facilities and retail merchandising areas



Catalog Number	Product Description	Replaces Up To	Selectable CCT	Voltage	Selectable Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
22FPSL2SCT3	2'x2' Recessed Panel	3-T8	3000K/3500K/4000K	120/277V	1,800-3,300	16	40	080083889402	PIBWK9P9, PB32RP9H, PJQG8V0T
24FPSL2SCT3	2'x4' Recessed Panel	2-T8, 3-T8	3000K/3500K/4000K	120/277V	3,400-6,400	30.2	20	080083889365	PK4M6K93, PZFJCMXS, PU0HKZ87

FPanel LED Panel Series

Metalux

- Ultra-thin flat panel; Less than 2-inches height for shallow plenums
- Easy to install, wire and wire nuts included
- Refined visual optics, superior acrylic light guide; uniform corner to corner illumination
- Integrated grid retention clips provide installation speed and flexibility
- Solution for office spaces, schools, healthcare facilities and retail merchandising areas



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
22FP3235C	2'x2' Recessed Panel	3-T8	3500K	120/277V	3307	29	44	080083833528	PQC9IUIIC
22FP3240C	2'x2' Recessed Panel	3-T8	4000K	120/277V	3,560	30	44	080083833542	PU0IG6S2
22FP4235C	2'x2' Recessed Panel	2-U6T8	3500K	120/277V	4,641	39	44	080083833580	P8HIK308
22FP4240C	2'x2' Recessed Panel	3-U6T8	4000K	120/277V	4,567	39	44	080083833603	PELH4PNQ
24FP4735C	2'x4' Recessed Panel	2-T8, 3-T8	3500K	120/277V	4,990	40	22	080083833641	PRZ2RGGDY
24FP4740C	2'x4' Recessed Panel	2-T8, 3-T9	4000K	120/277V	4,858	40	22	080083833665	PGY6ID6B
24FP6440C	2'x4' Recessed Panel	3-T8, 4-T9	4000K	120/277V	6,611	59	22	080083833726	PUQIRODO

Troffer

GRLED Series

Metalux

- Built and designed for general purpose lighting applications
- Shallow, low-profile housing, makes it compatible with highly restrictive plenums
- Traditional prismatic A12 lens and door assembly; Insulated ceiling (IC) rated
- Easy to install; Fits most T-grid systems; Below the ceiling maintenance
- Great choice for commercial offices, schools, hospitals, retail and more applications



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
24GR-LD5-48-F1-UNV-L840-CD1-U	2'x4' A Lens Troffer	2-T8	4000K	120/277V	4,800	43	28	080083817153	PF64UQWQ

Note: DLC Premium items are noted in bold.

SLSTP LED Striplight Series

Metalux

- Low-profile, high-quality luminaire with latest LED and electronic driver technology
- Frost white polycarbonate lens with linear prisms for even illumination
- Single lens eliminates the tandem appearance
- Quick installation features; Ideal for single or continuous row applications
- Perfect solution for restricted spaces and for stock and design build application



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4SLSTP4040DD-UNV	4' Single Lens	2-T8 32W, 1-T5HO 54W	4000K	120/277V	4,000	43	72	080083705825	PXZQGN9C, PPA1YS12
8SLSTP11040DD-UNV	8' Single Lens	4-T8 32W, 2-T12 75W	4000K	120/277V	10,464	83	70	080083807680	PWA7BZM9, PUOOP0M3
8SLSTP8040DD-UNV	8' Single Lens	4T8 32W, 2-T12 75W	4000K	120/277V	8,176	71	70	080083814787	POK8WFD1, PARMCVA1

Troffer/Strip

ST LED Striplights

Metalux

- Full-width LED strip light; Ideal for replacing single or 2-lamp fluorescent strip lights
- Superior performance with lumens up to 9400 and 123 lm/W
- Tool-less channel cover; Unique single or dual lens tube design
- Surface or suspended mounting; Wireless access from below
- Continuous row mount aligner included to add-on length as needed regardless of application or layout



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
2ST1L1040R	2' Single Lens	1-T8 17W	4000K	120/277V	1,165	10	288	080083838165	PLYWPPTN5MXA
2ST2L2040R	2' Dual Lens	2-T8 17W	4000K	120/277V	2,298	19	180	080083838172	PLT3RHMTZ063
4ST1L2040R	4' Single Lens	1-T8 32W	4000K	120/277V	2,298	20	252	080083838189	PLALG17SBDJR
4ST2L4040R	4' Dual Lens	2-T8 32W, 1-T5HO 54W	4000K	120/277V	4,433	39	150	080083838196	PLT1KD8JM2VZ
8ST2L8040R	8' Dual Lens	4-T8 32W, 2-T12 75W	4000K	120/277V	8,867	78	150	080083838202	PL5RGM59H32E

WNLED Wraparound Series

Metalux

- Utility commercial LED wraparound; Single or continuous row applications
- Frosted lens offers best-in-class uniform illumination
- Use in a broad range of commercial, schools, institutional, retail and residential applications
- Provides long service life, eliminating re-lamping issues and minimizing maintenance common with traditional fluorescent



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4WNLED-LD4-40SL-F-UNV-L840-CD1-U	4' Linear Wrap	2-T12, 2-T8 32W	4000K	120/277V	4,062	36	85	080083756889	PK3W95DW

CWPLD LED Wraparound Series

Metalux

- Versatile, commercial model, low-profile LED wraparound
- Premium optical linear prisms provide even and wide distribution, minimizing fixtures required
- Surface, wall, suspended and row mounting; Quick row mounting channel
- Trade sized knock outs included for "hard pipe" wiring through ends
- Mounts over the most common junction boxes



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4CWPLD4040C	4' Commercial	2-T12, 2-T8	4000K	120/277V	4,700	43	60	080083749072	P5SLI38B, PER729JP

WPLD LED Wraparound Series

Metalux

- Streamlined, low-profile design
- Smooth lens provides soft, uniform, glare-free light output
- Providing up to 60% energy savings over fluorescent light sources
- Suitable for ceiling, wall or suspension mounting
- Mounting slots allow for installation directly into the junction box with 100° of rotational freedom



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4WPLD4035C	4' Low Profile	2-T8 32W	3500K	120/277V	4,000	45	84	080083750603	PZ4NNCFK
4WPLD4040C	4' Low Profile	2-T8 32W	4000K	120/277V	4,603	42	84	080083749676	PYGI6R4N

WP LED Wraparound Series

Metalux

- Compact LED wrap light delivers value and energy savings
- Perfect retrofit solution for replacing single or 2-lamp fluorescent wraparounds
- Low-profile, highly versatile design; Post-painted die-formed channel
- Prismatic lens ensures even, glare-free light distribution
- Ideal for commercial applications from schools and dorms to warehouses and retail areas



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
4WP3040C	4' Linear Utility	2-T8 32W	4000K	120/277V	3,400	31	72	080083858361	PC1Y20YN

FM LED Dimming Flushmounts

Metalux

- Versatile ceiling- or wall-mount series for a broad range of residential and commercial applications
- Full frost, opal white lens provides optimal light output with no pixilation
- Even, uniform light distribution; Easy lens installation
- Ideal for offices, corridors, stairways, bedroom, closet and foyers applications where customers are replacing incandescent, circline or compact fluorescent lamps



Catalog Number	Product Description	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	ENERGY STAR Unique ID
FM11WRCCR	11" Flushmount, Round	22 W T9 Circline	3000K/4000K/5000K	120V	1,100	14	72	080083840151	2324855
FM15WRCCR	15" Flushmount, Round	100W INC or 32W T9 Circline	3000K/4000K/5000K	120V	1,800	22	32	080083845378	2324853

Wrap/Flushmount

HALO COMMERCIAL RECESSED COMMERCIAL DOWNLIGHT



Downlight
p.16



PR4 LED SeleCCTable™ Downlight Series

HALO Commercial

- 4-inch LED self-flanged, lensed recessed downlight
- Available in new construction, retrofit and surface-mount cylinder
- Field selectable lumens: 1000, 1500, 2000
- Field selectable CCT: 3000K, 3500K, 4000K
- Exclusive medium / wide beam distribution reversible flip lens



Catalog Number	Product Description	Finish	Replaces up to	Selectable CCT	Voltage	Selectable Lumens	Watts	Pallet Quantity	UPC	ENERGY STAR Unique ID
PR4FS12D010	4" Housing	Raw Finish	26W-32W	N/A	120-277V	1000/1500 /2000	11	90	080083131839	2353549
PR4M12MD8FSMW	4" LED Module	Matte White	26W-32W	3000K/3500K/4000K	120-277V	1000/1500 /2000	22	144	080083060795	2353549
PR4RFS12D010	4" Retrofit Frame	Raw Finish	26W-32W	N/A	120-277V	1000/1500 /2000	22	72	080083132683	2353549
PR4SFS12D010MW	4" Cylinder, Surface Mount	Matte White	26W-32W	N/A	120-277V	1000/1500 /2000	22	108	080083133581	2353549

Specify two parts: LED module and housing, retrofit or surface mount cylinder

Downlight

PR6 LED SeleCCTable™ Downlight Series

HALO Commercial

- 6-inch LED self-flanged, lensed LED recessed downlight
- Available in new construction, retrofit and surface-mount cylinder
- Field selectable lumens: 1000, 1500, 2000
- Field selectable CCT: 3000K, 3500K, 4000K
- Medium and wide interchangeable lens option included
- Specify two parts: LED module and housing or surface mount cylinder



Catalog Number	Product Description	Finish	Replaces up to	Selectable CCT	Voltage	Selectable Lumens (up to)	Watts	Pallet Quantity	UPC	ENERGY STAR Unique ID
PR6FS12D010	6" Housing	Raw Finish	26W-32W	N/A	120/277V 50/60 Hz	1000/1500/2000	21	72	080083892174	2328770
PR6M12MD8FSMW	6" LED Module	Matte White	26W-32W	3000K/3500K /4000K	N/A	1000/1500/2000	N/A	72	080083891122	2345484
PR6RFS12D010	6" Retrofit Kit	Raw Finish	26W-32W	N/A	120V-277V 50/60 Hz	1000/1500/2000	22	72	080083891726	2345457, 2345484
PR6SFS12D010MW	6" Cylinder, Surface Mount	Matte White	26W-32W	N/A	120V-277V 50/60 Hz	1000/1500/2000	21	72	080083891276	2328770

PR8 LED SeleCCTable™ Downlight Series

HALO Commercial

- 8-inch LED self-flanged, lensed recessed downlight
- Available in new construction, retrofit and surface-mount cylinder
- Field selectable CCT: 3000K, 3500K, 4000K
- Universal input 120V-277V with 0-10V 1% dimming
- Specify two parts: LED module and housing, retrofit or surface mount cylinder



Catalog Number	Product Description	Finish	Replaces up to	Selectable CCT	Voltage	Lumens (up to)	Watts	Pallet Quantity	UPC	ENERGY STAR Unique ID
PR830D010	8" Housing	Raw Finish	65W	N/A	120V-277V	3000	28	36	080083771790	2289674
PR8M34MDMW	8" LED Module	Matte Finish	65W-85W	3000K/3500K/4000K	Low Voltage	3000-4000		240	080083772940	2289767
PR8R30D010	8" Retrofit Kit	Raw Finish	65W	N/A	120V-277V	3000	28	480	080083772193	2289686
PR8S30D010MW	8" Cylinder, Surface Mount	Matte White	65W	N/A	120V-277V	3000	28	108	080083772599	2289685

CONTROLS

GREENGATE



Dimmer Switch
p. 18



Sensor
p. 19



Control
p. 20-22



0-10V WBSD Decorator Dimmer

Greengate

- Provides a full-range of linear-slide dimming control of 0-10V compatible light sources
- Allows user to return to previous light level when turning lights ON
- Can be used in single-pole (1 location) and 3-way (multi-location) applications
- Neutral wire is not required for installation of device
- Ideal for light commercial applications; Compatible with decorator style devices and wallplates



Catalog Number	Product Description	Finish	Voltage	Pallet Quantity	UPC
WBSD-010DEC-C1	0-10V Decorator Dimmer	White, Ivory, Almond	120V/277V	1,350	080083735266
WBSD-010DEC-C2	0-10V Decorator Dimmer	White, Ivory, Light Almond	120V/277V	1,350	080083735273

0-10V WBSD Preset Slide Dimmer

Greengate

- Full-travel slide control; LED ready
- Class 1 or Class 2 wiring capabilities
- Can be used in single-pole (1 location) and 3-way (multi-location) applications
- Works with the SP20-RD4 or directly controls the load
- White face assembled on device, Ivory and Light Almond color change kits included



Catalog Number	Product Description	Finish	Voltage	Pallet Quantity	UPC
WBSD-010M-C1	0-10V Preset Slide Dimmer	White	120/277 VAC	960	080083834983

0-10V OSW Wallbox Dimmer Sensor

Greengate

- 3-in-1 solution that combines functionality of a switchpack, a sensor and a 0-10V dimmer
- Saves labor costs, reduces installation time and meets energy codes and standards
- 0-10V dimming with passive infrared (PIR) occupancy sensing; Surge protection built-in
- Can be used in single-pole (1 location) as well as 3-way (multi-location) applications
- Compatible with Cooper Lighting Solutions' decorator style devices and wallplates



Catalog Number	Product Description	Finish	Voltage	Watts	Detection Type	Coverage	Pallet Quantity	UPC
OSW-P-010-W	0-10V Wallbox Dimmer, Sensor	White	120/277V	1200W/2200W	PIR	1000 sq ft.	1,920	080083758661

Dimmer Switch



0-10V Dual Tech Occupancy Sensor Dimmer

Greengate

- 3-in-1 solution that combines functionality of a switchpack, a sensor and a 0-10V dimmer
- Saves labor costs, reduces installation time and meets energy codes and standards
- Ultrasonic occupancy (US) and passive infrared (PIR) sensing; Daylight harvesting
- Can be used in single-pole (1 location) as well as 3-way (multi-location) applications
- Compatible with Cooper Lighting Solutions' decorator style devices and wallplates



OSW-D-010-W



Catalog Number	Product Description	Finish	Voltage	Watts	Detection Type	Coverage	Pallet Quantity	UPC
OSW-D-010-W	0-10V Dimmer, OCC Sensor	White	120/277V	960W/2200W	PIR and Ultrasonic	1000 sq. ft.	1,200	080083816071

NeoSwitch ONW Occupancy Wall Sensor

Greengate

- Passive Infrared (PIR) single level occupancy sensing switch for motion sensing control
- Also a conventional wall switch; Designed for energy savings and convenience
- Detects motion from a heat-emitting source (such as a person entering a room) within its field-of-view and automatically switches lights ON
- Neutral and non-neutral wiring options for installation; Ideal for retrofit applications



ONW-P-1001-DMV-W

ONW-D-1001-DMV-W



Catalog Number	Product Description	Finish	Voltage	Watts	Detection Type	Coverage	Pallet Quantity	UPC
ONW-P-1001-MV-W	PIR Wall Sensor	White	120/277V	1200W/2200W	PIR	1000 sq. ft.	900	080083523863
ONW-D-1001-MV-W	Dual Tech Wall Sensor	White	120/277V	1200W/2200W	PIR and Ultrasonic	1000 sq. ft.	900	080083524709
ONW-D-1001-MV-N-W	Dual Tech Wall Sensor, Neutral required	White	120/277V	1200W/2200W	PIR and Ultrasonic	1000 sq. ft.	900	080083524594

OAC MicroSet Dual Tech Ceiling Sensors

Greengate

- Combines ultrasonic and Passive Infrared (PIR) technologies, eliminates false deactivations
- MicroSet self-adjusting technology provides an adaptive and airflow tolerant technology
- Ideal for spaces that have increased airflow due to higher occupant levels
- Drastically simplifies and reduces installation and adjustment time
- Available in line-voltage and low-voltage versions; Compatible with SP20 switchpacks



Catalog Number	Product Description	Finish	Voltage	Watts	Detection Type	Coverage	Pallet Quantity	UPC
OAC-DT-2000-MV	DT Ceiling Mount, Line Voltage	White	120-347V	1200W-2700W	PIR and Ultrasonic	2000 sq. ft.	450	080083579426
OAC-DT-2000	DT Ceiling Mount, Low Voltage	White	10-30VDC	N/A	PIR and Ultrasonic	2000 sq. ft.	450	080083579266
OAC-DT-2000-R	DT Ceiling Mount, Isolated Relay	White	10-30VDC	N/A	PIR and Ultrasonic	2000 sq. ft.	450	080083702077
OAC-DT-1000	DT Ceiling Mount, Low Voltage	White	10-30VDC	N/A	PIR and Ultrasonic	1000 sq. ft.	540	080083579242
OAC-DT-1000-R	DT Ceiling Mount, Isolated Relay	White	10-30VDC	N/A	PIR and Ultrasonic	1000 sq. ft.	540	080083702060
OAC-DT-0501	DT Ceiling Mount, Low Voltage	White	10-30VDC	N/A	PIR and Ultrasonic	500 sq. ft.	450	080083579228
OAC-P-1500-R	Low Voltage Ceiling Sensor	White	10-30VDC	N/A	N/A	N/A	800	080083579150

LightKeeper 8 Lighting Control Panel

Greengate

- An all-inclusive premium grade system, stand-alone lighting control panel
- For applications that would traditionally use a time clock in conjunction with contactors
- Control up to 8 relays per panel; Manual and programmable control of each relay
- Time schedules with astronomic clock; Occupant warn-off and overrides
- Prioritization and masking of switch inputs, schedules and remotes



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
LK8	LiteKeeper 8 Lighting Control Panel	White	120/277 VAC	40	45	080083594573

LiteKeeper 4 Lighting Control Panel

Greengate

- An all-inclusive premium grade system, stand-alone lighting control panel
- For applications that would traditionally use a time clock in conjunction with contactors
- Controls up to 4, 20A circuits; Manual and programmable control of each relay
- Time schedules with astronomic clock; Occupant warn-off and overrides
- Prioritization and masking of switch inputs, schedules and remotes



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
LK4-120NO	LiteKeeper 4 Lighting Control Panel	White	120V	20	126	080083592043
LK4-277NO	LiteKeeper 4 Lighting Control Panel	White	277V	20	150	080083594603

ControlKeeper CK4A Series

Greengate

- Cost-effective, specification grade lighting control system
- Control 4 relays per panel
- Network up to 254 ControlKeeper panels for a state-of-the-art lighting control system
- Capable of mixed load voltages (120/277 VAC) as well as mixed sources
- Time schedules with astronomic clock; NEMA 1 enclosure; UL listed, UL 916 Standard



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
CK4A-SLRC	ControlKeeper 4A, SLRC Relay card	White	120 / 277V	40	90	080083162062
CK4A-SSRCNO	ControlKeeper 4A, SSRCNO Relay card	White	120 / 277V	40	80	080083162079
CK4A-STPRCNO	ControlKeeper 4A, STPRCNO Relay card	White	120 / 277V	40	80	080083162055

Control

GDS - Digital Switch

Greengate

- For the ControlKeeper and LiteKeeper 32, LiteKeeper 16 and LiteKeeper 8 lighting control panels
- Offers ON/OFF control of any relay or group of relays in the lighting control network
- Permits multiple control stations to be connected to the lighting control panels
- Provides override and status feedback; Create custom configuration for each button
- Suitable for standard single and multi-gang NEMA wall box; Class 2 low-voltage wiring



Catalog Number	Product Description	Finish	Voltage	Pallet Quantity	UPC
GDS-1TLB-W	Digital Switch, 1 large button	White	24VDC	1200	080083162130
GDS-2TLB-W	Digital Switch, 2 large buttons	White	24VDC	1200	080083162123
GDS-3TLB-W	Digital Switch, 3 large buttons	White	24VDC	1200	080083162116
GDS-4TSB-W	Digital Switch, 4 small buttons	White	24VDC	600	080083162109
GDS-6TSB-W	Digital Switch, 6 small buttons	White	24VDC	1200	080083663453
GDS-I-KIT	Digital Switch Integrator	White	24VDC	450	080083663477

Room Controller

Greengate

- Code-compliant lighting, emergency and plug load control
- Low-voltage control panel for ON/OFF and dimming loads
- Click & Go ready with RJ45 QuickConnect ports eliminates wiring errors
- Wallstations are pre-engraved low-voltage switches; Fits in standard decorator opening
- Input/Output Device provides connection of any Greengate low-voltage occupancy sensor



OCC-RJ45



RC3DE-PL



RC-5TSB-OS2-W



RC-3TLB-Z1D-W



Catalog Number	Product Description	Finish	Voltage	Pallet Quantity	UPC
RC3DE-PL	3 Zone with emergency	White	120- 277V	162	080083835041
RC3D-PL	3 Zone without emergency	White	120- 277V	120	080083835027
RC-3TLB-Z1D-W	1 Zone wall station	White	24V	1,120	080083695126
RC-5TSB-OS2-W	Office Station	White	24V	1,120	080083657322
OCC-RJ45	OCC Sensor Input/output device	White	24V	3,000	080083814572

Open Loop Daylight Sensor/IR Receiver

Greengate

- Measures natural light in order to automatically adjust the lighting zones
- Light sensor ranges: Low (3-300 lux), High (30-3000 lux), Direct Sun (300-30000 lux)
- High light range is selected by default, but can be adjusted using IR handheld remote
- Easy installation in suspended fixture or drop ceiling; RJ45 connection
- Mounting bracket for installation in light well or hard ceiling



Catalog Number	Product Description	Finish	Voltage	Detection Type	Pallet Quantity	UPC
DSRC-FMOIR	Open Loop Daylight Sensor	White	24VDC	Open Loop Photocell	2100	080083786497

Heavy Duty Switch Pack

Greengate

- Provides 15 VDC operating voltage to all low-voltage, 15 VDC, occupancy sensors and daylighting controllers
- A single switchpack can provide power for up to 5 sensors
- Up to 10 switchpacks can be connected to 1 sensor for control of multiple circuits
- Replaces separate transformer and relays; Capable of switching up to 20 amps
- Isolated contacts may also be used to control HVAC, contractors and motors, etc.



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
SP20-MV	Standard Heavy Duty	Raw Finish	120/277V	2400W-5400W	1,800	080083503223

SP20 Switch Pack

Greengate

- Robust switchpack with a wide array of switching solutions in a single unit
- Exclusive fail-safe circuitry: In an event of failure, return to close (ON)
- Reliable mechanical latching relays; Daylight harvesting; Bi-level switching
- Configurable for energy code requirements
- Designed to handle high inrush electronic ballast loads




Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
SP20-RD4	Advanced Heavy Duty	White	120-230-277VAC	2400W-5400W	1,800	080083815869

Emergency Power Control

Greengate

- Allows control of emergency lighting by any Greengate lighting control panel or occupancy sensor
- Eliminates energy waste by allowing emergency lighting to be switched
- Senses a local single normal power circuit
- Wired as either a control device along with a relay panel and occupancy sensor or as a shunt to bypass line voltage devices when normal power fails

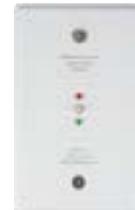

Catalog Number	Product Description	Finish	Voltage	Pallet Quantity	UPC
CEPC-2-D	Emergency Power Control 0-10V	White	120V or 277V	920	080083832088

High Bay Fixture Mount Sensors

Greengate

- Fixture-mount high bay/low bay occupancy sensor with integrated photocell
- Provides 0-10V control and 1-100% continuous dimming
- 2 interchangeable 360° high bay and low bay lenses; specifically designed for LED fixture control
- Easy to program; Quicksnap feature for easy installation
- Suitable for use in standard and cold storage applications



Catalog Number	Product Description	Finish	Voltage	Watts	Detection Type	Coverage	Pallet Quantity	UPC
OEF-P-010V-MV	Fixture Mount Sensor	White	120/277V	1200	PIR	1,500 sq. ft.	1200	080083758104

Control

SURE-LITES | ALL-PRO | ATLITE

EXIT & EMERGENCY



Sure-Lites
p. 24-26



All-Pro
p. 26-27



AtLite
p. 27-28



SEL LED Emergency Lighting

Sure-Lites

- Designed to reduce egress system cost and maintenance and improve reliability
- Proprietary adjustable AccuLED Optics™
- Injection-molded, high-impact thermoplastic
- Long life LED's, No maintenance nickel cadmium battery
- EZ hang feature reduces installation time and cost



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
SEL17	2 Head, NiCad	White	2-5.4W Inc. Heads	17 ft.	120-277V	0.78W	270	080083722143
SEL25	2 Head, NiCad	White	2-9W Inc. Heads	25 ft.	120-277V	0.6W/0.64W	270	080083736669
SEL25SD	2 Head, NiCad, Self Diagnostic	White	2-9W Inc. Heads	25 ft.	120-277V	0.67	324	080083723027
SEL50	2 Head, NiCad	White	2-12W Inc. Heads	50 ft.	120-277V	1W/1.02W	324	080083733347
SEL50SD	2 Head, NiCad, Self Diagnostic	White	2-12W Inc. Heads	50 ft.	120-277V	1.19	270	080083733361

AP2SQ Emergency Lighting

Sure-Lites

- LED emergency light with a minimum of 90 minutes of run time
- Compact form factor optimizes aesthetics
- Adjustable square heads maximize design flexibility; Each head outputs 80 lumens
- No maintenance nickel cadmium battery
- Universal j-box mounting pattern and snap-fit polycarbonate housing construction reduces installation time



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
AP2SQLED	2 Head, NiCad	White	2-5W Inc.Heads	12 ft.	120/277V	2 at 277V	288	080083824922

SELW LED Outdoor Emergency Lighting

Sure-Lites

- Code compliant, wet location for outdoor use; Standard 0°C to 40°C temperature rating
- Designed to reduce egress system cost and maintenance and improve reliability
- Proprietary adjustable AccuLED Optics™; 25 feet of emergency egress coverage
- Injection-molded, high-impact thermoplastic
- Long life LED's, No maintenance nickel cadmium battery



SELW25BZ



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
SELW25BZ	2 Rotatable Heads, NiCad	Bronze	2-9 W INC Heads	25 ft.	120-277V	1.4	224	080083764037

XR LED Emergency Lighting

Sure-Lites

- Emergency light with minimum of 90 minutes runtime; Chicago and New York City compliant
- 20-gauge sheet metal housing; Heads are fully adjustable and 300 lumens each
- Designed to reduce egress system cost and maintenance and improve reliability
- Proprietary adjustable AccuLED Optics™, No maintenance nickel cadmium battery
- External battery disconnect and EZ Hang feature reduces installation time and cost



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
XR6C-LED	Steel, NiCad	White	2-12W INC Heads	60 ft.	120-277V	1.7	144	080083753215

SELMTG LED Emergency Lighting

Sure-Lites

- Architectural emergency light; Up to 60-feet of coverage; Rugged sheet metal housing
- Designed to reduce egress system cost and maintenance and improve reliability
- Proprietary adjustable AccuLED Optics™; Recessed heads to eliminate ceiling disruption
- Self-diagnostic automatically performs NFPA required testing; City of Chicago and New York City compliant
- External battery disconnect and EZ Hang features reduce installation time and cost



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
SELMTG60R5SD	2 Rotatable Heads, NiCad, Self Diag.	White	2-12 W INC Heads	60 ft.	120-277V	5	168	080083823406

CHX Exit Signage

Sure-Lites

- Chicago code compliant exits are ideal for general purpose applications
- Extensive range of field-installed accessories and choice of faces
- Ceiling and end mounting; Lens installs from side of fixture for convenient maintenance
- Durable steel construction and attractive styling
- High-efficiency illumination; Compatible in commercial, institutional and multi-housing applications



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
CHX60	AC Powered, Steel	White	2-12 W INC Heads	N/A	120/277V	3	60	080083573615
CHX61	AC Powered, Steel	White	2-12 W INC Heads	N/A	120/277V	3	60	080083574629
CHX70	Self Powered, Steel	White	2-12 W INC Heads	N/A	120/277V	3	96	080083576753
CHX71	Self Powered, Steel	White	2-12 W INC Heads	N/A	120/277V	3	120	080083567614
CHXC71	Self Powered Combo Unit, Steel	White	2-12 W INC Heads	60 ft.	120/277V	3.6	90	080083771271

EBP LED Emergency Battery Packs

Sure-Lites

- Battery Pack automatically switches to emergency mode when AC power fails
- Maintains illumination of an LED fixture for a minimum of 90 minutes
- UL 924 classified for field retrofit installation
- Guaranteed compatibility with Cooper Lighting Solutions' LED fixtures with accessible LED drivers



Catalog Number	Product Description	Voltage	Watts	Pallet Quantity	UPC
EBPLED7W	Emergency Battery Pack	120/277V	7	240	080083732265
EBPLED14W	Emergency Battery Pack	120/277V	14	288	080083732272
EBPLED-7.5WSD	Emergency Battery Pack	120/277V	7.5	210	080083158621
EBPLEDLP-10WSD	Emergency Battery Pack	120/277V	10	400	080083158645

EBP Fluorescent Emergency Battery Packs

Sure-Lites

- Battery Pack automatically switches to emergency mode when AC power fails
- Powers a fluorescent lamp for 90 minutes during a power outage
- UL 924 classified for field retrofit installation
- Compatible with most linear fluorescent lamps



Catalog Number	Product Description	Voltage	Watts	Pallet Quantity	UPC
EBP500	Emergency Battery Pack	120/277V	2.7	576	080083906741
EBP1400	Emergency Battery Pack	120/277V	3.8	432	080083912162

APEL LED Emergency Lighting

All-Pro

- Emergency light with a minimum of 90 minutes of run time
- No maintenance nickel cadmium battery
- Fully adjustable LED heads maximizes design flexibility
- Compact form factor optimizes aesthetics; Components are injection-molded, high impact thermoplastic
- Universal j-box mounting pattern and snap-fit housing construction reduce installation time



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
APEL	2 Head, NiCad	White	2-5.4W Inc. Heads	17 ft.	120/277V	0.47W at 277V	384	080083566501
APELH2	2 Head, Nicad, Remote Capacity	White	4-5.4 W INC Heads	34 ft.	120/277V	0.8 W at 277 V	512	080083804986

Exit & Emergency

APX LED Exit Signage

All-Pro

- Economical LED exit sign for general purpose applications
- Durable, injection-molded, thermoplastic material resists discoloration due to UV radiation
- Energy-efficient, low-maintenance LED's provide bright illumination
- Universal configurations (single- and double-face); Universal mounting (ceiling, wall and end)



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
APX7G	Self Powered, Unv. Green	White	120/277V	1.05W at 277V	270	080083566549
APX7R	Self Powered, Unv. Red	White	120/277V	1.14W at 277V	270	080083566532

APC LED EM Combo Light

All-Pro

- Economical LED combo unit; Exit and LED emergency lighting heads
- Durable, injection-molded, thermoplastic material resists discoloration due to UV radiation
- Energy-efficient, low-maintenance LED's provide bright illumination
- Universal configurations (single- and double-face); Universal mounting (ceiling, wall and end)
- Low-voltage disconnect, Line-Latched; Brownout circuit



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
APC7G	2 Heads, Unv. Green	White	2-5.4W Inc. Heads	17 ft.	120/277V	1.68W at 277V	192	080083567164
APC7R	2 Heads, Unv. Red	White	2-5.4W Inc. Heads	17 ft.	120/277V	1.68W at 277V	192	080083566556
APCH7G	2 Heads, Unv. Green, Remote Cap.	White	4-5.4W Inc. Heads	34 ft.	120/277V	1.68W at 277V	192	080083567188
APCH7R	2 Heads, Unv. Red, Remote Cap.	White	4-5.4W Inc. Heads	34 ft.	120/277V	1.68W at 277V	192	080083567171

APWR LED Remote Heads

All-Pro

- Emergency lighting remote heads unit; Allows for 17 feet of emergency egress coverage
- Adjustable heads adjust 80° from vertical with 358° rotation
- Wet location listed and can be used indoors or outdoors
- Injection-molded thermoplastic material
- Universal mounting plate; Flame-resistant and impact-resistant



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
APWR2	Remote Emergency Lamps, 2 Heads	White	2-5.4W Inc. Heads	17 ft.	3.6V	1W	810	080083608584

Exit & Emergency

RCS LED Combo Exit Light

AtLite

- New York City compliant LED combo exit sign
- Heavy-duty, 20-gauge steel housing and face plate provides durability
- Energy-efficient, long-life LED's; illuminated by field-replaceable LED strip
- Single or double face with maximum of three heads for ultimate flexibility



Catalog Number	Product Description	Finish	Replaces Up To	Voltage	Watts	Pallet Quantity	UPC
RCS183LED	Steel Combo, 1 face, 3 heads	White	3 12W Inc. Heads	120/277V	N/A	192	080083574308
RCS283LED	Steel Combo, double face, 3 heads	White	3 12W Inc. Heads	120/277V	N/A	192	080083574292
RCS182LED	Steel Combo, 1 face, 2 heads	White	2 12W Inc. Heads	120/277V	N/A	192	080083574322
RCS282LED	Steel Combo, double face, 2 heads	White	2 12W Inc. Heads	120/277V	N/A	192	080083574315

Rival RXS Exit Signage

AtLite

- New York City compliant steel LED exit sign
- Heavy-duty, 20-gauge steel housing with canopy
- Energy-efficient, long-life LED's; illuminated by field-replaceable LED strip
- Universal configurations (single- and double-face); Universal mounting (ceiling, wall and end)



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
RXSN8RU	Steel Exit, Self Powered, Univ. Face	White	120/277V	5	24	080083634576

REL Emergency Lighting

AtLite

- New York City compliant steel LED emergency light
- Heavy-duty, 20-gauge steel housing and face plate for maximum durability
- Long-lasting, high-efficiency LED heads; maintenance-free nickel cadmium battery
- Brownout protection; low-voltage disconnect



Catalog Number	Product Description	Finish	Replaces Up To	Voltage	Watts	Pallet Quantity	UPC
10REL36-LED42	Steel Emergency Light, 2 heads, 2 remotes	White	2 9W Inc. Heads	120/277V	5	144	080083574353
10REL72-LED83	Steel Emergency Light, 3 heads, 5 remotes	White	2 9W Inc. Heads	120/277V	5	192	080083574339

AUX LED Edge-Lit Exit Signage

AtLite

- Edge-lit Exit allows seamless presence in architecturally significant surroundings
- Eagle Eye self-diagnostics; New York City compliant
- Universal mounting; Universal Lens (clear, mirror, white and single- and double-sided)
- Ordering and installation simplified as all housing and lens options are included



Catalog Number	Product Description	Finish	Voltage	Watts	Pallet Quantity	UPC
AUXSSD	Unv. Self powered, Self Diag.	Silver	120/277V	1.1 at 277 V	50	080083703296
AUXSSD6	Unv. Edge Lit, Self powered	Silver	120/277V	0.9/1.1W	50	080083718115
AUXSSD-SP PACK	Unv. Self powered, Self Diag., Single Pack	Silver	120/277V	1.1 at 277 V	50	080083848669

ATLEMINI Series Emergency Lights

AtLite

- New York City compliant LED emergency light with 90 minutes of run time
- J-box and conduit knockouts for easy installation; wall or ceiling mount applications
- Long-lasting, energy-efficient LED heads; maintenance-free nickel cadmium battery
- Available with two or three 80 lumen rotatable heads



Catalog Number	Product Description	Finish	Replaces Up To	Coverage	Voltage	Watts	Pallet Quantity	UPC
ATLEMINI-2H	Steel Emergency Light, 2 Rotable heads	White	5.4 W INC	18 ft.	120-277V	0.78 W	400	080083836079
ATLEMINI-3H	Steel Emergency Light, 2 Rotable heads	White	5.4 W INC	27 ft.	120-277V	0.78 W	200	080083836093

Exit & Emergency

OUTDOOR

LUMARK & HALO OUTDOOR



Floodlight
p. 30



Wall Mount
p. 31



Ceiling Mount
p. 31



Area/Site
p. 32



Night Falcon LED Floodlight

Lumark

- Cost-effective solution available in 3 sizes
- Precision engineered and high-efficiency optics delivers superior uniformity
- Compact, robust die-cast aluminum housing, driver compartment and door
- 6H x 6V NEMA distribution
- Perfect for area lighting for security, building facade lighting, accent and signage lighting



NFFLD-S



NFFLD



NFFLD-L



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
NFFLD-S-C15-KNC-UNV	Small, Knuckle	Carbon Bronze	150W HID	4000K	120-277V	5,797	51	27	080083760268	P07DFEUO
NFFLD-S-C15-T-UNV	Small, Trunnion	Carbon Bronze	150W HID	4000K	120-277V	5,797	51	36	080083760275	P07DFEUO
NFFLD-C25-S	Medium, Slipfitter	Carbon Bronze	250W HID	4000K	120-277V	10,530	85	20	080083801244	PFT7DB3V, PY7YCS7P, P688KBF9
NFFLD-C25-T	Medium, Trunnion	Carbon Bronze	250W HID	4000K	120-277V	10,530	85	24	080083801220	P1KJC5UE, PX8F6VUW, P5VPYGW5
NFFLD-C40-S	Medium, Slipfitter	Carbon Bronze	400W HID	4000K	120-277V	16,932	128	20	080083801206	P6WY96JR, PSCSJCSY, P9J2MXXC
NFFLD-C40-T	Medium, Trunnion	Carbon Bronze	400W HID	4000K	120-277V	16,932	128	20	080083801183	P1FRZ85N, P5KZZS6U, P2UR5RKV
NFFLD-L-C100-S	Large, Slipfitter	Carbon Bronze	1,000W HID	4000K	120-277V	33,941	252	6	080083800889	PXL241RW, PWCEZG57, P15GC6CP
NFFLD-L-C100-T	Large, Trunnion	Carbon Bronze	1,000W HID	4000K	120-277V	33,941	252	6	080083800902	PWOBVSIR, PVK3AY96, PYOWZCFO

Note: DLC Premium items are noted in bold.

Tracer LED Floodlight

Lumark

- Combines value and performance in a unique durable design; Die-cast aluminum housing
- Delivers superior uniformity and excellent illumination to the targeted application
- Rugged, die-cast housing; IP66 rated for exceptional durability and long-term reliability
- Energy and maintenance savings up to 94% compared to halogen; Up to 138 lm/W
- Design flexibility for applications such as landscape, accent, facade or sign lighting



TCRL



TCRS



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
TCRS5M	Small, Medium Distribution	Carbon Bronze	50W Halogen	4000K	120-277V	552	5	360	080083884834	P8738XR6
TCRS8W	Small, Wide Distribution	Carbon Bronze	70W Halogen	4000K	120-277V	860	8	360	080083884957	P7RUSYQ7
TCRL15M	Large, Medium Distribution	Carbon Bronze	100W Halogen	4000K	120-277V	1,630	12	144	080083884872	PRMSPIFM
TCRL20M	Large, Medium Distribution	Carbon Bronze	120W Halogen	4000K	120-277V	2,215	18	144	080083884896	PD93F1ZM
TCRL20W	Large, Wide Distribution	Carbon Bronze	120W Halogen	4000K	120-277V	2,251	18	144	080083884995	PRCTOM6W
TCRL26M	Large, Medium Distribution	Carbon Bronze	150W Halogen	4000K	120-277V	2,953	25	144	080083884919	PRXQGGD7

Crosstour LED Wall Pack

Lumark

- Architectural style with super bright, energy-efficient LEDs
- Low-profile, rugged die-cast aluminum construction and stainless steel hardware
- Universal back box with sealed and gasketed optical compartment
- Surface- or inverted-mount for post/bollard mounting, facade/canopy and low-level pathway illumination
- For building entrances, multi-use facilities, apartment buildings, institutions, schools, stairways and loading docks



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
XTOR1B	Small Full Cutoff	Carbon Bronze	70W HID	5000K	120-277V	1,418	12	324	080083777969	PRVAZAZR
XTOR2B	Small Full Cutoff	Carbon Bronze	100W HID	5000K	120-277V	2,135	18	270	080083778225	PGP4FYV3
XTOR3B	Small Full Cutoff	Carbon Bronze	150W HID	5000K	120-277V	2,751	26	270	080083778041	PWFZHYJH
XTOR4B	Medium Full Cutoff	Carbon Bronze	250W HID	5000K	120-277V	4,269	38	216	080083778003	PUJ1NXGY
XTOR6B	Large Full Cutoff	Carbon Bronze	320W HID	5000K	120-277V	6,129	58	72	080083774807	PWEKQNMV
XTOR6BRL	Large Refractive Lens	Carbon Bronze	320W HID	5000K	120-277V	6,225	58	54	080083774821	PH59ANRG
XTOR8B	Large Full Cutoff	Carbon Bronze	400W HID	5000K	120-277V	8,502	81	54	080083774814	P5557CRH
XTOR8BRL	Large Refractive Lens	Carbon Bronze	400W HID	5000K	120-277V	8,635	81	54	080083774852	P2F72ZQT
XTOR6B-PC1	Large Full Cutoff	Carbon Bronze	N/A	5000K	120-277V	6,129	58	54	080083774845	PWEKQNMV
XTOR8B-PC1	Large Full Cutoff	Carbon Bronze	N/A	5000K	120-277V	8,502	81	54	080083774869	P5557CRH

Note: DLC Premium items are noted in bold.

WP LED Glass Wall Pack

Lumark

- High performance, energy-efficient illumination across 3 housing sizes
- Rugged, die-cast aluminum construction; Heat and impact resistant borosilicate glass lens
- Gasketed housing and sealed optical compartment makes impervious to contaminants
- Energy and maintenance savings up to 89% versus HID solutions
- Ideal for pathway illumination, building entrances, vehicle ramps, schools, tunnels, stairways and loading docks



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
WPSLED10	Small Refractive Lens	Bronze	100W HID	4000K	120-277V	4,733	39	48	080083885664	PTV55HZL
WPMLED10	Medium Refractive Lens	Bronze	100W HID	4000K	120-277V	4,700	39	32	080083885688	PIV2ITCS
WPMLED15	Medium Refractive Lens	Bronze	150W HID	4000K	120-277V	6,203	49	32	080083885701	PBJ759X5
WPMLED25	Medium Refractive Lens	Bronze	250W HID	4000K	120-277V	10,227	81	32	080083885725	PGE0EJ1Q
WPLLED15	Large Refractive Lens	Bronze	150W HID	4000K	120-277V	6,075	49	32	080083885749	PSEL08UB
WPLLED25	Large Refractive Lens	Bronze	250W HID	4000K	120-277V	10,198	81	32	080083885763	PTOPZBCG
WPLLED45	Large Refractive Lens	Bronze	450W HID	4000K	120-277V	15,523	121	32	080083885787	PY0SAW93

Note: DLC Premium items are noted in bold.

CLCSLED Canopy Luminaire

Lumark

- Slim, low-profile, traditional design
- Die-cast aluminum housing
- High-performance, energy-efficient illumination
- Quick mount installation bracket
- Seamlessly integrates into new or existing spaces including bank/retail drive-thru, covered sidewalks and hospitality entryways



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
CLCSLED-40-SM-UNV	Square Surface Mount	Bronze	150W HID	4000K	120-277V	4,839	36	48	080083776061	PCQT436Y
CLCSLED-55-SM-UNV	Square Surface Mount	Bronze	175W HID	4000K	120-277V	7,230	56	72	080083776085	PJ1SCY7M
CLCSLED-86-SM-UNV	Square Surface Mount	Bronze	250W HID	4000K	120-277V	11,494	92	54	080083776108	P124NMP8

Caretaker LED Area Luminaire

Lumark

- Rugged die-cast housing for durability in security applications
- Uniform distribution with excellent vertical illumination for maximum light coverage
- Wall/pole-mount bracket and integral slipfitter for versatility in mounting
- Versatile universal mounting plate allows quick and easy installation
- Low-cost, low-maintenance solution for residential street lighting, perimeter area lighting, parking areas, loading platforms, boat docks, access drives or pathways



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
CTKR1B	Area site with PC, UNV Mount Arm	Raw	150W HID	4000K	120-277V	4,515	29	48	080083865390	P9G7NN3C
CTKR2B	Area site with PC, UNV Mount Arm	Raw	175W HID	4000K	120-277V	7,110	50	40	080083865406	PRSAJP8E, PKGOJV49
CTKR3B	Area site with PC, UNV Mount Arm	Raw	250W HID	4000K	120-277V	9,741	71	48	080083865413	P9E35CQB, P3P0FHML
SR-CARETAKER	Small Acrylic Refractor	Clear	N/A	N/A	N/A	N/A	N/A	200	080083699087	N/A

Note: DLC Premium items are noted in bold.

Prevail LED Area/Site Luminaire

Lumark

- Provides a new level of performance, versatility and value
- Low-profile, architectural design with a die-cast aluminum housing
- Versatile mount arm includes multiple drill patterns, round and square poles
- Simple retrofit installation; Reduces installation time and provides labor savings
- Ideal for general area lighting such as parking lots, walkways, roadways and building areas



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
PRVS-C25-UNV-T3	T3 Distr., STD Arm Mount	Bronze	250W HID	4000K	120-277V	13,183	96	16	080083897308	PVJAMD08
PRVS-C25-UNV-T4	T4 Distr., STD Arm Mount	Bronze	250W HID	4000K	120-277V	13,140	96	16	080083897322	PC50ML3L
PRVS-C40-UNV-T3	T3 Distr., STD Arm Mount	Bronze	400W HID	4000K	120-277V	17,144	131	14	080083897346	PFLCEN3P
PRVS-C40-UNV-T4	T4 Distr., STD Arm Mount	Bronze	400W HID	4000K	120-277V	17,087	131	16	080083897360	P0B3IQ7D
PRVS-C60-UNV-T3	T3 Distr., STD Arm Mount	Bronze	450W HID	4000K	120-277V	20,050	153	14	080083897384	PG5CZXKH
PRVS-C60-UNV-T4	T4 Distr., STD Arm Mount	Bronze	450W HID	4000K	120-277V	19,984	153	14	080083897421	PM3XNS4Q
PRVS-XL-C75-UNV-T3	T3 Distr., STD Arm Mount	Bronze	750W HID	4000K	120-277V	26,120	176	8	080083906499	PX7MW2FB
PRVS-XL-C75-UNV-T4	T4 Distr., STD Arm Mount	Bronze	750W HID	4000K	120-277V	26,098	176	8	080083906512	PCWO68VF

Note: DLC Premium items are noted in bold.

LAS Area/Site Luminaire

Lumark

- Automatic dusk-to-dawn area lighting with included twistlock photocontrol
- 10-position, field-selectable lumens across 2 die-cast aluminum housing sizes
- Energy and maintenance savings up to 79% versus HID solutions up to 79%
- Versatile, adjustable slipfitter arm mounts horizontally or vertically for simple installation
- Ideal parking lots, walkways, building areas and other outdoor areas



Catalog Number	Product Description	Finish	Replaces Up To	CCT	Voltage	Selectable Lumens	Watts	Pallet Quantity	UPC	DLC Product ID
LAS45S-T3	T3 Distr., Adjustable Slipfitter Arm	Bronze	450W HID	4000K	120-277V	4,900 - 20,000	30-153	28	080083155804	P1T4HG08
LAS45S-T4	T4 Distr., Adjustable Slipfitter Arm	Bronze	450W HID	4000K	120-277V	4,900 - 20,000	30-153	28	080083155828	PJZTZ423
LAS45S-T5	T5 Distr., Adjustable Slipfitter Arm	Bronze	450W HID	4000K	120-277V	4,900 - 20,000	30-153	28	080083155842	PW39PQB3
LAS100S-T3	T3 Distr., Adjustable Slipfitter Arm	Bronze	1,000W HID	4000K	120-277V	8,200 - 34,000	48-251	21	080083155866	PP8AW4F5
LAS100S-T4	T4 Distr., Adjustable Slipfitter Arm	Bronze	1,000W HID	4000K	120-277V	8,200 - 34,000	48-251	21	080083155880	P0CHU9AS
LAS100S-T5	T5 Distr., Adjustable Slipfitter Arm	Bronze	1,000W HID	4000K	120-277V	8,200 - 34,000	48-251	21	080083155903	PMUFIF4F

Note: DLC Premium items are noted in bold.

Area/Site

Industrial in a new light

PRODUCT SELECTION GUIDE

Turnkey lighting and controls solutions
for warehouses, distribution centers
and logistic facilities

LIGHTING BRANDS

Ametrix
AtLite
Corelite
Ephesus
Fail-Safe
Halo
Halo Commercial
Invue
io
Iris
Lumark
Lumière
McGraw-Edison
Metalux
MWS
Neo-Ray
Portfolio
RSA
Shaper
Streetworks
Sure-Lites

CONTROLS BRANDS

Greengate
Fifth Light

CONNECTED LIGHTING SYSTEMS

HALO Home
WaveLinX

IOT PLATFORMS

Trellix

Cooper Lighting Solutions is a
registered trademark.

All other trademarks are property
of their respective owners.

Product availability, specifications,
and compliances are subject to
change without notice.

© 2021 Cooper Lighting Solutions
All Rights Reserved
Printed in USA
Publication No. CA525490EN0-WESCO-Anixter
May 2021

Cooper Lighting Solutions
1121 Highway 74 South
Peachtree City, GA 30269
P: 770-486-4800
www.cooperlighting.com

Canada Sales
5925 McLaughlin Road
Mississauga, Ontario L5R 1B8
P: 905-501-3000
F: 905-501-3172

