

Section 11 Security Cables and Connectors

11

Coaxial Cables 11:2
Alarm Cables 11:3
Composite Cables 11:4
BNC/COAX Connectors & Tools 11:5
Category 5e & 6 Cables 11:6

Security Cables and Connectors


Coaxial Cables



Anixter Number	Description
RG59-PVC-BLK-COM-###	RG59B/U 75 ohm Cu braid, black PVC jacket
RG59-PVC-WTE-COM-###	RG59B/U 75 ohm Cu braid, white PVC jacket
RG59-LSNH-WTE-CM-###	RG59B/U 75 ohm Cu braid, white LSNH jacket
RG59-LSNH-BLK-CM-###	RG59B/U 75 ohm Cu braid, black LSNH jacket
RG59-DUCT-P-###	RG59B/U 75 ohm Cu braid, duct grade, black
RG59-SWA	RG59B/U 75 ohm Cu braid, PVC/SWA/PVC black jacket
RG59-M-LSNH-BLK-P-###	RG59B/U Miniature 75 ohm Cu braid, black LSNH jacket
RG11-PVC-BLK-P-###	RG11A/U 75 ohm 95% Cu braid black PVC jacket
RG11-LSNH-BLACK-P-###	RG11A/U 75 ohm 95% Cu braid, black LSNH jacket
RG11-SWA-LSNH	RG11A/U 75 ohm Cu braid, PE/SWA/LSNH black jacket
RG11-SWA-PVC	RG11A/U 75 ohm Cu braid, PVC/SWA/PVC black jacket
CT100-PVC-BLK-P-###	CT100 75 ohm 1mm BC, CPE, 50% Cu braid, black PVC jacket
CT100-LSNH-BLK	CT100 75 ohm 1mm BC, CPE, 50% Cu braid, black LSNH jacket
CT100-LSNH-WTE	CT100 75 ohm 1mm BC, CPE, 50% Cu braid, white LSNH jacket
CT100-DUCT-P-###	CT100 75 ohm 1mm BC, CPE, 50% Cu braid, duct grade, black
CT100-RBS-BLACK-P-###	CT100 75 ohm 1mm BC, CPE, 50% Cu braid, black RBS jacket
CT125-PVC-BLK-P-###	CT125 75 ohm 1.25mm BC, CPE, 50% Cu braid, black PVC jacket
CT125-LSNH-BLK	CT125 75 ohm 1.25mm BC, CPE, 50% Cu braid, black LSNH jacket
CT125-LSNH-WTE	CT125 75 ohm 1.25mm BC, CPE, 50% Cu braid, white LSNH jacket
CT125-DUCT-P-###	CT125 75 ohm 1.25mm BC, CPE, 50% Cu braid, duct grade, black
CT125-RBS-BLACK-P-###	CT125 75 ohm 1.25mm BC, CPE, 50% Cu braid, black RBS jacket
CT167-LSNH-BLK-P-###	CT167 75 ohm 1.67mm BC, CPE, 50% Cu braid, black LSNH jacket
CT167-DUCT	CT167 75 ohm 1.67mm BC, CPE, 50% Cu braid, duct grade, black
URM70-LSNH-BLK-P-###	URM 70 75 ohm, black LSNH jacket

P### = Put up reel lengths (in metres)

= Put up reel lengths (in metres)

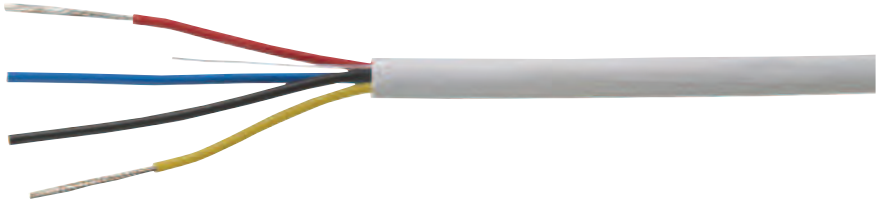

Anixter Number	Description
Unscreened PVC	
AL-4C-PVC-P###	0.19mm ² , 4 core, PVC insulated, white PVC jacket
AL-6C-PVC-P###	0.19mm ² , 6 core, PVC insulated, white PVC jacket
AL-8C-PVC-P###	0.19mm ² , 8 core, PVC insulated, white PVC jacket
AL-12C-PVC-P###	0.19mm ² , 12 core, PVC insulated, white PVC jacket
Screened PVC	
AL-4C-PVC-S-P###	0.19mm ² , 4 core, PVC insulated, 0/A foil shield, white PVC jacket
AL-6C-PVC-S-P###	0.19mm ² , 6 core, PVC insulated, 0/A foil shield, white PVC jacket
AL-8C-PVC-S-P###	0.19mm ² , 8 core, PVC insulated, 0/A foil shield, white PVC jacket
AL-12C-PVC-S-P###	0.19mm ² , 12 core, PVC insulated, 0/A foil shield, white PVC jacket
Unscreened LSNH	
AL-4C-LSNH-P###	0.19mm, 4 core LSNH insulation, white LSNH jacket
AL-6C-LSNH-P###	0.19mm, 6 core LSNH insulation, white LSNH jacket
AL-8C-LSNH-P###	0.19mm, 8 core LSNH insulation, white LSNH jacket
AL-12C-LSNH-P###	0.19mm, 12 core LSNH insulation, white LSNH jacket
Screened LSNH	
AL-4C-LSNH-S-P###	0.19mm ² , 4 core, LSNH/Alum-My Screen, white LSNH jacket
AL-6C-LSNH-S-P###	0.19mm ² , 6 core, LSNH/Alum-My Screen, white LSNH jacket
AL-8C-LSNH-S-P###	0.19mm ² , 8 core, LSNH/Alum-My Screen, white LSNH jacket
AL-12C-LSNH-S-P###	0.19mm ² , 12 core, LSNH/Alum-My Screen, white LSNH jacket

P# # # = Put up reel lengths in metres

Composite Cables




Anixter Number	Description
Coax Composites	
B539945	RG6 + 18 AWG/1-pair siamese, PVC, black
B439945	RG6 + 18 AWG/1-pair siamese, LSNH, grey
RG59-COMP1-LSNH	RG59 + 0.75mm ² /1-pair, LSNH, black siamese
B549945	RG59 + 18 AWG/1-pair siamese, PVC, black
B449945	RG59 + 18 AWG/1-pair siamese, LSNH, grey
B500PTZ-000	RG59, 23 AWG/1-pair, 18 AWG/2 core PVC
B501PTZ	RG59, 22 AWG/1-pair overall foil screen, 18 AWG/2 core PVC
B502PTZ	RG59, 18 AWG/1-pair overall foil screen, 18 AWG/2 core PVC
358487	RG59 75 ohm PVC coaxial cable + 2-18 power pair conductors
B9265	RG59 22STR TNC FPE 95% BC BRD, SHD + 22-2C STR TNC PVC foil SHD PVC siamese
RG59-0.75/1P-PVC-WTE	RG59 + 0.75mm ² /1-pair PVC white, circular construction
UTP Composites	
B5284US	UTP Category 5e 2-pair 24 AWG + 16 AWG/2 core siamese, PVC, black
B5284UE	UTP Category 5e 2-pair 23 AWG + 16 AWG/2 core round, PVC, black
Miscellaneous Composite	
BYR48312	24 AWG/1-pair, + TCWB + 18 AWG/2 core PE, PVC, blue
CRS070212-1	22 AWG/2-pair, 20 AWG/1-pair, 22 AWG/9 core for access control
B558AFS	18 AWG/4 core, 22 AWG/3-pair, 22 AWG/2 core, 22 AWG/4 core, PVC/PVC Banana Peel®
B558AFS+2C22SHLD	18-4C+22-3P+(2)22-2C+22-4C STR BC PP PVC IND SHLD UNJKT CMR Banana Peel®

Security Cables and Connectors
COAX Connectors and Tools




Anixter Number	Description
BNC-C-RG59	BNC crimp plug for RG59 (turned body, die-cast nut)
BNC-C-MULTI	100 BNC plugs RG59 in bag with spare pins and ferrules
BNC-C-FEMALE	BNC female crimp jack for RG59
BNC-F-F	BNC straight female to female in-line adaptor
BNC-C-RIGHTANGLE	BNC right angle crimp jack for RG59
BNC-T-PIECE	BNC T piece F-M-F adaptor
BNC-GOALPOST	BNC goalpost adaptor
BNC-C-CT100	BNC crimp plug for CT100 cable
BNC-C-CT125	BNC crimp plug for CT125 cable
BNC-C-CT125RBS	BNC crimp plug for CT125RBS cable
BNC-C-CT167	BNC crimp plug for CT167 cable
BNC-C-MINI	BNC crimp plug for Mini RG59
BNC-C-RG11	BNC crimp plug for RG11
SRB-RG59-02	Strain relief boots for RG59 connectors black

BNC Crimp Tools

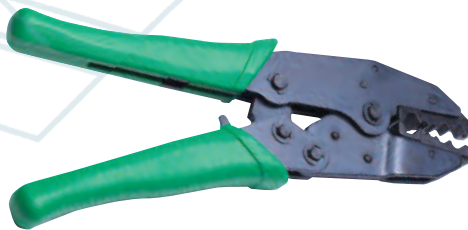

Anixter Number	Description
CRIMPTOOL-1	Crimp Tool for RG59, CT100, RG58 and Mini RG59
CRIMPTOOL-2	Crimp Tool for CT125
CRIMPTOOL-3	Crimp Tool for RG11 and RG213

Category 5e and 6 cables UTP and FTP, ISTP Category 7

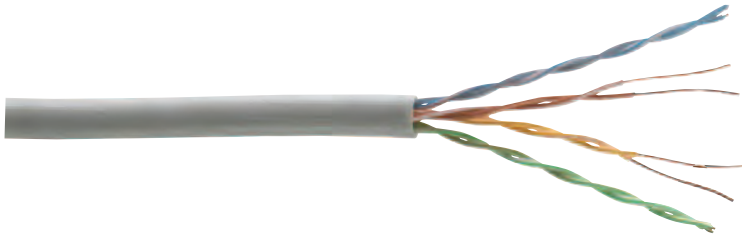

Anixter Number	Description
Category 5e Cables	
CM-00424UTP-5BE	24 AWG/4P Cat 5e UTP PVC grey sheath Belden 1583E
CMZ-00424UTP-5BE	24 AWG/4p Cat 5e UTP LSZH grey Belden 1583ENH
CM-00424UTP-5EUGC	24 AWG/4PR Cat 5e UTP PVC grey sheath
CMZ-00424UTP-5EUGC	24 AWG/4PR Cat 5e UTP LSZH white sheath
CM-00424UTP-5E-DUCT	24 AWG/4PR Cat 5e UTP duct grade black sheath
CMZ-00424UTP-5E-SWA	24 AWG/4PR Cat 5e UTP SWA/LSNH black sheath
CMZ-00424UTP-5E-SWB	24 AWG/4PR Cat 5e UTP GSWB/LSNH grey sheath
Category 6 Cables	
CM-00424UTP-6UGC	24 AWG/4PR Cat 6 UTP PVC grey sheath
CMZ-00423UTP/B-6B-06	23-4P UTP-CM SOL BC Cat 6 PP/LSZH blue jacket reel tested to 250 MHZ Belden 7965ENH
CMZ-00424UTP-6UGC	24 AWG/4PR Cat 6 UTP LSZH light grey sheath
CMZ-00423FTP-6B	23AWG/4PR Cat 6 FTP SOL BC Poloyefin LSOH grey reels Belden 7860ENH
CM-00424UTP-6-DUCT	24 AWG/4PR Cat 6 UTP duct grade black sheath
CMZ-00424FTP-6-SWA	24 AWG/4PR Cat 6 FTP LSNH/SWA/LSNH black sheath
6 and 7 ISTP	
CMZ-00423STP-7BE	23-4P STP-CM SOL BC Cat 6 and 7 ISTP FRNC grey Belden 1885ENH