



ESSENTIAL ACCESS CONTROL SOLUTIONS

More than just a reader and panel

Access control solutions, incorporating mechanical and electronic elements, as well as logical access controls, are fundamental to any integrated security system. They extend beyond the building to the perimeter, gate or fencing to protect people, facilities, assets and intellectual property.

With the increased focus on safeguarding employee health and safety, access control solutions are rapidly evolving to keep pace with new demands, and will be a key component of your updated workplace safety strategy.

This product guide highlights some of the latest essential access control products available from our premier technology partners to assist with your workplace adaptation requirements.



Access Control Readers

Featuring a sleek, upscale design, HID Signo Readers extend HID's tradition of best-in-class performance while adding innovative features to keep organisations secure. To help organisations meet the security needs of our dynamic world, HID Signo Readers are designed to be highly versatile, powerful and connected for the future.


HID Part No.	Anixter Part No.	Description
20TKS-01-00001H	10012036	Signo20, Mullion, Seos Profile, OSDP/Wiegand, terminal, mobile ready
40TKS-01-00001H	10012038	Signo40, Wall mount, Seos Profile, OSDP/Wiegand, terminal, mobile ready
40KTKS-01-00001H	10012041	Signo40K, Wall mount with keypad, Seos Profile, OSDP/Wiegand, terminal, mobile ready



Magnetic Locks

- Securing the door with high-quality electronic locks is essential for all access control systems.
- The Schlage range from Allegion includes models with field selectable voltage, status monitoring and various mounting options.

Allegion Part No.	Anixter Part No.	Description
3300U	10016719	Schlage 3300 series single magnetic lock - 600 lbs- 12/24V DC/500 mA @12V DC
3300U-DSM-MBS-L1	10016720	Schlage 3300 series single magnetic lock - 600 lbs- 12/24V DC/500 mA @12V DC with door status monitor & magnetic bond sensor with LED indicator
3302U	10016721	Schlage 3300 series double magnetic lock - 600 lbs- 12/24V DC/500 mA @12V DC
3302U-DSM2-MBS-L2	10016722	Schlage 3300 series double magnetic lock - 600 lbs- 12/24V DC/500 mA @12V DC with door status monitor & magnetic bond sensor with led indicator
3600U	10016723	Schlage 3600 series single magnetic lock - 1200 lbs- 12/24V DC/500 mA @12V DC
3600U-DSM-MBS-L1	10016724	Schlage 3600 series single magnetic lock - 1200 lbs- 12/24V DC/500 mA @12V DC with door status monitor & magnetic bond sensor with led indicator
3602U	10016725	Schlage 3600 series double magnetic lock - 600 lbs- 12/24V D/500 mA @12V DC
3602U-DSM2-MBS-L2	10016726	Schlage 3600 series double magnetic lock - 600 lbs- 12/24V DC/500 mA @12V DC with door status monitor & magnetic bond sensor with led indicator
TJ3300	10016727	Top jamb for inswing doors for Schlage 3300 series
TJ3302	10016728	Top jamb for inswing doors for Schlage 3300 series double doors
TJ3600	10016729	Top jamb for inswing doors for Schlage 3600 series
HDB 3300 8mm	10016730	Herculite door bracket for glass doors of 8 mm thickness for Schlage 3300 series
HDB 3300 10mm	10016731	Herculite door bracket for glass doors of 10 mm thickness for Schlage 3300 series
HDB 3300 12mm	10016732	Herculite door bracket for glass doors of 12 mm thickness for Schlage 3300 series
HDB 3600 12mm	10016733	Herculite door bracket for glass doors of 12 mm thickness for Schlage 3600 series
HEB 3300	10016734	Header extension bracket for Schlage 3300 series
HEB 3600	10016735	Header extension bracket for Schlage 3600 series
AH 3300	10016736	Armature holder can be used for fire doors and glass doors for Schlage 3300 series
AH 3600	10016737	Armature holder can be used for fire doors and glass doors for Schlage 3600 series
AB 3300	10016738	Angle bracket for Schlage 3300 series
AB 3600	10016739	Angle bracket for Schlage 3600 series

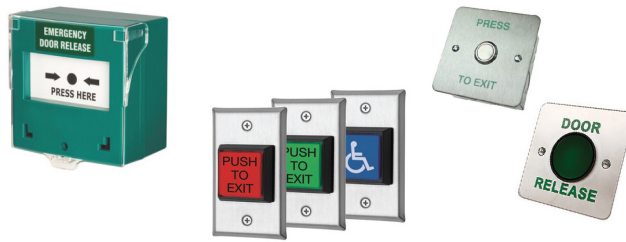

Exit Devices

- Egress from the secure side of the door can be achieved using exit buttons.
- Emergency breakglass units will ensure door opening in case of emergency.

Allegion Part No.	Anixter Part No.	Description
IPB500.1	10016740	Exit push button DPDT, flush mounted with green plastic button, stainless steel (optional red, green & handicap indicators) with backbox
AC.PB20.F.SS	10016741	Exit push button, flush mounted vandal resistant, stainless steel with backbox
AC.PB10.F.SS	10016742	Exit push button, green mushroom button, stainless steel with backbox
EGB.100.G	10016743	Emergency call point station, green case, double pole, sounder and back light, includes cover
EGB.200.G	10016744	Emergency call point station, green case, triple pole, sounder and back light, includes cover
EDL.G-BG	10016745	Emergency door release, green case, double pole, resettable, includes cover



Power Supplies


- Power supplies with battery backup, mains failure and low battery alerting available in 12V DC and 24V DC versions.
 - Choice of enclosure size
 - Mount common access control door controller PCBs.
- Axis A1001 Door Controller Power Centres
 - POE+ or mains power selectable
 - Available up to four-door controllers
 - Rack or wall mount versions

DanTech Part No.	Anixter Part No.	Description
DA774-XSM-12VDC	10105472	Dantech, 12V DC 8A extra-small mild steel wall mount Power Centre, wall mount
DA774-LGE-12VDC	10104775	Dantech, 12V DC 8A large mild steel wall mount Power Centre, wall mount
DA890IN	1055638	Dantech, Indoor Power Centre for one Axis A1001 network door controller, wall mount



Security Systems

- Inception is an integrated access control and security alarm system.
- With web-based software built directly into the main system controller, the Inception system is easy to access using a web browser on a computer, tablet or smartphone.
- Access Controlled Doors - Up to 128
- Card Readers - Up to 256
- Security Monitored Areas - Up to 96
- Inputs - Up to 512
- Outputs - Up to 512
- Lift Cars - Up to 32
- Card Holders / Users - Up to 10,000
- Event log - Up to 250,000 events
- Certified to EN50131 Grade 3
- Milestone VMS Integration

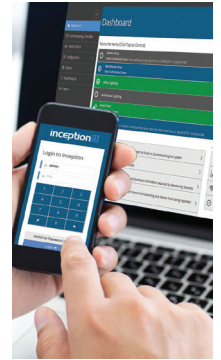

Part No.	Description
Inception Access Kits	
INCP-2DOORKIT	2 door kit with inception controller, medium unpowered enc, 2 SIFER readers & 20 SIFER P cards
INCP-4DOORKIT	4 door kit with inception controller, medium unpowered enc, 4 SIFER readers & 20 SIFER P cards
INCP-4DOORKIT/M	4 door/monitored kit with inception controller, 8Z LAN expander medium unpowered enc, 4 SIFER readers & 20 SIFER P cards
INCP-2DOORKIT/F	2 door kit with inception controller, medium unpowered enc, 2 SIFER readers & 20 SIFER P fobs
INCP-4DOORKIT/F	4 door kit with inception controller, medium unpowered enc, 4 SIFER readers & 20 SIFER P fobs
INCP-4DOORKITF/M	4 door/monitored kit with inception controller, 8Z LAN expander medium unpowered enc, 4 SIFER readers & 20 SIFER P fobs
Readers	
INTG-994720	SIFER smart card reader Mifare DESfire EV2
INTG-994720MF	SIFER multi-format reader
INTG-994725	SIFER keypad, smart card reader Mifare DESfire EV2
INTG-994725MF	SIFER keypad, smart card reader Mifare DESfire EV2 multi format version
Credentials	
INTG-994610	SIFER-P ISO cards, DESFire, EV2, 4K, pre-programmed and printed
INTG-994616	SIFER-P fobs, DESfire, EV2, 4K, pre-programmed

Anixter can provide a complete access control solution or provide components for a custom system of your design.

Contact your local Anixter sales representative for more information.

About Anixter: anixter.com/aboutus/emea
Legal Statement: anixter.com/legalstatement

20X0421EM © 2021 Anixter Inc. · 01/21

Anixter Inc. World Headquarters
2301 Patriot Boulevard
Glenview, Illinois 60026
United States
+1.224.521.8000

Anixter EMEA
Inspired, Easthampstead Road,
Bracknell, Berkshire
RG12 1YQ United Kingdom
+44 (0)1344 388100

anixter.com/emea

